

EnviroNize® ULTRAMAX

SCAN FOR
**CARE
& USE**



Made in Canada
Manufactured under License
from EnviroNize
11-1673 Richmond St. PMB 110
London, ON, Canada N6G 2N3

877.432.8548 - EnviroNize
www.environize.ca
www.environize.us




POWERHOUSE **DISINFECTING** and **DEODORIZATION**

Added Protection and Protocols: Areas beyond common, high-touch surfaces where "Primary Disinfection Protocols" are inaccessible, or the area is too large to provide proper Primary Disinfection.

Provides **Disinfection** and **Deodorization** to areas where **NO OTHER DEVICE CAN BE DEPLOYED!** The **EnviroNize® UltraMax** once deployed quickly and effectively envelopes the area with a thick fog-like mist engulfing everything in its path. The result is a conditioning of **Clean, Fresh and Sanitized!**

Clean | Fresh | Sanitized

Why a smaller disinfectant solution droplet size is more efficient for disinfection?

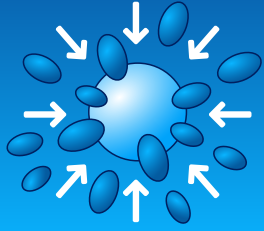

1~3 Microns - UltraMax™ Droplet Size

NO ESCAPING - Dust, harmful airborne pathogens (a Floating Virus which attaches to airborne particles) are attracted to the UltraMax™ Fog-Like Mist like a **MAGNET**. Pathogen eradicating begins immediately once they come in contact with the **EnviroNize®** Disinfectant Solution.



CHOOSING THE RIGHT DISINFECTION PROTOCOL TO FIGHT THE COVID-19 VIRUS

Primary Disinfection Protocols

(Handheld Trigger Spraying Devices/Wiping Cloth) - **Key High Touch Contact Surfaces: Surface-adhering virus:** defined as cell-to-cell contact infection, it happens when a contaminated object gets in contact with a human body (its hand). **Limited coverage as the disinfectant droplet is too heavy** to travel any distance. (1~2 feet from deployment)

Added Protection and Protocols (ULTRAMAX™)

Areas Beyond Common, High-Touch Surfaces: Floating virus: defined as airborne contamination where "Primary Disinfection Protocols" are inaccessible, or the area is too large to provide proper **Primary Disinfection**. **Maximum coverage as the disinfectant droplet is very light** with virtually no weight and can travel longer distances. (30~100 feet from deployment)

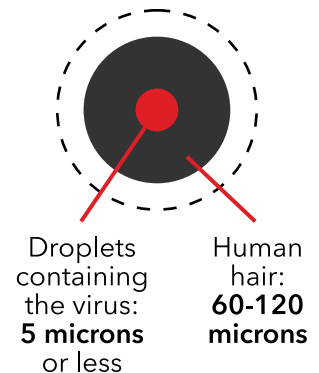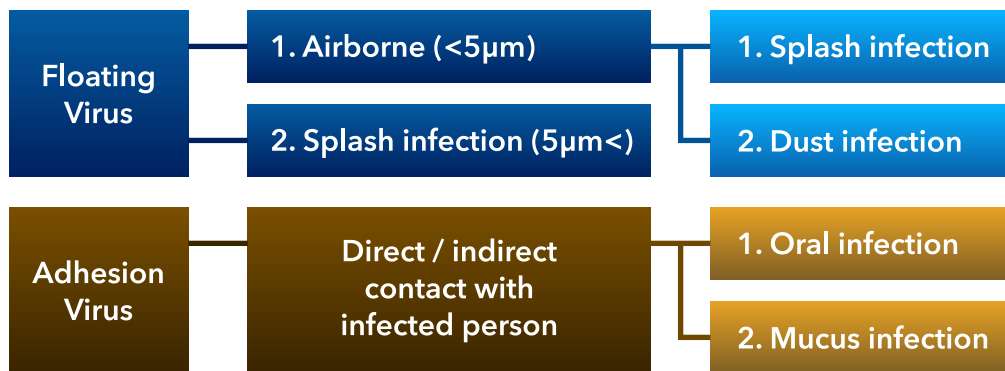

ULTRAMAX Provides Critical Disinfection to Areas Where Other Devices Cannot!

The **UltraMax™** delivers a consistent, fog-like mist quickly and efficiently. It supersaturates the atmosphere, deploying 1-3 micron droplets of **EnviroNize® Disinfectant**, completely engulfing any closed-in area within minutes. This **POWERFUL DISINFECTANT** assists in eradicating floating pathogens before they land on **Primary High Touch Surfaces** such as walls and other surrounding hard, non-porous surfaces, where they could encounter human activity and spread the deadly virus. It also applies a disinfectant to surfaces that are inaccessible through **Primary Disinfection Protocols**.

Fog-Like Mist Sanitation is a proven method to fight against micro-organisms infections. "The ability of a sprayer to make smaller particles may help a solution's molecules to be suspended in the air for a longer period because of their low settling velocity rate. This may increase the solution's chance of coming into contact with pathogens and inactivating them. Thus, the fogger used should have an aerosol size less than 20 µm."

Source: <https://www.ncbi.nlm.nih.gov/pmc/articles/PMC7315945/>

Why Choose EnviroNize® Disinfectant Solutions in an UltraMax™ Deployment Device?

SAFE AROUND

MARINE, PLANT, HUMAN AND ANIMAL LIFE



Powerful & Sustainable HOCl Technology

- Non-WHMS regulated
- Non-Hazardous
- Zero Surface Contact Residue



Health	0 - None
Flammability	0 - None
Physical	0 - None
Personal Protection	A - Splash Goggles

Health and Safety: EnviroNize® Disinfectant Solutions are manufactured with Health and Safety in mind. Choosing a disinfectant that promotes a **ZERO HEALTH HAZARD** is key to EnviroNize® disinfection protocols.

Good Common Sense: Always look to the products SDS (Safety Data Sheet) before deploying the disinfectant to ensure the product you are using supports sustainability and does not promote a health hazard.

Choose an UltraMax™ that meets your Needs!

Small to Mid Range 350 sq ft ~ 1400 sq ft

2" Straight Pipe Deployment



2" Flex Hose Deployment



2" Housekeeping w/Cart



Mid to Max Range 2100 sq ft ~ 3500 sq ft

4" Straight Pipe Deployment



4" Flex Hose Deployment









4" Housekeeping w/Cart



Product Specifications

Model #	Specifications	Voltage	Total Power Consumption	Current Power Consumption	Droplet Size	Control Method	Solution Consumption
EUMF-350	D35*W22*H36 cm	110v / 220v	160W	1.9A	1 μ m ~ 5 μ m (micron)	On/Off Timer	1.8 lph
EUMF-700P	D38*W28*H33 cm	110v / 220v	240W	3A	1 μ m ~ 5 μ m (micron)	On/Off Timer	3.0 lph
EUMF-700	D38*W28*H33 cm	110v / 220v	240W	3A	1 μ m ~ 5 μ m (micron)	On/Off Timer	3.0 lph
EUMF-1400	D38*W28*H33 cm	110v / 220v	480W	6A	1 μ m ~ 5 μ m (micron)	On/Off Timer	6 lph
EUMF-2100	D65*W42*H33 cm	110v / 220v	720W	9A	1 μ m ~ 5 μ m (micron)	On/Off Timer	9 lph
EUMF-2800	D76*W42*H33 cm	110v / 220v	960W	12A	1 μ m ~ 5 μ m (micron)	On/Off Timer	12 lph
EUMF-3500	D90*W45*H35 cm	110v / 220v	1440W	15A	1 μ m ~ 5 μ m (micron)	On/Off Timer	18 lph

 Accessories

ITEM	DESCRIPTION	PRODUCT PICTURE		
EUMF-2FH	Item EUMF-2FH Flex Hose (2" x 2 Meter) for use with UltraMax™ as extension piping. Fits models EUMF-350; 700; 1400 series			
EUMF-2SP	Item EUMF-2SP Straight Pipe (2" x 3 Feet) for use with UltraMax™ as extension piping. Fits models EUMF-350; 700; 1400 series			
EUMF-4FH	Item EUMF-4FH Flex Hose (4" x 2 Meter) for use with UltraMax™ as extension piping. Fits models EUMF-2100; 2800; 3500 series			
EUMF-4SP	Item EUMF-4SP Straight Pipe (4" x 3 Feet) for use with UltraMax™ as extension piping. Fits models EUMF-2100; 2800; 3500 series			
EUMF-CT	Item # EUMF-CT UltraMax™ Circular Timer. Use to control solution deployment times up to 24-hour period for all UltraMax™ devices			
EUMF-UC	Item EUMF-UC Small utility cart w/casters for use with UltraMax™. Fits models EUMF-350; 700; 1400 series			
ITEM	DESCRIPTION	APPROX. COVERAGE	PACK SIZE	
EUMF-350	UltraMax™ coverage up to 350'. Includes carrying handle. Comes with 2 x 2" straight pipes. 2" Flex hose is an option for flexible misting applications. 110v w/power cord	350 Sq. Ft	1	
EUMF-700P	UltraMax™ coverage up to 700'. Includes carrying handle. Comes with 1 x 2" straight pipes and 1 x 2" Flex hose. 110v w/power cord	700 Sq. Ft	1	
EUMF-700	UltraMax™ coverage up to 700'. Includes carrying handle. Comes with 2 x 2" straight pipes. 2" Flex hose is an option for flexible misting applications. 110v w/power cord	700 Sq. Ft	1	
EUMF-1400	UltraMax™ coverage up to 1400'. Comes with cart/gravity-fed tank and 2 x 2" straight pipes. 2" Flex hose is an option for flexible misting applications. 110v w/power cord.	1400 Sq. Ft	1	
EUMF-2100	UltraMax™ coverage up to 2100'. Comes with cart/gravity-fed tank and 2 x 4" straight pipes. 4" Flex hose is an option for flexible misting applications. 110v w/power cord.	2100 Sq. Ft	1	
EUMF-2800	UltraMax™ coverage up to 2800'. Comes with cart/gravity-fed tank and 2 x 4" straight pipes. 4" Flex hose is an option for flexible misting applications. 110v w/power cord.	2800 Sq. Ft	1	
EUMF-3500	UltraMax™ coverage up to 3500'. Comes with cart/gravity-fed tank and 2 x 4" straight pipes. 4" Flex hose is an option for flexible misting applications. 110v w/power cord.	3500 Sq. Ft	1	