

# MOBILE GRIDDLES

MG-30, 36, 48, 60, 72

Project: \_\_\_\_\_  
 Item #: \_\_\_\_\_  
 Quantity: \_\_\_\_\_



MG-60

Our griddle bodies, legs, splash guards, burners, under shelves, radiants, water pans, fasteners, pilot tubes are all constructed in 304 series stainless steel for durability and ease of cleaning. Compared to units made of metal or 430 stainless steel, our units are built to last.

15,000 BTUH stainless steel burners are placed every 5.75" to ensure the most even heat pattern possible. These units heat up to cooking temperature within 5 minutes. Our stainless steel burners carry a 10 year warranty.

Each MG model includes built-in tank holders that accommodate standard 20 Lb. propane tanks. Each model is also available with a single gas connection and 25' quick disconnect hose for use with remote tanks. Each MG model is available as either LP or NG.

MG models include either one, or two pro griddles on the unit. The griddle plate is made of 5/16" cold rolled steel with stainless steel splash guards and a removable stainless steel grease tray in front of the unit.

**Certifications**



**SPECIFICATIONS**

- Gas griddles constructed of 304 stainless steel including bodies, burners and all fasteners
- 15,000 BTUH stainless steel burners
- Two 14" wheels and two total lock casters
- Ready to use: ships completely assembled on a skid
- Tank holder(s) on back of unit that hold 20 lb. propane tank(s)
- Storage shelf and angled legs for rock solid durability
- Includes water pans with drain ports to ease cleaning and help eliminate grease fires from occurring
- 16 ga stainless steel radiants that remain in place during transportation and cleaning
- Pro griddle plate(s) with stainless steel splash guard and removable grease tray(s)
- c ETL us, ETL Sanitation listed, Conforms to ANSI Z83.11/CSA 1.8 and NSF Standard 4

**More Standard Features**

- Unibody design for lighter weight and added strength
- Stainless steel pilot burner tube system
- Two stage regulator(s) and hose(s) on LP models
- Single gas connection and a 10ft quick disconnect on NG models
- Factory technician tested prior to shipping
- 1 year parts and labor limited warranty
- Lifetime warranty on body and 10 years on burners

**Options/Accessories**


- |                |               |
|----------------|---------------|
| Cooking Grates | End Shelf     |
| Front Shelf    | Propane Tanks |
| Side Burner    |               |
| Roll Dome      |               |

**SPECIFICATIONS**



Model	MG-30	MG-36	MG-48	MG-60	MG-72
Number of Burners	4	5	6	8	10
BTUH	64,500	79,500	99,000	129,000	159,000
Actual Weight (lbs)	195	220	288	348	417
Shipping Weight (lbs)	272	318	389	463	555
Gas Connections (LP)*	1	1	2	2	2
Cooking Surface	28" x 21"	34" x 21"	46" x 21"	58" x 21"	70" x 21"
Overall Dimensions	38" L x 28" D x 43.25" H	44" L x 28" D x 43.25" H	56" L x 28" D x 43.25" H	69" L x 28" D x 43.25" H	81" L x 28" D x 43.25" H

\* All units are available in natural gas models (MG-NG).

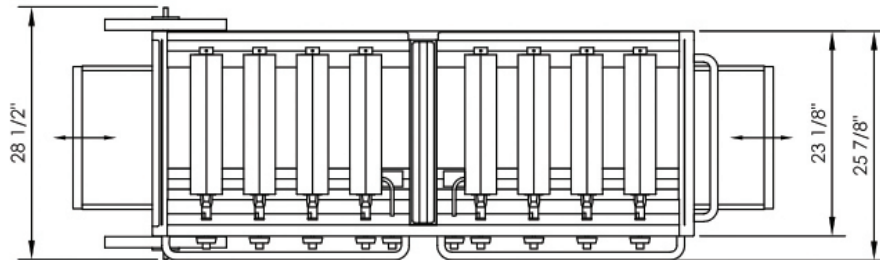

MG	"X"
30	38"
36	44"
48	56"
60	69"
72	81"

