

PRO SERIES GRILLS

RCB- 48. 60. 72

Project: _____

Item #: _____

Quantity: _____



RCB- 72

We constructed our RCB Grills specifically for the rental market, so that you can take the party on the road. It's mobile design was created with large scale events in mind. Built with handles on each end and double crash bars to protect the valves and knobs from being damaged during transport and storage, ensuring maximum durability.

Our grill bodies, legs, cooking grates, burners, under shelves, radiants, water pans, fasteners, pilot tubes are all constructed of 304 series stainless steel for durability and ease of cleaning. Compared to units made of metal or 430 stainless steel, our units are built to last.

15,000 BTUH stainless steel burners are placed every 5.75" to ensure the most even heat pattern possible. These units heat up to cooking temperature within 5 minutes. Our stainless steel burners and cooking grills carry a 10 year and lifetime warranty, respectively.

The RCB model is available in liquid propane (LP). All LP models include a two stage regulator(s) and hose(s) and a built-in tank holder(s) that accommodate standard 20 lb. propane tanks. Each model is also available with a single gas connection and an optional 25' quick disconnect hose for use with remote tanks.

Certifications



SPECIFICATIONS

- Gas grill constructed of 304 stainless steel including grids, burners and all fasteners
- 15,000 BTUH stainless steel burners
- Two 14" wheels and two total lock casters
- Ready to use: ships completely assembled on a skid
- Tank holder(s) on back of unit that hold 20 lb. propane tank(s)
- Storage shelf and angled legs for rock solid durability
- Includes water pans with drain ports to ease cleaning and help eliminate grease fires from occurring
- 16 ga stainless steel radiants that remain in place during transportation and cleaning
- Extra crash bars on the front and side
- c ETL us, ETL Sanitation listed, Conforms to ANSI Z83.11/CSA 1.8 and NSF standard 4

More Standard Features

- Unibody design for lighter weight and added strength
- Stainless steel pilot burner tube system
- Two stage regulator(s) and hose(s) on LP models
- 5131 hose not included with SI model
- Factory technician tested prior to shipping
- 1 year parts and labor limited warranty
- Lifetime warranty on body and cooking grids and 10 years on burners


Options/Accessories

- | | |
|---------------|---------------------|
| Roll Dome | Adjustable Bun Rack |
| Griddle Plate | Steam Pan Adapter |
| End Shelf | Remote Propane Cart |
| Rotisserie | Propane Tanks |
| Wind Guard | Smoker Box |
| BBQ Cover | Charcoal Tray |

SPECIFICATIONS



Model	RCB-48	RCB-60	RCB-72
Number of Burners	6	8	10
BTUH	99,000	129,000	159,000
Actual Weight (lbs)	177	220	263
Shipping Weight (lbs)	275	320	383
Gas Connections (LP)*	2	2	2
Cooking Surface	46" x 21"	58" x 21"	70" x 21"
Overall Dimensions	56" L x 28"D x 36" H	69" L x 28"D x 36" H	81" L x 28"D x 36" H

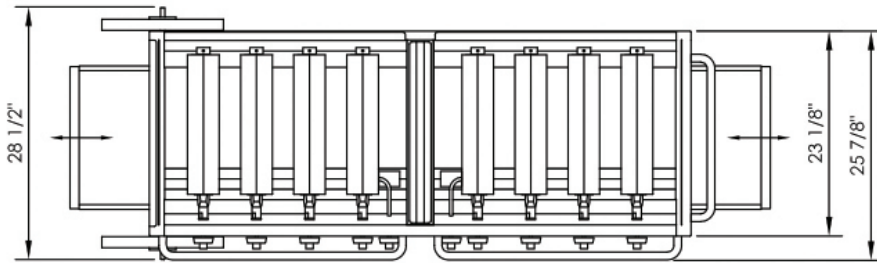

RCB	"X"
48	56"
60	69"
72	81"

