

Project	Item Number	Quantity

Multi-Purpose Oven		<h2 style="margin: 0;">Multi-Purpose Oven</h2> <p>Models:</p> <ul style="list-style-type: none"> ➤ MP4TE - 4 Tray ➤ MP6TE - 6 Tray ➤ MP10TE - 10 Tray
---------------------------	--	---

Multi-Purpose	<p>Features:</p> <ul style="list-style-type: none"> • Touch screen control panel with multiple user programs • Internal lighting for easy product viewing • Baking chamber is made in stainless steel and features rounded corners for easier cleaning and better air flow • Comes with 1 core probe • Double glass panel with low heat emission and easy disconnect for easy cleaning • Carbon fiber handle is light and strong • Reversing motors with heat resistant bearings • Doors feature condensation catching trays • Convection baking from 158 to 518° fahrenheit (70 to 270° celsius) • Steam baking from 158 to 266° fahrenheit (70 to 130° celsius) • Multiple cooking methods: steam, convection, dry, and probe 	
----------------------	---	--


Univex Corporation	<p>Tray Size:</p> <p>18x26" (45.7x66cm)</p>	<p>Optional Accessories:</p> <ul style="list-style-type: none"> • Stand • Multi-point probe • External prode for vacuum • Automatic washing system <p>Warranty:</p> <ul style="list-style-type: none"> • One year, on-site parts and labor
---------------------------	--	---



WE RAISE THE BAR. WE SET THE STANDARD.


Multi-Purpose Oven

ELECTRIC

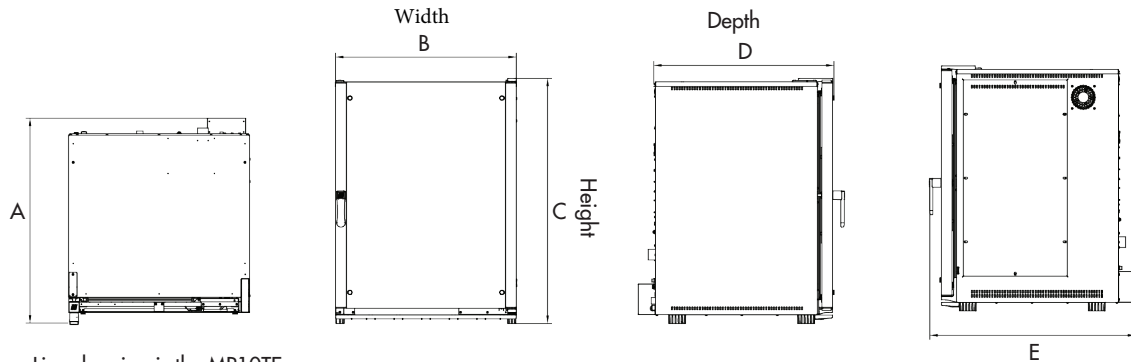

Line drawing is the MP10TE

	MP4TE	MP6TE	MP10TE
A	36.5" (92.5cm)	36.5" (92.5cm)	57.75" (146.5cm)
B	33.5" (85cm)	33.5" (85cm)	33.5" (85cm)
C	26.4" (66.7cm)	32.75" (82.9cm)	45.5" (115.57cm)
D	36.5" (93cm)	36.5" (93cm)	36.5" (93cm)
E	36.5" (92.6cm)	36.5" (92.5cm)	57.75" (146.4cm)

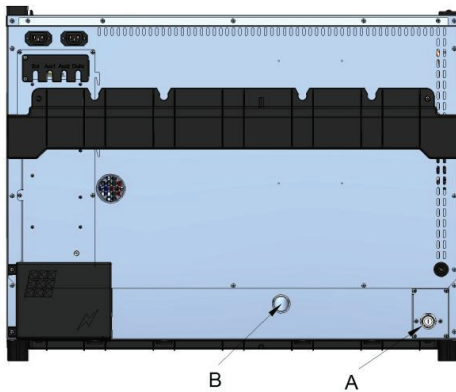

A: Water Inlet 3/4" (1.9cm)
 B: Water Drain 1 1/4" (3cm)

If washing system is in place,
 there is another water connection.

* The water needs to be filtered and
 softened with a hardness of 3.5 - 7 G/Gal

Minimum clearance away from the wall: left side-2" (5cm), right side-4" (10cm), rear-6" (15cm)

Distance needed away from wall to be cleaned and serviced: 20" (50.8cm)

Optional Stand Height: 13.8" (35cm), 26.8 (68cm)", 39.4" (100cm)

Water PSI: 7-43

Oven Weight	
MP4TE	143.3lbs. (65kg)
MP6TE	180.8lbs. (82kg)
MP10TE	242.5lbs. (110kg)

Electrical Information (60Hz)		
Model	Standard Voltage/Phase/Amps	Optional Voltage/Phase
MP4TE	208-240/3/33	400/3
MP6TE	208-240/3/43.7	400/3
MP10TE	208-240/3/66	400/3



Univex Corporation
www.Univexcorp.com

3 Old Rockingham Rd
 Salem, NH 03079
 United States of America

TEL: (800)258-6358
 INTL TEL: (603)893-6191
 FAX: (800)356-5614
 INTL FAX: (603)893-1249