


Project _____

Item Number _____

Quantity _____

Round Rotating Dome Oven

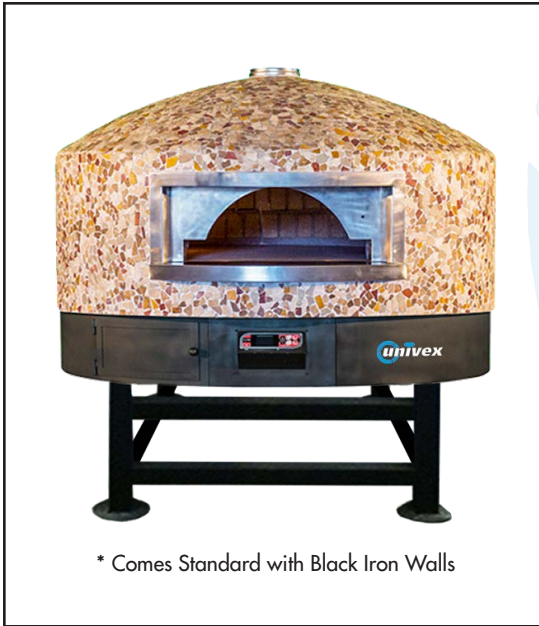

* Comes Standard with Black Iron Walls

Rotating Dome Pizza Oven

Models:

- Rotante47: Rotating Dome Pizza Oven
- Rotante59: Rotating Dome Pizza Oven

Pizza Oven

Features:

- 47" Cooking chamber with 39.4" cooking Surface
- 59" Cooking chamber with 55" cooking surface
- Handmade firebrick pizza oven
- Rotating cooking floor
- Round internal cooking chamber
- Insulated and ready to be connected to smoke stack
- Very well insulated, outside is cool to touch at highest temperature
- Full Electronic Control

Burner Specifications:

- 3/4" (1.9cm) NPT gas connection
- Natural Gas or Propane
- Natural Gas- 4.0" (10.2cm) WC
- Propane- 10.0" (25.4cm) WC

Venting: Depends on local state code. Recommend a dedicated natural draft flue. If exhaust fan is required by code, it needs to be no more than 200-300 CFM.

Univex Corporation

Standard Accessories:

- Iron stand
- Thermometer
- Remote Control
- Iron door
- Stack exhaust internal diameter 7 7/8" (20cm)

Optional Accessories:

- Black or customizable exterior
 - Marble
 - Mosaic

Warranty:

- One year, on-site parts and labor



Rotating Dome Pizza Oven

Gas

Vent Pipe: 7.87"(200mm)

Drawing	Details	
	DOME47D-R DOME47R-R	DOME 59D-R DOME 59R-R
	Height H 185cm 72.83" Length L 165cm 65"	Height H 185cm 72.83" Length L 195cm 76.77"
	External diameter 165cm 65"	External diameter 195cm 76.77"
	DOME47D-RW DOME47R-RW	DOME 59D-RW DOME 59R-RW
	Height H 185cm 72.83" Length L 205cm 80.7"	Height H 185cm 72.83" Length L 235cm 92.5"
	Depth D 165cm 65"	Depth D 195cm 76.77"

Minimum clearance away from combustibles from all sides: 6" (15.2cm)
 Minimum clearance away from combustibles from top: 16" (40.6cm)
 Please note that standard dry-wall or sheet rock is considered a combustible
 Built on a non combustible floor with at least 32" (81.3cm) surrounding the oven
 and at least 40" (101.6cm) in front of the oven
 Minimum clearance under oven: 31 inches² (200cm²)
 Leave enough clearance for someone to service the oven

Oven Weight	
Rotante47	4400lbs. (1995Kg)
Rotante59	5300lbs. (2404Kg)

Number of Pizzas	
Model	12" Pizzas
Rotante47	6
Rotante59	14

BTU: Rotante47 - 92,500 BTU
 Rotante59 - 97,500 BTU

Electrical Information (60Hz)			
	Voltage	Phase	Hz
Standard Voltage	208	3	60