

Manual Shears – MPS-8G / MPS-12

SPECIFICATIONS MPS-8G

Shear Capacity		
Round	.236"	6 mm
Flat Bar	2.75" x .236"	69.8 mm x 6 mm
Sheet Steel	.187"	4.7 mm
Cut Length	6.5"	165 mm
Power Requirement	Manual	
Shipping Dimensions (L x W x H)	20" x 6.5" x 18"	508 x 165 x 457 mm
Shipping Weight	42 lbs.	19 kgs.

Specifications subject to change without notice.

- ◆ 8" Multi-purpose shear
- ◆ Shears flat and round stock
- ◆ Adjustable material hold down
- ◆ Rigid construction
- ◆ Multi-edge blades for increased productivity
- ◆ Spring-assisted action for increased leverage
- ◆ Gear-driven




MPS-8G

SPECIFICATIONS – MPS-12

Shear Capacity		
Round	.236"	6 mm
Flat Bar	2.75" x .236"	69.8 mm x 6 mm
Sheet Steel	.187"	4.7 mm
Cut Length	10.375"	263 mm
Power Requirement	Manual	
Shipping Dimensions (L x W x H)	29" x 6.5" x 17.5"	737 x 165 x 445 mm
Shipping Weight	62 lbs.	29 kgs.

Specifications subject to change without notice.

- ◆ 12" Multi-purpose shear
- ◆ Shears flat and round stock
- ◆ Adjustable material hold down
- ◆ Rigid construction
- ◆ Multi-edge blades for increased productivity
- ◆ Spring-assisted action for increased leverage

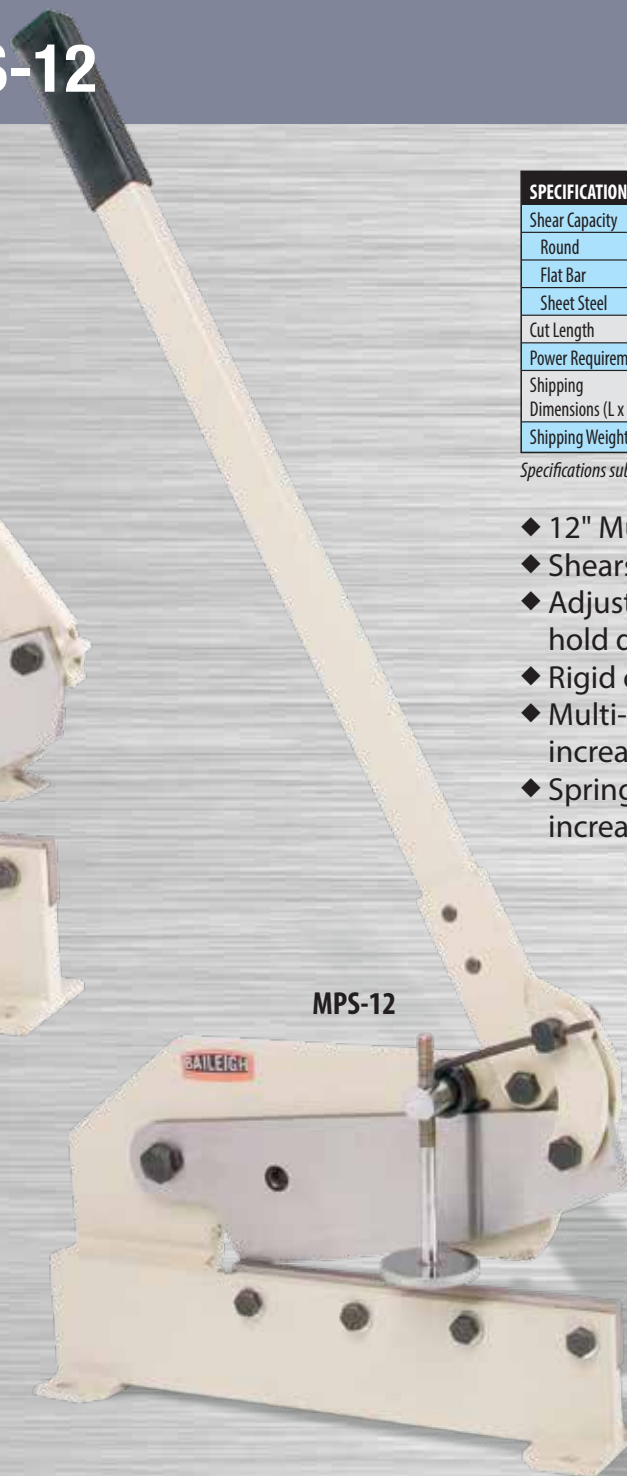

MPS-12