


Bead Rollers – BR-22 / BF-035

SPECIFICATIONS – BR-22		
Capacity (mild steel)	22 ga.	
Throat Depth	7"	177 mm
Shipping Dimensions (L x W x H)	20" x 18" x 8"	508 x 457 x 203 mm
Shipping Weight	71 lbs.	33 kgs.

Specifications subject to change without notice.

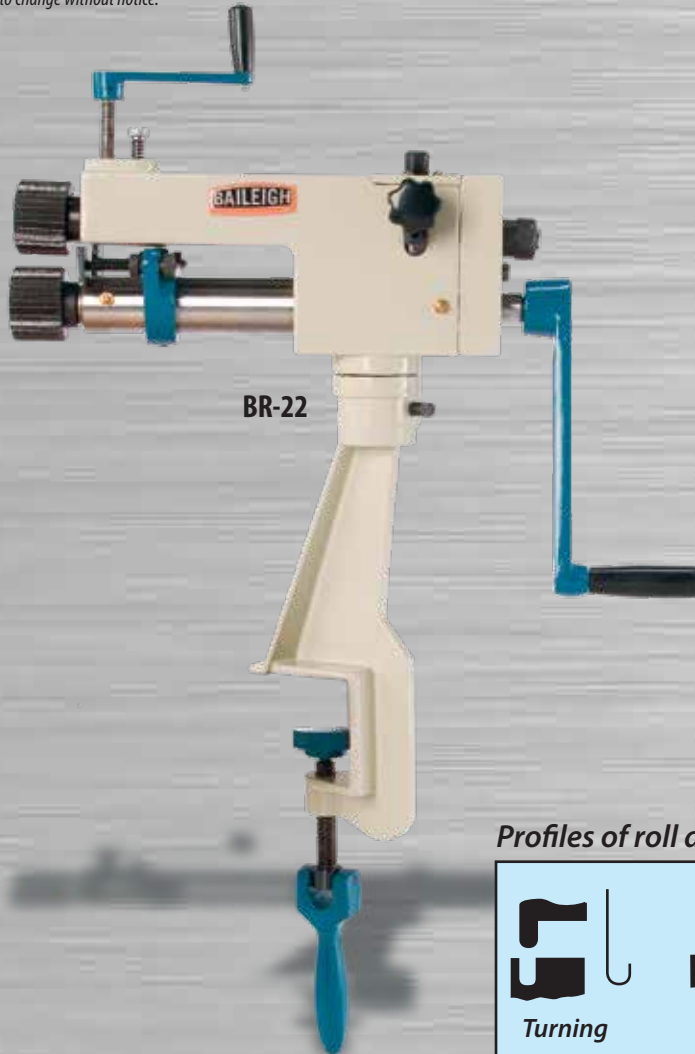

BR-22

- ◆ 7" throat depth
- ◆ Bench-mounted
- ◆ Dies included: 1/4" and 1/8" turning, wiring, crimping, burring, and ogee bead

The BR-035 makes short work of hose beads on all types of tubing and is great for fuel, radiator, and intake lines.

SPECIFICATIONS – BF-035		
Capacity (mild steel)	.035"	.9 mm
Minimum OD	3/8"	9.5 mm
Shipping Weight	5 lbs.	2.3 kgs.

Specifications subject to change without notice.



BF-035

Profiles of roll dies included with the model BR-22

