


Ironworkers – SW-22M

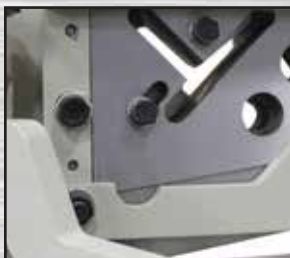

SW-22M
Shear

SPECIFICATIONS – SW-22M

SHEAR CAPACITY		
Round	.625"	16 mm
Square	.625"	16 mm
Flat Bar	4" x .312"	100 mm x 8 mm
Angle Iron	2.375" x 2.375" x .250"	60 mm x 60 mm x 6 mm
Plate	.250"	6 mm
Power Requirement		Manual
Shipping Dimensions (L x W x H)		39" x 16" x 26" / 991 mm x 406 mm x 660 mm
Shipping Weight		253 lbs. / 115 kgs.

Specifications subject to change without notice.

- ◆ Shears angle iron, flat bar, T-bar, round and square stock
- ◆ Rigid construction
- ◆ Adjustable material hold down
- ◆ Spring-assisted return