


50", 55", & 60" Panel Fans

RECIRCULATION FANS



Belt Drive Panel Fans with Galvanized Prop and VRSBRSQ6X Swivel Offset 6" Square Column Mounting Brackets

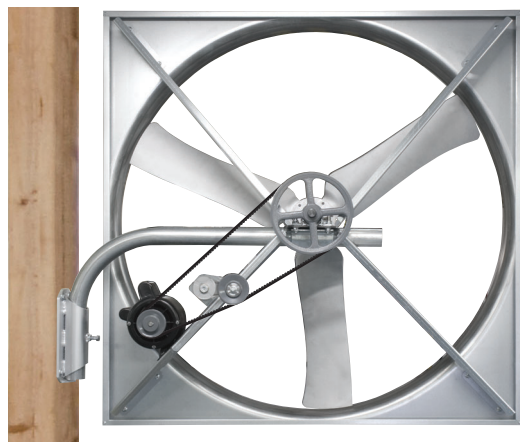

Swivel Offset Wood Post Mount



In-line Column Mount



⚠ WARNING: This product can expose you to chemicals including lead, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov/product.

50", 55", & 60" Panel Fans

J&D Manufacturing's Panel Fans have a rugged x-frame mount with an efficient motor and a powerful balanced blade that is designed to create comfortable air velocity. The cushion-mounted maintenance-free bearings and heavy-duty automatic belt tensioning device make this fan high performing, low maintenance, and a great value.

Features

- Ships fully assembled and ready for installation
- Durable cast iron pulleys
- Balanced, high-output, galvanized prop or **Lifetime Warranty** cast aluminum prop
- Heavy-duty, G90 galvanized, 18-gauge venturi with 10-gauge gusset support X-frame, provides superior strength and rigidity to minimize vibration compared to angle iron, square, or round tube designs
- Utilizes an auto belt tensioner to reduce bounce at startup and provide self-adjusting uniform loading throughout the life of the belt for high efficiency
- Shaft bearings are eccentric locking, pre-lubricated, permanently sealed, rubber mounted for smooth operation and reduced blade fatigue, and are covered by a **3 Year Warranty**
- Wide assortment of optional mounting brackets for wood and steel posts for precise airflow

- Maximize your cooling capabilities by adding a stainless steel, 12-nozzle, high pressure fog ring kit
- Totally enclosed, maintenance-free, high-efficiency motors have completely sealed ball bearings, UL and CUL recognized, and are covered by a **2 Year Warranty**

Installation Options

Part#	Description
Swivel Offset Mounting Bracket	
Wood Post Mount	
VRSBRP6PX	4"-6" Wood Post, VPX Panel Fan, Glv
Round Column Mount	
VRSBRP3X	3" Rnd Column, VPX Panel Fan, Glv
VRSBRP35X	3½" Rnd Column, VPX Panel Fan, Glv
VRSBRP4X	4" Rnd Column, VPX Panel Fan, Glv
VRSBRP55X	5½" Rnd Column, VPX Panel Fan, Glv
Square Column Mount	
VRSBRSQ4X	4" Sq Column, VPX Panel Fan, Painted
VRSBRSQ6X	6" Sq Column, VPX Panel Fan, Painted
In-line Column Mounting Brackets	
Round Column Mount	
VRSBRP3	3"-3½" Rnd Column, Black Powder Coat & Glv
VRSBRP4	4"-4½" Rnd Column, Black Powder Coat & Glv
VRSBRP5	5"-5½" Rnd Column, Black Powder Coat & Glv
VRSBRP6	6"-6½" Rnd Column, Black Powder Coat & Glv
Square Column Mount	
VRSBRP4SQ	4"-4½" Sq. Column, Black Powder Coat & Glv
VRSBRP6SQ	6"-6½" Sq. Column, Black Powder Coat & Glv
Chain Suspending Kit	
HK211	(3) 72" of Chain, w/Fan to Chain Hardware

Part#	Size	Ph	Spd	Thrust CFM	Thrust CFM/Watt	Drive	Prop
Single Phase							
* VPX50GV31011	50"	1	1	22,300	21.1	Belt	3-Glv
VPX50GV61011	50"	1	1	22,500	20.2	Belt	6-Glv
VPX50CA31011	50"	1	1	23,200	21.7	Belt	3-CA
* VPX50CA31011-E	50"	1	1	22,000	23.8	Belt	3-CA
VPX50GV61011-E	50"	1	1	21,200	24.3	Belt	6-Glv
VPX55GV31511-E	55"	1	1	29,700	20.6	Belt	3-Glv
VPX55CA31511	55"	1	1	29,100	20.4	Belt	3-CA
VPX55CA31511-E	55"	1	1	27,400	22.7	Belt	3-CA
VPX55GV51511	55"	1	1	29,200	21.2	Belt	5-Glv
VPX55CA32011	55"	1	1	30,400	17.3	Belt	3-CA
VPX55GV32011	55"	1	1	29,200	20.5	Belt	3-Glv
VPX55GV52011	55"	1	1	29,500	19.1	Belt	5-Glv
VPX60GV32011	60"	1	1	37,500	17.7	Belt	3-Glv
VPX60GV32011-E	60"	1	1	31,600	23.9	Belt	3-Glv
Three Phase							
VPX50GV31031	50"	3	1	22,200	20.7	Belt	3-Glv
VPX50GV31031-E	50"	3	1	21,200	24.9	Belt	3-Glv
VPX50GV61031	50"	3	1	22,300	21.2	Belt	6-Glv
VPX50GV61031-E	50"	3	1	20,900	24.3	Belt	6-Glv
VPX50CA31031	50"	3	1	23,000	22.2	Belt	3-CA
VPX50GV31531	50"	3	1	21,600	23.3	Belt	3-Glv
VPX55CA31531	55"	3	1	28,600	20.8	Belt	3-Glv
* VPX55CA31531-E	55"	3	1	27,400	23.2	Belt	3-CA
VPX55GV31531	55"	3	1	29,900	21.1	Belt	3-Glv
VPX55GV51531	55"	3	1	29,100	21.8	Belt	5-Glv
VPX55CA32031	55"	3	1	29,600	20.4	Belt	3-CA
VPX55CA32031-E	55"	3	1	28,000	23.0	Belt	3-CA
VPX55GV32031	55"	3	1	30,600	21.4	Belt	3-Glv
VPX55GV32031-H	55"	3	1	31,400	16.9	Belt	3-Glv
VPX55GV52031	55"	3	1	29,000	22.0	Belt	5-Glv
* VPX60GV32031	60"	3	1	39,500	17.8	Belt	3-Glv
VPX60GV32031-E	60"	3	1	34,500	23.7	Belt	3-Glv

* Best sellers/recommended models

Bold red text is data based on testing performed by an accredited lab using ANSI/AMCA Standard 230-12

OSHA requires these fans to be mounted a minimum of 7' above the floor

⚠ WARNING: This product can expose you to chemicals including lead, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov/product.