


# Tables

## Adjustable Tables

### THE GEORGETOWN TABLE

**Description:** Our Georgetown table was designed to straddle the OR table with a manual hand crank adjustable height mechanism. Height adjustment within ergonomic range between 36" and 56" off the ground. Travels easily on 3" swivel casters with brakes. Two standard surface areas available. Select extended arm design for electrophysiology procedures.

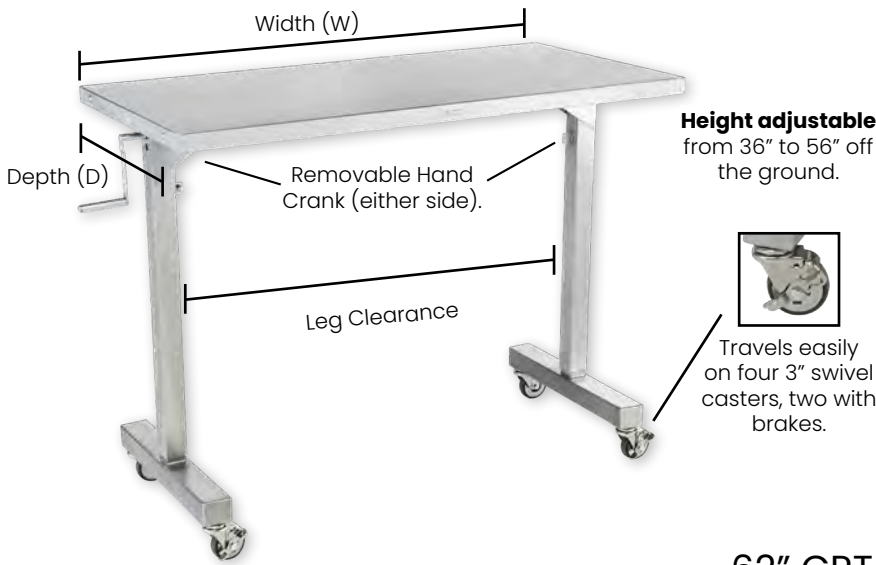

#### Standard Features




Hand Crank


**MANUAL ADJUSTMENT:**  
Manually adjust the height of this table from either side with a detachable crank handle.

#### 62" CRT table


This Georgetown table with the 14" extended arm was designed for optimizing electrophysiology procedures.

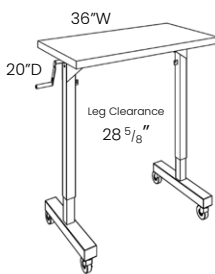


7892SS-0

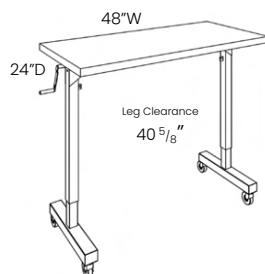

7895SS-0

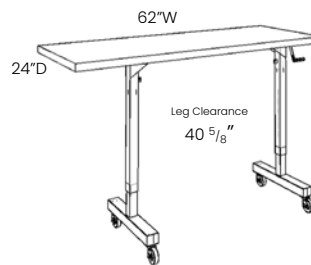

7895SS-0 CRT

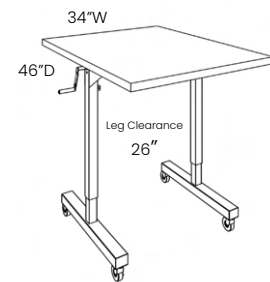

7896SS-0

#### Name

#### Georgetown Table

Model #	Item #	Width (W)	Depth (D)	Leg Clearance	Shipping Weight
7892SS-0	0157892000	36"W	20"D	28 5/8"	135 lbs.
7895SS-0	0157895000	48"W	24"D	40 5/8"	160 lbs.
7895SS-0 CRT	0157895062	62"W	24"D	40"	190 lbs.
7896SS-0	0157896000	34"W	46"D	26"	175 lbs.

**Customize the surface area dimensions to fit your needs.**

Please email us at [info@blickman.com](mailto:info@blickman.com)