



Industrial Floor Machines


- ▶ Triple planetary all steel gears.
- ▶ Durable all metal construction*.
(*TP models only)



TP-1715 N
TP-2015 N
TP2S-2015 N



RM-1715 N
RM-2015 N

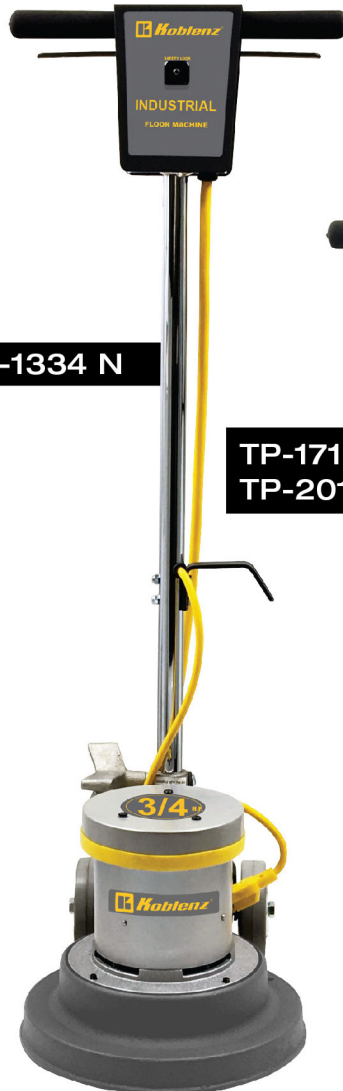

DP-1334 N



TP-1715-AU N
TP-2015-AU N

Don't compromise, **get the best!**

Triple planetary all steel gears



Durable all metal construction

- Cast iron chassis.
- Non marking sealed double ball bearing wheels and wrap around bumper guard.
- Hardened pinion gear.



High performance 1.5 H.P. motor

- Cool running, continuous operating heavy duty motor.
- Best modern technology.
- Can start with low voltage.



Safety switch and locking mechanism

- 13 Gauge chromed steel handle.
- Protection against operator error.
- No operator fatigue.

The Koblenz 3 Idler Planetary gear drive assures a durable and smooth transmission of power from motor to pad driver. (TP & RM models).

Easy to use handle clamp

(TP models only)



- Simple, easy to operate and adjust.
- Smooth gliding on handle.
- Will lock to allow proper height adjustment of the handle.
- Large fine adjustment wheel and lock handle.

Accessories	Part Number
46 lb floor machine weight	46-2751-9
4 gallon solution tank	45-0449-4
Pad driver 12" including clutch plate	45-0513-7
Pad driver 16" including clutch plate	45-0432-0
Pad driver 19" including clutch plate	45-0433-8
16" Trilock™ pad driver	45-0503-8
19" Trilock™ pad driver	45-0504-6
Scrub brush 15"	45-0434-6
Scrub brush 18"	45-0435-3
Carpet brush 15"	45-0436-1
Carpet brush 18"	45-0437-9

MODEL	BRUSH SPEED	PAD SIZE	MOTOR	SHIPPING WEIGHT	NET WEIGHT	CONSTRUCTION
TP-1715 N	175 RPM	17 in	1.5 HP ♦	123 lbs	96 lbs	Cast iron & steel
TP-2015 N	175 RPM	20 in	1.5 HP ♦	125 lbs	106 lbs	
TP2S-2015 N	320/175 RPM	20 in	1.5 HP D.C.	120 lbs	101 lbs	High impact polyethylene
RM-1715 N	175 RPM	17 in	1.5 HP	110 lbs	86 lbs	
RM-2015 N	175 RPM	20 in	1.5 HP	136 lbs	111 lbs	Cast aluminum
DP-1334 N	175 RPM	13 in	3/4 HP	160 lbs	135 lbs	
TP-1715-AU N	175 RPM	17 in	1.5 HP ♦	122 lbs	104 lbs	Cast iron & steel
TP-2015-AU N	175 RPM	20 in	1.5 HP ♦	124 lbs	106 lbs	

- Non marking bumper
- Smooth glide vibration free operation.
- 50 ft. 3 wire grounded 14 gauge.
- Durable chromed 13 gauge steel 1 1/4" diameter.
- 5 inch non-marking wheels.
- 1 1/2" axle with sealed double ball bearings.

• 5 year limited warranty. * Excludes wear items. ♦ Dual capacitor.



Koblenz Eléctrica, S.A. de C.V.
Av. Ciencia #28, Fracc. Industrial Cuamatla,
Cuautitlán Izcalli, Estado de México, C.P. 54730
Tel: 5864•0300



Thorne Electric Company, P.O. Box 18363
San Antonio, Tx 78218-0363
Tel: (210) 590•1226
Fax: (210) 590•1258

www.koblenz-electric.com

*except TP-2015/1715 AU N