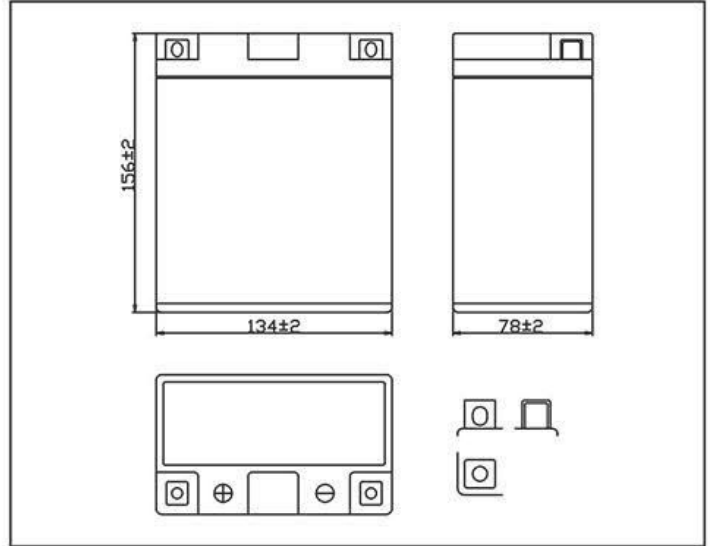


MODEL: YB12A-A(GEL)


Plane Chart:

Parts:

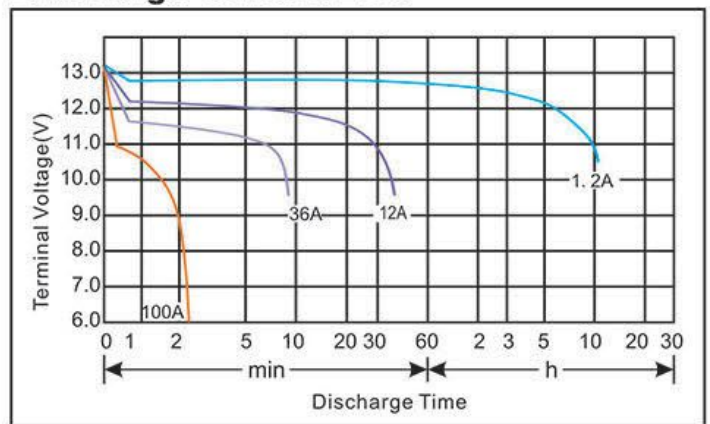
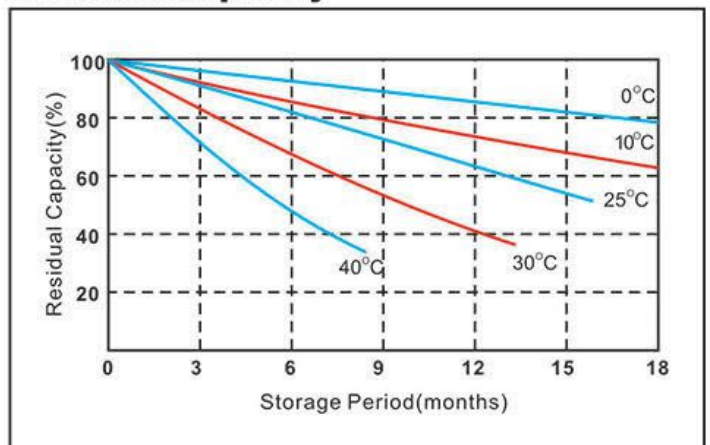
Cover	Container Bottom	Terminal	Positive Plate	Negative Plate	Separator	Electrolyte	Gel	Safety Valve	Seal Glue
ABS	ABS	Cu	PbO ₂	Pb	AGM	dilute sulphuric acid	Fumed Silica	Rubber	Epoxy Resin

Parameter Chart:

Volts	12V	
Capacity (25°C)	10 hours rate	12Ah
Appx. Dimension (mm)	L±2	134
	W±2	78
	H±2	156
Storage Status	Wet	
Weight (Approx)	3.63Kg	

Retention of Charge Storage @25°C

1 month	97%	Directly Mounted
3 month	90%	Directly Mounted
6 month	80%	Constant Volts:14.4V Limit Current:2.4A Charging Hours:2-3H
12 month	40%	Constant Volts:14.4V Limit Current:2.4A Charging Hours:4-6H
CCA	Factory Standard (-10°C)	Factory Standard (-18°C)
Discharging Current	100A	140A

Discharge Current 25°C

Residual Capacity


★ The above are average and data obtained from the first 3 charge/discharge cycles. These are not minimum values.