


# Portable Access Control Folding Gates

IllinoisEngineeredProducts.com  
877.437.4623



## Finished Assembly

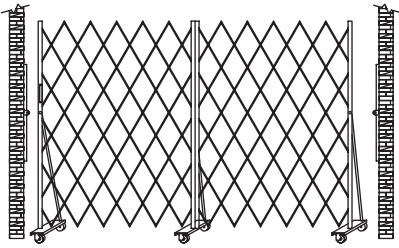

## Tools Needed

Flathead Screwdriver



3/4" (19mm) Wrench or Socket



## Parts Included

1/4" - 20 x 3/4" Carriage Bolt (5)



1/4" - 20 x 3/8" Round Head Bolt (3)



 
Washer (3)



Lock Washer (6)



Brace (6)



Support Brace (3)



1/4"-20 Nut (5)



1/2"-13 Nut (6)



 
3" Caster (6)



Wall Locking Bar (2)




Axle (3)




## INSTALLATION INSTRUCTIONS


- 1) Bolt both sides of gate together at the top, middle and bottom by using the carriage bolts, washers and small nuts. (See Figure 1)

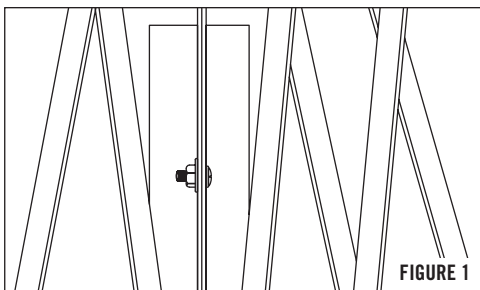

- 2) Insert each gate end into axle support. Insert round head bolt and tighten with screwdriver. (See Figure 2)

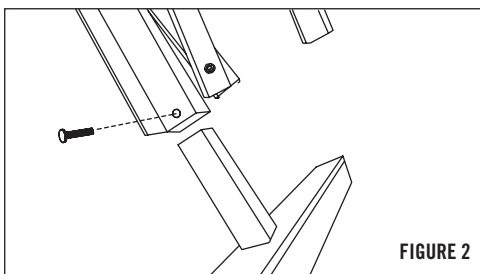

- 3) Attach casters to axle supports. Put caster through the brace and opening in the axle support and tighten with lock washer and large nut. Use a 3/4" wrench to tighten. (See Figure 3)

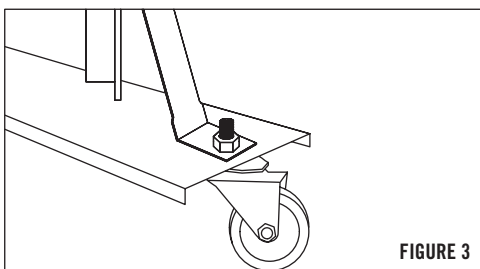


### PORTABLE ADD-ON UNIT:

Repeat steps 1-3

### TO MOVE GATE:

Collapse gate, lock axle locking bars into pins and roll to desired location. (See Figure 4)

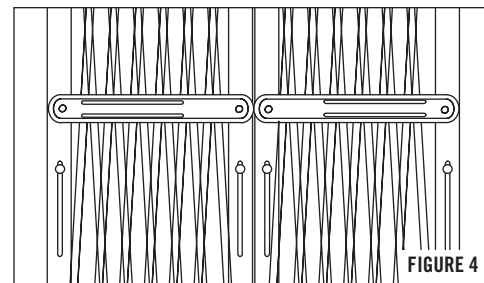

### TO MOUNT GATE:

Align padlock holes and mount wall locking bar to wall. (See Figure 5)

