




MANUAL SHUTTER

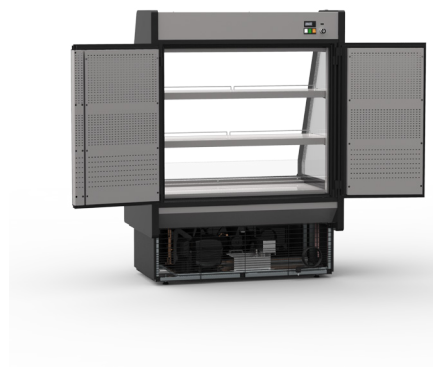

REAR LOADING

MODELS

KGL-RM-(40,60)-S

KGL-RM-(40, 60)-R

GRAB-N-GO LOW PROFILE CASE FRONT AND REAR LOADING, MANUAL SHUTTER

CASE HOLDS 38°F TO 40°F • FORCED AIR REFRIGERATION • OPEN FRONT
FRONT AND REAR LOADING • KEY OPERATED MANUAL SHUTTER



AVAILABLE WITH A BLUE DECAL
*CONTACT OUR SALES DEPARTMENT FOR MORE INFORMATION



AUTODESK®
REVIT®



GRAB-N-GO LOW PROFILE CASE FRONT AND REAR LOADING MANUAL SHUTTER

SELF CONTAINED	Model	O.A. Length (inches)	Volume FT³	Electrical 115 Volts					NEMA 115 V Plug	Weight lbs		Crate Size (inches)		
				Front	Compressor		LIGHTS Fans HTRS	EVAP Pan		Total Amps	No Crate	With Crate	L"	W"
			H.P		F.L.A									
	KGL-RM-40-S	41	12.98	5/8	8.9	2.32	6.7	16.8	5-20P	419	585	44	39	74
	KGL-RM-60-S	60.6	19.85	3/4	16	3.45	6.7	25	-	510	750	64	39	74

REMOTE	Model	O.A. Length (inches)	115 Volts Total Amps	B.T.U	Weight lbs	
					No Crate	With Crate
	KGL-RM-40-R	41	0.9	4190	361	515
	KGL-RM-60-R	60.6	1.4	5835	430	635

SPECIAL FEATURES

Locking back doors for rear loading
Manual pull-down shutter

STANDARD FEATURES



Silver colored PVC coated steel front panel with a blue decal
CFC free injected foam insulation
PVC coated steel gray interior
Black steel kick plate
Foamed polystyrene black end panels
Tempered side glass
LED lighting in canopy and under shelves
Temperature and defrost regulated by a digital controller
Slide out condensing unit on self-contained units
Removable condensate evaporating pan for easy cleaning
Product stops on all shelves
Height adjustable, shelves can be tilted
Levelling feet

OPTIONAL FEATURES

Stainless steel exterior and / or interior
Other colors available
Additional shelves
Price tag molding
Product dividers
Condensate evaporating pan for remote cases
Stainless steel legs are adjustable from 5-1/8" to 7-5/8"
KGL-RM caster kit

WARRANTY

One year parts and labor with an additional four years on the compressor (part only)

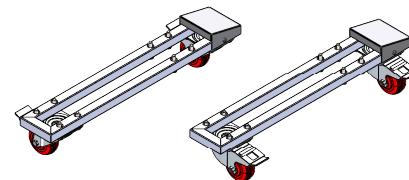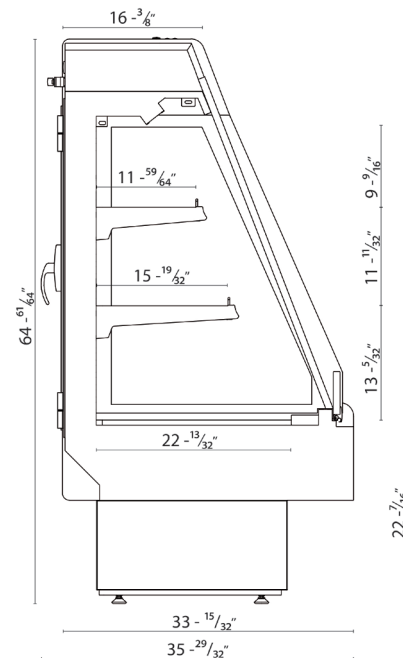

KGL-RM CASTER KIT

NOTE

These cases are engineered to operate in locations not exceeding 75°F and 55% R.H. These cases are designed to operate using R404a refrigerant. Alternate refrigerants available by special order. O.A. length includes (2) ends at 1-1/2" each. Ventilation grills at front and back cannot be blocked. B.T.U's are calculated at 14°F (evaporator) and 90°F (ambient). Remote cases are provided with an expansion valve and a liquid solenoid for pump down cycle. On remote cases, if no floor drain is provided, a condensate evaporating pan must be ordered and 6.7 amps added to the amp load. Remote cases must be hard wired – no plugs.



Tel: 786.600.4687 / Toll Free: 844.218.8477

Fax: 786.661.4100



Tel: 514.737.9701 / Toll Free: 888.275.4538

Fax: 514.342.3854 / toll free: 877.453.8832

sales@mvpgroupcorp.com / mvpgroupcorp.com

