

LEGENDVIZ[®]

Shown to increase sign legibility distance by as much as 100 percent compared to standard signs*, LegendViz[®] feature highly visible, LED-illuminated legends for improved visibility at night.

- Enhanced sign legibility without retroreflectivity or headlights
- Designed for quick and easy installation
- Legend illuminated from dusk-to-dawn
- 7+ days of solar autonomy**
- Solar or AC power options for flexible configuration
- MUTCD compliant
- Made in the USA



*According to the results of a closed-course driver trial and statistical analysis conducted by the Texas A&M Transportation Institute (TTI)

** Autonomy depends on installation specifications.


LEGENDVIZ® APPLICATIONS



LOW AMBIENT LIGHT CONDITIONS



PERPENDICULAR OR OFFSET ANGLE

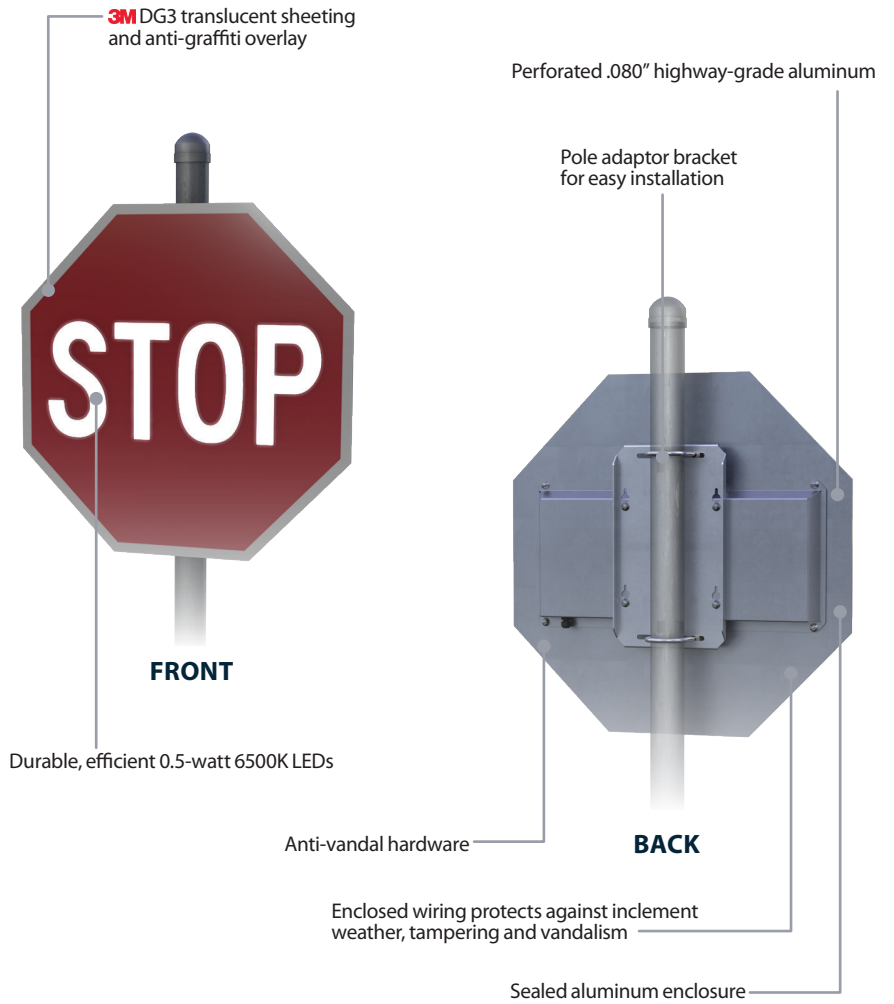

SPECIFICATIONS

POWER	6VDC - 12VDC or low voltage; current controlled through TAPCO controller
SIGN SUBSTRATE	0.080" highway-grade aluminum; perforated legend
REFLECTIVE SHEETING	3M™ translucent DG3; anti-graffiti overlay
LEGEND ILLUMINATION	Dusk-to-Dawn or vehicle-activated nighttime illumination
LED COLOR	White (6500K)
LED QUANTITY	Variable to achieve illumination uniformity
LED LIFE EXPECTANCY	50,000 hours
LED VISIBILITY	Nighttime viewable up to 500 feet Nighttime readable up to 300 feet
OFFSET LEGEND LEGIBILITY	Illuminated sign legible without retroreflectivity or headlights; legible at twice the distance of standard signs*
LED WIRING PROTECTION	Protected by sealed aluminum enclosure
MOUNTING BRACKETS	Universal mounting brackets included
SIGN DIMENSIONS	Stop (R1-1): 30" x 30", 36" x 36" (shown) Do Not Enter (R5-1): 30" x 30", 48" x 48"

* According to the results of a closed-course driver trial and statistical analysis conducted by the Texas A&M Transportation Institute (TTI).

SIGN	GLOBAL ITEM
STOP	B3137713
DO NOT ENTER	B3137745