

LEGENDVIZ[®] BLINKERSIGN[®]

Shown to increase sign legibility distance by as much as 100 percent compared to standard traffic signs*, LegendViz[®] BlinkerSigns feature highly visible, LED-illuminated legends for improved visibility at night.

- Enhanced sign legibility without retroreflectivity or headlights
- Designed for quick and easy installation
- Perimeter LEDs automatically dim based on ambient light, maintaining optimal LED output
- Legend illuminated from dusk to dawn
- 7+ days of solar autonomy **
- Solar or AC power options for flexible configuration
- MUTCD compliant
- Made in the USA



*According to the results of a closed-course driver trial and statistical analysis conducted by the Texas A&M Transportation Institute (TTI)

** Autonomy depends on installation specifications.


LEGENDVIZ® APPLICATIONS



LOW AMBIENT LIGHT CONDITIONS



PERPENDICULAR OR OFFSET ANGLES

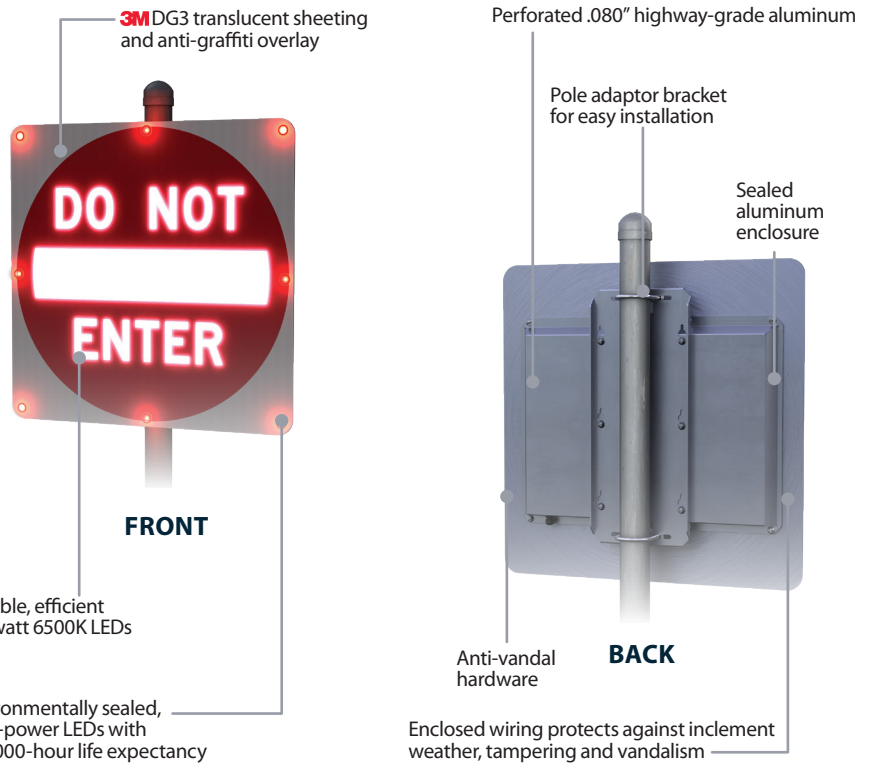

Durable, efficient
0.5-watt 6500K LEDs

Environmentally sealed,
high-power LEDs with
100,000-hour life expectancy

Enclosed wiring protects against inclement
weather, tampering and vandalism

SPECIFICATIONS

POWER	6VDC - 12VDC or low voltage; current controlled through TAPCO controller
SIGN SUBSTRATE	0.080" highway-grade aluminum; perforated legend
REFLECTIVE SHEETING	3M™ translucent DG3; anti-graffiti overlay
ILLUMINATION	Legend: Dusk-to-Dawn or vehicle-activated nighttime illumination
	Perimeter: 24/7, Dusk-to-Dawn or activated
LED COLOR	Legend: White (6500K)
	Perimeter: Red (6500K)
LED LIFE EXPECTANCY	Legend: 50,000 hours
	Perimeter: 100,000 hours
LED VISIBILITY	Legend: Nighttime viewable up to 500 feet and readable up to 300 feet
	Perimeter: Daytime viewable more than 1,000 feet and nighttime viewable more than 1 mile
OFFSET LEGEND LEGIBILITY	Illuminated sign legible without retroreflectivity or headlights; legible at twice the distance of standard signs*
PERIMETER FLASH PATTERN	Various MUTCD-compliant options dependent upon sign legend
LED WIRING PROTECTION	Legend: Protected by sealed aluminum enclosure
	Perimeter: Protected by enclosed aluminum
MOUNTING BRACKETS	Universal mounting brackets included
SIGN DIMENSIONS	Stop (R1-1): 30" x 30", 36" x 36"
	Do Not Enter (R5-1): 30" x 30", 48" x 48"

* According to the results of a closed-course driver trial and statistical analysis conducted by the Texas A&M Transportation Institute (TTI).



SIGN	GLOBAL ITEM
STOP	B3137731
DO NOT ENTER	B3137788