



FIXED SPREADER BEAMS

- Manufactured to exceed all ASME B30.20 and OSHA regulations.
- Painted safety yellow for increased visibility.
- **ALL** Spreader Beams shipped with proof load certification paperwork.
- Durable construction ideally suited to jobsite or warehouse use.
- Standard with swivel latch hooks. Top rigging not included - please call for pricing
- Made in U.S.A.
- Custom designs available - call for engineering.
- Minimum horizontal top rigging angle of 45°.

Prop 65 – See Page 100

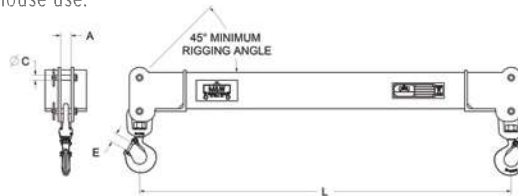

**SHOWN WITH
OPTIONAL
TOP
RIGGING**

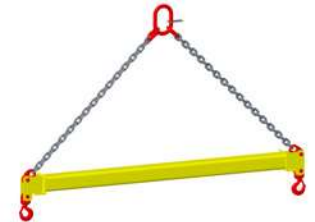

FIXED LENGTH SPREADER BEAM									
Working Load Limit in Pounds*	Model Number Headroom (in) Weight (lbs)	Outside Spread (L) in Feet*							A (in) C (in) E (in)
		4	6	8	10	12	16	20	
4,000	Part Number	13094	13097	13100	13103	13106	13109	13112	1.00 0.50 .089
	HR =	7.37	7.37	8.12	8.12	8.12	8.12	8.12	
	LBS =	55	75	95	115	135	180	218	
10,000	Part Number	13116	13119	13122	13125	13128	13131	13134	1.31 0.75 1.08
	HR =	8.23	8.98	8.98	8.98	9.98	9.98	9.98	
	LBS =	75	105	135	165	195	255	315	
20,000	Part Number	13138	13141	13144	13147	13150	13153	13156	1.66 1.00 1.31
	HR =	9.25	11.00	11.00	11.00	11.00	12.00	12.00	
	LBS =	125	165	210	255	300	385	475	

OPTIONAL TOP RIGGING								
Working Load Limit in Pounds*	Part Name	Part Number	Part Number	Part Number	Part Number	Part Number	Part Number	Part Number
4,000	Fixed Spreader	13094	13097	13100	13103	13106	13109	13112
	Chain	23354	23354	23355	23355	23356	23357	23357
	Wire Rope	23396	23396	23397	23397	23398	23399	23399
	Round Sling Bridle	23374	23374	23375	23375	23376	23377	23377
10,000	Fixed Spreader	13116	13119	13122	13125	13128	13131	13134
	Chain	23378	23378	23379	23379	23380	23381	23381
	Wire Rope	23400	23400	23401	23401	23402	23403	23403
	Round Sling Bridle	23382	23382	23383	23383	23384	23385	23385
20,000	Fixed Spreader	13138	13141	13144	13147	13150	13153	13156
	Chain	23386	23386	23387	23387	23388	23389	23389
	Wire Rope	23404	23404	23405	23405	23406	23407	23407
	Round Sling Bridle	23390	23390	23391	23391	23392	23393	23393