
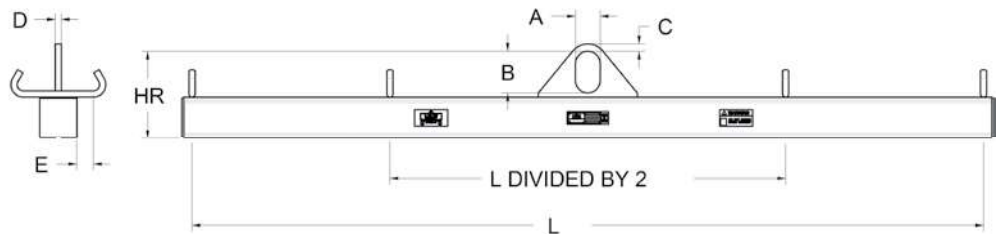


BASKET LIFTING BEAM

- Manufactured to exceed all ASME B30.20 and OSHA regulations.
- Painted safety yellow for increased visibility.
- **ALL** Lifting Beams proof loaded and shipped with certification paperwork.
- Durable construction ideally suited to jobsite or warehouse use.
- Designed to be used with lifting slings in a basket hitch
- Two sets of lifting sling hooks are standard
- Hooks designed for 2" eye width
- Custom configurations available - call for ordering assistance
- Made in U.S.A.
- Custom designs available - call for engineering.
- **ALL** lifting equipment individually proof loaded per OSHA requirements.
- All dimensions in inches unless otherwise noted.

 Prop 65 – See Page 100

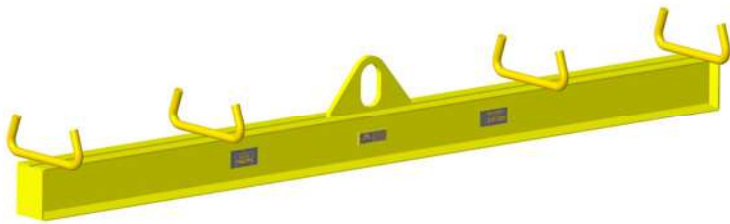

Working Load Limit in Pounds*	Model Number Headroom (in) Weight (lbs)	Outside Spread (L) in Feet*							A (in) B (in) E (in)
		4	6	8	10	12	14	16	
1,000	Part Number	17492	17493	17494	17495	17496	17497	17498	3.0 5.0 2.0
	HR =	9.50	9.50	9.50	9.50	9.50	9.50	10.50	
	LBS =	65	80	100	120	205	235	315	
2,000	Part Number	17499	17500	17501	17502	17503	17504	17505	3.0 5.0 2.0
	HR =	9.50	9.50	10.50	10.50	10.50	11.50	11.50	
	LBS =	65	80	175	210	245	325	370	
4,000	Part Number	17506	17507	17514	17508	17509	17510	17511	3.0 5.0 2.0
	HR =	10.50	10.50	11.50	11.50	12.50	13.50	13.50	
	LBS =	110	150	210	310	340	580	660	
10,000	Part Number	17512	17513	17514	17515	17516	17517	16574	3.0 5.0 2.0
	HR =	16.37	16.37	16.37	17.37	17.37	17.37	17.37	
	LBS =	260	340	425	510	720	965	1,090	

* Call for specifications on larger sizes and capacities