


LIFTING HOOKS : ALLOY STEEL J-HOOKS EYE STYLE 9

- +4% on dimensions.
 - Custom designs available - call for engineering.
 - **All eyes welded unless otherwise specified.**
 - Manufactured to exceed all ASME B30.20 and OSHA regulations.
 - Corrosion resistant finish.
- Durable construction ideally suited to jobsite or warehouse use.
 - Made in U.S.A.
 - **Maximum use temperature is 400° F.**
- ⚠ Prop 65 – See Page 100

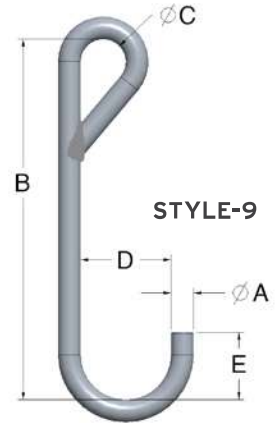

Material Diameter in Inches*	Part Number C = D = E =	Standard Alloy Style 9 Steel J-Hooks - B (length)							
		5"	6"	7"	8"	9"	10"	12"	14"
1/4 WLL= 100 Pounds	Part Number C = D = E =	19475-5 1.00 1.25 0.87	19475-6 1.00 1.25 0.87	19475-7 1.00 1.25 0.87	19475-8 1.00 1.25 0.87	19475-9 1.00 1.25 0.87	19475-10 1.00 1.25 0.87	19475-12 1.00 1.25 0.87	19475-14 1.00 1.25 0.87
5/16 WLL= 250 Pounds	Part Number C = D = E =	19476-5 1.00 1.25 0.87	19476-6 1.00 1.25 0.87	19476-7 1.00 1.25 0.87	19476-8 1.00 1.25 0.87	19476-9 1.00 1.25 0.87	19476-10 1.00 1.25 0.87	19476-12 1.00 1.25 0.87	19476-14 1.00 1.25 0.87
3/8 WLL= 365 Pounds	Part Number C = D = E =	19477-5 1.00 1.50 1.12	19477-6 1.00 1.50 1.12	19477-7 1.00 1.50 1.12	19477-8 1.00 1.50 1.12	19477-9 1.00 1.50 1.12	19477-10 1.00 1.50 1.12	19477-12 1.00 1.50 1.12	19477-14 1.00 1.50 1.12
1/2 WLL= 650 Pounds	Part Number C = D = E =	19478-5 1.00 2.00 1.50	19478-6 1.00 2.00 1.50	19478-7 1.00 2.00 1.50	19478-8 1.00 2.00 1.50	19478-9 1.00 2.00 1.50	19478-10 1.00 2.00 1.50	19478-12 1.00 2.00 1.50	19478-14 1.00 2.00 1.50
5/8 WLL= 1,000 Pounds	Part Number C = D = E =	19479-5 1.00 2.50 1.87	19479-6 1.00 2.50 1.87	19479-7 1.00 2.50 1.87	19479-8 1.00 2.50 1.87	19479-9 1.00 2.50 1.87	19479-10 1.00 2.50 1.87	19479-12 1.00 2.50 1.87	19479-14 1.00 2.50 1.87
3/4 WLL= 1,450 Pounds	Part Number C = D = E =		19480-6 1.00 3.00 2.25	19480-7 1.00 3.00 2.25	19480-8 1.00 3.00 2.25	19480-9 1.00 3.00 2.25	19480-10 1.00 3.00 2.25	19480-12 1.00 3.00 2.25	19480-14 1.00 3.00 2.25
7/8 WLL= 1,900 Pounds	Part Number C = D = E =				19481-8 1.00 3.50 2.62	19481-9 1.00 3.50 2.62	19481-10 1.00 3.50 2.62	19481-12 1.00 3.50 2.62	19481-14 1.00 3.50 2.62
1" WLL= 2,600 Pounds	Part Number C = D = E =						19482-10 1.25 4.00 3.00	19482-12 1.25 4.00 3.00	19482-14 1.25 4.00 3.00

*Larger capacities and custom configurations available. Please call for ordering assistance.