

LIFTING HOOKS

Alloy Steel J-Hooks


Eye Style A



LIFTING HOOKS : ALLOY STEEL J-HOOKS EYE STYLE A

- +4% on dimensions.
- Custom designs available - call for engineering.
- **All eyes welded unless otherwise specified.**
- Manufactured to exceed all ASME B30.20 and OSHA regulations.
- Corrosion resistant finish.
- Durable construction ideally suited to jobsite or warehouse use.
- Made in U.S.A.
- **Maximum use temperature is 400° F.**

Prop 65 – See Page 100

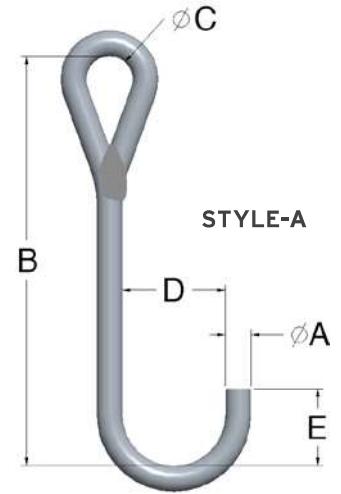

Material Diameter in Inches*	Part Number C = D = E =	Standard Alloy Style A Steel J-Hooks - B (length)							
		5"	6"	7"	8"	9"	10"	12"	14"
1/4 WLL= 100 Pounds	Part Number C = D = E =	11621-5 1.00 1.25 0.87	11621-6 1.00 1.25 0.87	11621-7 1.00 1.25 0.87	11621-8 1.00 1.25 0.87	11621-9 1.00 1.25 0.87	11621-10 1.00 1.25 0.87	11621-12 1.00 1.25 0.87	11621-14 1.00 1.25 0.87
5/16 WLL= 250 Pounds	Part Number C = D = E =	11622-5 1.00 1.25 0.87	11622-6 1.00 1.25 0.87	11622-7 1.00 1.25 0.87	11622-8 1.00 1.25 0.87	11622-9 1.00 1.25 0.87	11622-10 1.00 1.25 0.87	11622-12 1.00 1.25 0.87	11622-14 1.00 1.25 0.87
3/8 WLL= 365 Pounds	Part Number C = D = E =	11623-5 1.00 1.50 1.12	11623-6 1.00 1.50 1.12	11623-7 1.00 1.50 1.12	11623-8 1.00 1.50 1.12	11623-9 1.00 1.50 1.12	11623-10 1.00 1.50 1.12	11623-12 1.00 1.50 1.12	11623-14 1.00 1.50 1.12
1/2 WLL= 650 Pounds	Part Number C = D = E =	11624-5 1.00 2.00 1.50	11624-6 1.00 2.00 1.50	11624-7 1.00 2.00 1.50	11624-8 1.00 2.00 1.50	11624-9 1.00 2.00 1.50	11624-10 1.00 2.00 1.50	11624-12 1.00 2.00 1.50	11624-14 1.00 2.00 1.50
5/8 WLL= 1,000 Pounds	Part Number C = D = E =	11625-5 1.00 2.50 1.87	11625-6 1.00 2.50 1.87	11625-7 1.00 2.50 1.87	11625-8 1.00 2.50 1.87	11625-9 1.00 2.50 1.87	11625-10 1.00 2.50 1.87	11625-12 1.00 2.50 1.87	11625-14 1.00 2.50 1.87
3/4 WLL= 1,450 Pounds	Part Number C = D = E =		11626-6 1.00 3.00 2.25	11626-7 1.00 3.00 2.25	11626-8 1.00 3.00 2.25	11626-9 1.00 3.00 2.25	11626-10 1.00 3.00 2.25	11626-12 1.00 3.00 2.25	11626-14 1.00 3.00 2.25
7/8 WLL= 1,900 Pounds	Part Number C = D = E =				11627-8 1.00 3.50 2.62	11627-9 1.00 3.50 2.62	11627-10 1.00 3.50 2.62	11627-12 1.00 3.50 2.62	11627-14 1.00 3.50 2.62
1" WLL= 2,600 Pounds	Part Number C = D = E =						11628-10 1.25 4.00 3.00	11628-12 1.25 4.00 3.00	11628-14 1.25 4.00 3.00

*Larger capacities and custom configurations available. Please call for ordering assistance.