


FIXED ROLL LIFTING BEAMS


- Manufactured to exceed all ASME B30.20 and OSHA regulations.
- Painted safety yellow for increased visibility.
- **ALL** Lifting Beams proof loaded and shipped with certification paperwork.
- Durable construction ideally suited to jobsite or warehouse use.
- Made in U.S.A.
- Custom designs available - call for engineering.
- **ALL** lifting equipment individually proof loaded per OSHA requirements.
- Beams supplied standard with alloy swivel latch hook connections.

 Prop 65 – See Page 100




Working Load Limit	Part Number	Max Roll Diameter	Max Arbor Diameter	Inside Length	Weight
2,000	20715	36	3	50	75
2,000	20716	36	3	74	105
4,000	20717	36	3	50	115
4,000	20718	36	3	74	154

* Call for specifications on larger sizes and capacities

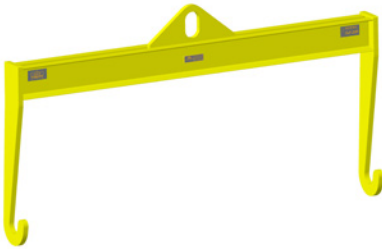

Working Load Limit	Part Number	Max Roll Diameter	Max Arbor Diameter	Inside Length	Weight
6,000	20721	36	3	50	200
6,000	20722	36	3	74	245
10,000	20719	36	3	50	370
10,000	20720	36	3	74	450

* Call for specifications on larger sizes and capacities

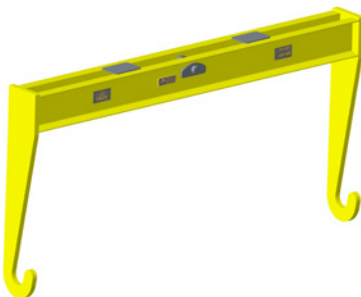

Working Load Limit	Part Number	Max Roll Diameter	Max Arbor Diameter	Inside Length	Weight
6,000	20756	36	3	50	205
6,000	20755	36	3	74	255
10,000	20754	36	3	50	360
10,000	20753	36	3	74	440

* Call for specifications on larger sizes and capacities