


Size (Inches) Nominal W x H x D	Size (Inches) Actual W x H x D	Koch Part Number	Capacity (CFM)	Initial Resistance (Inches W.G.)	Media Area (Sq. Ft.)
12 x 24 x 4	11-3/8x23-3/8x3-3/4	102-380-023	1000	0.20	9.9
16 x 20 x 4	15-1/2x19-1/2x3-3/4	102-380-025	1111	0.20	11.4
16 x 24 x 4	15-3/8x23-3/8x3-3/4	102-114-005	1389	0.20	13.6
16 x 25 x 4	15-1/2x24-1/2x3-3/4	102-380-026	1400	0.20	14.2
18 x 24 x 4	17-1/2x23-3/8x3-3/4	102-380-027	1500	0.20	16.1
20 x 20 x 4	19-1/2x19-1/2x3-3/4	102-380-028	1389	0.20	14.4
20 x 24 x 4	19-1/2x23-3/8x3-3/4	102-380-029	1667	0.20	17.3
20 x 25 x 4	19-1/2x24-1/2x3-3/4	102-380-030	1736	0.20	18.1
24 x 24 x 4	23-3/8x23-3/8x3-3/4	102-380-031	2000	0.20	21.0

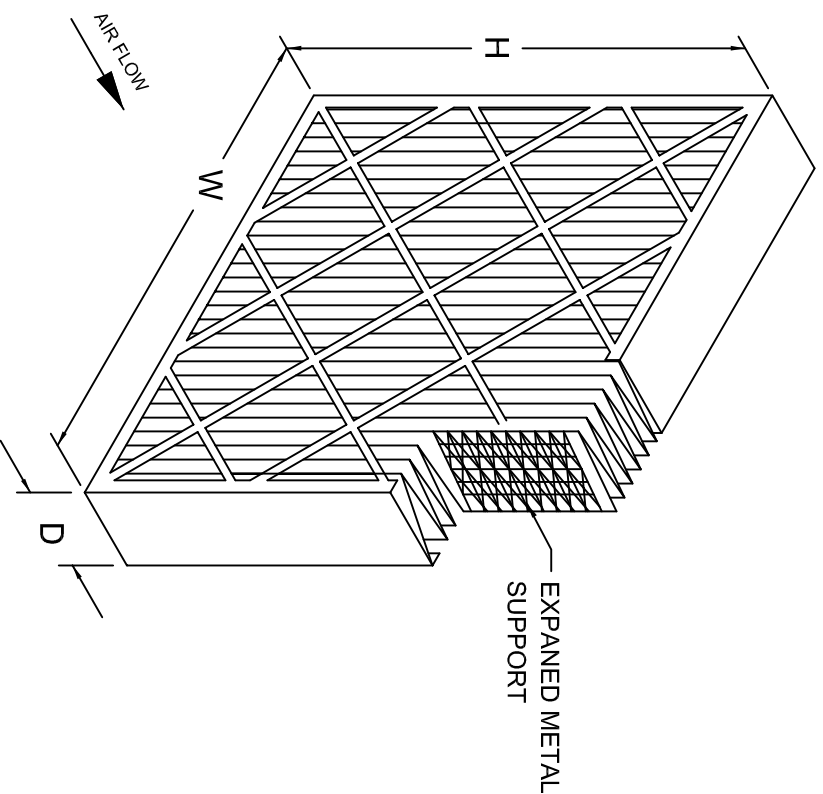

Standard Construction:

1. New White 100% Synthetic Media
2. Rust Resistant Expanded Metal Support on Downstream Side
3. Moisture Resistant Beverage Board Frame (24 point)
4. Double Wall Frame
5. 9 Pleats per Linear Ft.

Specifications:

1. Efficiency: MERV 10 (ASHRAE Standard 52.2-2017)
2. Final Resistance: 1.0" W.G.
3. Rated Velocity: 500 FPM
4. Classified per UL Standard 900
5. Max Operating Temp: 200F (93 C)
6. Tolerance: Height & Width - +/- 1/8"
7. Tolerance: Depth - +/- 1/16"

KOCHFILTER
PURE PERFORMANCE

Multi-Pleat XL 10
4" Standard Capacity

8401 Air Commerce Drive - Louisville KY 40219
Phone: (502) 634-4796 FAX: (502) 637-2280

Drawn By: B. Chamberlain
Date: April 08, 2021

Revision

REV
LTR

REVISION

BY /
DATE