

SYNERGY.5

Manual Stretch Wrap System

The Synergy .5 Spiral is the affordable solution to stretch wrap your loads without stretching your budget. The Synergy .5 delivers the same high quality and high performance that Highlight is famous for, at an affordable price.

The Synergy .5 offers the flexibility to precisely adjust the level of film stretch to match your load-holding requirements. Stretch levels of up to 60% are typical for the Synergy .5. The Synergy .5 will stretch film further, wrap loads tighter and more securely, at a lower price than any system in it's price range.



Low Profile shown
High Profile available

HIGHLIGHTS

- » Powered turntable and counterweighted carriage reduce stress and injuries
- » Sturdy mast and Stretch-Set™ features allow for tighter wrapping, more secure loads, and less product damage on the road
- » Save wrapping time with the 12 RPM powered turntable




SIMPLE CONTROLS

- Turntable dial adjusts from 0 to 12 RPM
- ON/OFF Footswitch controls turntable rotation
- Film stretch and tension set using adjustment knob

SYSTEM SPECIFICATIONS

Stretch-Set™	Adjustable 20% to 100%	Load Weight Capacity	Low & High Profile 4,000 pounds
Turntable	Low Profile 59" Diameter, 12 RPM High Profile 48"x48" Octagonal, 12 RPM	Turntable Drive Motor	1/2 HP AC
Wrap Height	Low Profile up to 80" High Profile up to 70"	Electrical Requirements	120 Volts, 15 Amp
Film Carriage	Manual, Counterweighted	Machine Weight	Low Profile 1,000 Pounds High Profile 800 Pounds
Film Capacity	6.5" Roll Diameter, 12"-18" Roll Width	Options	Attachable ramp is optional in Low Profile Only

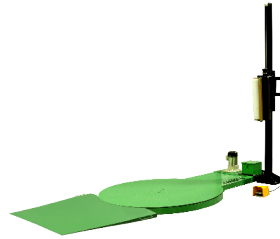

Optional Ramp

Optional ramp locks in at any position 180 degrees around the turntable for easy hand pallet jack loading.



Lift Carriage

Counterbalanced lift carriage for minimal lift effort.



Stretch-Set

Uses Highlight's patented Stretch-Set™ tension system to maximize film stretch with the turn of a knob.



High or Low Profile

Highlight will build the correct system for your application. The Synergy .5 is available in either High or Low Profile. The High Profile can be easily loaded with a fork lift. The Low Profile can use an optional ramp for loading with hand pallet jacks.



Film Capacity

Accepts 12" to 18" handwrap roll with up to a 6.5" diameter. Designed for use with common hand film dimensions for easy machine transitions.

Contact: