


HEAVY DUTY MANUAL TURNTABLE SURVEY SHEET

Inquiry Date: _____ Due Date: _____
 Contact: _____
 Company: _____
 Phone: _____
 Fax: _____
 E-mail: _____


PLEASE SELECT ONE OF THE STYLES LISTED:

TYPE A ____ TYPE E ____
 TYPE B ____ TYPE F ____
 TYPE C ____ TYPE G ____
 TYPE D ____


- TYPES (D) AND (F) FEATURE A STATIONARY SHELF FOR STORING PARTS AND TOOLS
- TYPES (A) AND (B) DO NOT FEATURE HEIGHT ADJUSTMENT
- TYPES (C), (D), AND (G) FEATURE TURN-KNOB HEIGHT ADJUSTMENT
- TYPES (E) & (F) FEATURE GAS CYLINDER HEIGHT ADJUSTMENT

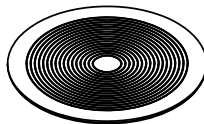


TYPE A

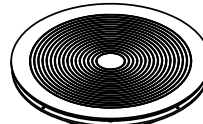

TYPE B

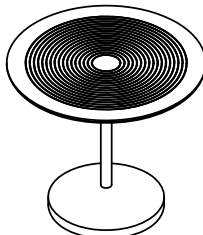

TYPE C

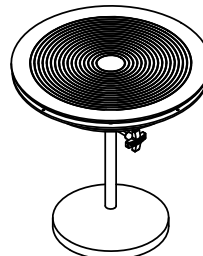


TYPE D



TYPE E



TYPE F

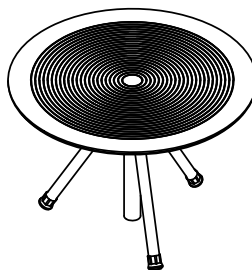

TYPE G

AVAILABLE TURNTABLE DIAMETERS:

Ø18" ____
 Ø24" ____
 Ø30" ____

LOWERED HEIGHT: _____

RAISED HEIGHT: _____

Application/General Information:

Additional Requirements:

Quote options:

_____ Exactly as specified _____ Cheapest / Closest to Vestil standard
 _____ Quickest to ship
 Requested Delivery Date: _____

*All options may not be available on all models

Vestil Manufacturing Company * Angola, IN 46703 * Ph- 260-665-7586 * Fx- 260-665-1339