


# CROWDCADE™ & CROWDCADE™ DELUXE

## Crowd Control Parade Barricades

THE  
ULTIMATE!  
GREAT FOR  
RENTING

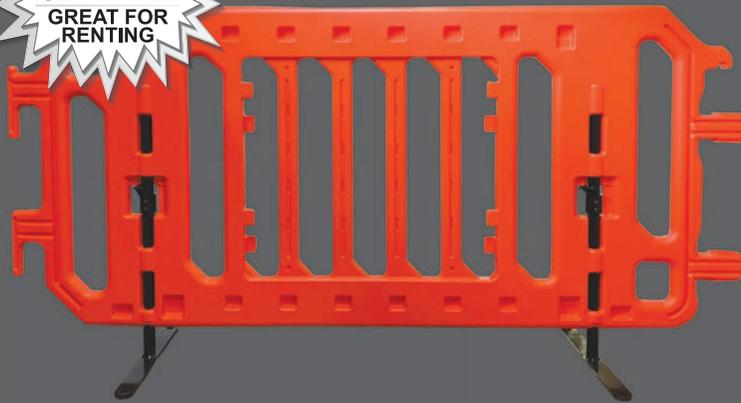

### Crowdcade™ Deluxe

Deluxe 7' thick walled, plastic barricade with steel legs and feet

- Sturdy and extra durable - Feels as solid as steel, but won't rust
  - 50% thicker double wall panel, prevents warping or bending
- Superior stability, stands up to large crowds
  - steel legs are integrated with barricade panel, preventing tip-over
- Anti-trip, flat steel feet are securely welded to steel legs
  - powder coated finish
- Feet rotate and lock for compact stacking
  - molded-in lugs keep units from sliding when stacked
- Tamper resistant locking hooks create strong connections
  - prevent in-line barricades from being pulled apart
- Double locking hooks accommodate various configurations
  - units pivot on hooks and adjust to uneven ground
- Unique Quick-Change™ system makes it easy to insert signs, 29.5" x 26"
  - signs held in by stay tabs™ on both sides of barricade
  - holes for bolting signs if required
- Available in orange and white
  - custom colors with minimum order quantity



### Crowdcade™

6' durable plastic barricade with strong plastic legs and rubber feet

- Sturdy, and durable - thick, double wall panel
- Feet won't break off from panel
  - stable, recycled rubber feet, securely attached to panel
- Easy stacking, no tangling of feet
  - feet rotate flat for stacking
  - molded-in lugs keep units from sliding when stacked
- Tamper resistant linking bracket
  - prevent in-line barricades from being pulled apart
- Linking bracket accommodates various configurations
  - units pivot on bracket and adjust to uneven ground
- Holes for bolting on signs (one side)
- Panels on both sides for retroreflective sheeting
- Available in orange and white
  - custom colors with minimum order quantity



Steel, Anti-trip feet

Crowdcade™ Deluxe with Quick-Change™, holds two 29.5" x 26" signs just slide signs in...



Crowdcade™ Panels on both sides for sheeting


Holes for sign to be affixed

**PLASTICADE®**

Plasticade.com

TF045 Rev. 1

# CROWDCADE™


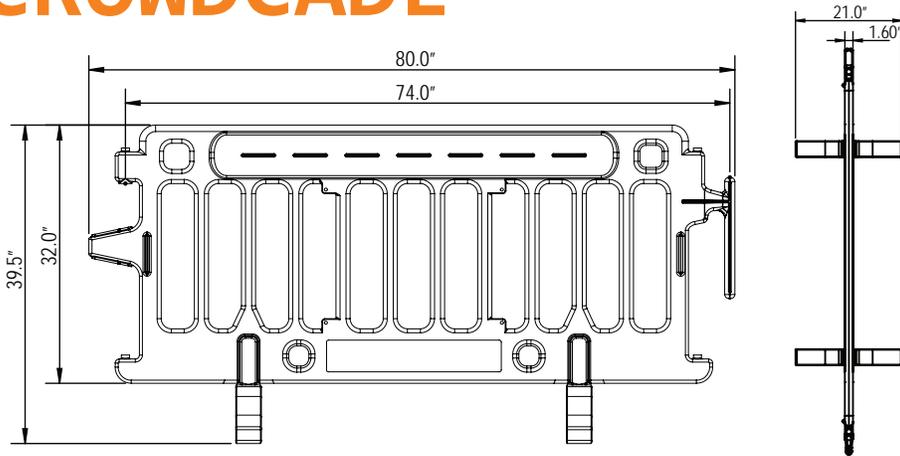


connected unlocked

connected locked

feet rotate for stacking

# CROWDCADE™ DELUXE

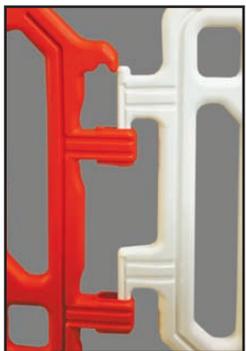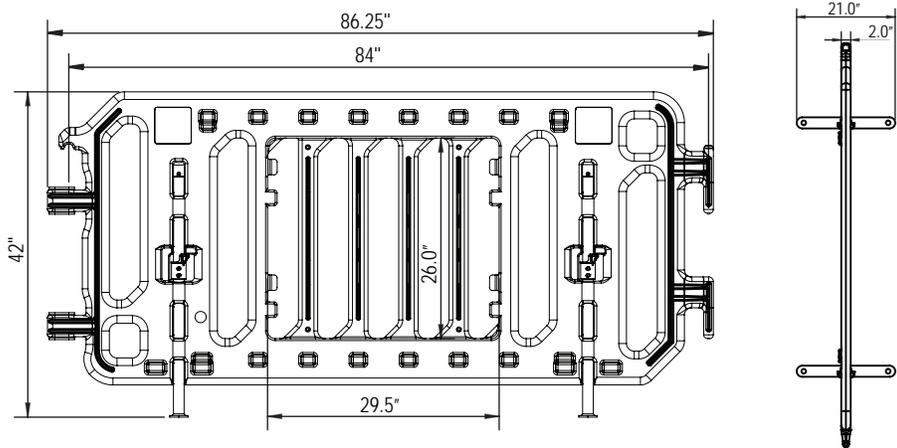

connected

connected locked

feet rotate and lock for stacking

To lock feet, rotate foot and push down on top of barricade.  
To release lock, stand on foot and pull up barricade.

**PLASTICADE®**

100 Howard Avenue  
Des Plaines, IL 60018  
phone (800) 772-0355  
fax (847) 966-8074

[Plasticade.com](http://Plasticade.com)

patent pending on  
Crowdcade™ Deluxe

## Specs: Crowdcade™

|                          |  |
|--------------------------|--|
| Composition              | Polyethylene   |
| Weight                   | 32 lbs. with feet<br>Feet weigh 9.5 lbs. ea.                         |
| Length                   | 74"  |
| Height                   | 39.5"  |
| Connected length         | 6'   |
| Colors                   | Orange & White   |
| Sheeting Area            | 5.5" x 51"   |
| Retroreflective Sheeting | Striped sheeting in engineer grade or high intensity prismatic grade |
| Sign size                | 24"W x 18"H or larger  |

## Specs: Crowdcade™ Deluxe

|                  |   |
|------------------|---|
| Composition      | Polyethylene  |
| Weight           | 35 lbs. with feet<br>Feet weigh 5 lbs. ea.  |
| Length           | 86.25"  |
| Height           | 42"   |
| Connected length | 7'  |
| Sign Insert Size | 29.5" W x 26" H<br>4 mm (3/16" thick)<br>corrugated plastic sign material recommended |
| Colors           | Orange & White  |