

SPEED BUMPS, SPEED HUMPS & CAR STOPS

PLASTICADE®

Plasticade.com

- Resistant to weather, oil, salt, moisture, UV light, and temperature
- Will not warp, chip, or crack
- Never needs painting, durable striping
 - molded-in reflective marking tape
- Flexible, conforms to surface contours
- Easy one person installation
 - install on asphalt or concrete (hardware sold separately)
- Removable for road surface maintenance or snow plowing
- 100% post-consumer recycled rubber with polyurethane binder

SPEED BUMPS



End Caps are optional

Standard Speed Bumps

- 6' & 4' sections
- Available with or without yellow reflective stripes
- Use in moderate traffic areas
- For traffic speeds 10 mph or less
- Cut with a utility knife if necessary
- Optional cat eye reflectors
- Dual bottom channels for drainage



Premium Textured Speed Bumps

- 6' sections
- Use in heavy traffic areas
- Textured, vulcanized rubber performs well in extreme temperatures
- For traffic speeds 10 mph or less
- Cat eye reflectors included for increased visibility at night
- 5 synthetic rubber yellow stripes, (EPDM) won't degrade
- Dual bottom channels for drainage
 - protects wire, hose, or pipe to 3/4" dia.
- Optional end caps sold separately



Comes with 8 Cat Eye Reflectors

SPEED HUMPS



Standard Speed Humps

- Available in 24" sections
- For traffic speeds 15 mph or less
- Gentler than speed bumps
 - good for heavy truck traffic areas
- Reflective stripes in yellow
- Dual bottom channels for drainage
 - protects wire, hose, or pipe to 3/4" dia.



Premium Textured Speed Humps

- Available in 20" sections
- Use in heavy traffic areas
- Grooved surface helps with traction
- 8 rectangular yellow stripes per section

CAR STOPS



- 3', 4', & 6' lengths
- Use in parking lots and garages
 - protects garage walls, delineates spaces
- Available with and without reflective stripes
- Yellow or white reflective stripes



SPEED BUMPS, SPEED HUMPS & CAR STOPS

SPEED BUMPS



Standard End Cap



Premium End Cap




Channels for drainage or protect wire, hose, or pipe to 3/4" dia.



Back View


SPEED HUMPS

Standard Speed Hump

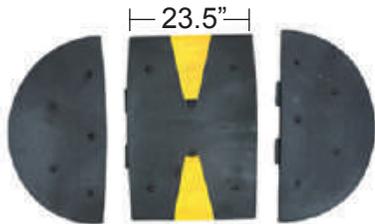

Female End Cap Center Section Male End Cap

Premium Speed Hump

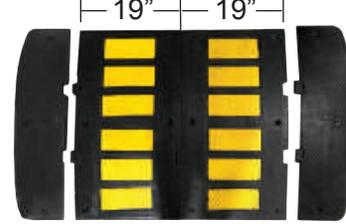

Female End Cap Center Sections Male End Cap

Channels for drainage or protect wire, hose, or pipe to 3/4" dia.



Back View of Standard Speed Hump



Back View of Premium Speed Hump

CAR STOPS



Back View



Installation Hardware



- Concrete
 - 4 1/2" Lag Bolt with Washer & Shield for Speed Bumps & Speed Humps
 - 6" Lag Bolt with Washer & Shield for Car Stops
- Asphalt
 - 14" Rebar Spike with Washer
- Epoxy can be used in addition to or as a replacement for the hardware in certain applications. See the installation instructions on our website.

Standard Speed Bump

Dimensions	72"L x 12"W x 2.6"H, 52 lbs. 48"L x 12"W x 2.6"H, 35 lbs.
End Caps	12"L x 12"W x 2.6"H, 3.5 lbs.
Stripes	72" - 3 yellow stripes 48" - 2 yellow stripes
Cat Eyes	72" - 8 48" - 6
Installation Holes	72" - 4 48" - 3 End Cap - 2

Premium Speed Bump

Dimensions	72"L x 12"W x 2"H, 52 lbs.
End Caps	12"L x 6"W x 2"H, 3.5 lbs.
Stripes	5
Cat Eyes	8
Installation Holes	4 End Cap - 1

Standard Speed Hump

Dimensions	24"L x 36"W x 2.4"H, 52 lbs. connected length - 23.5"
End Caps	17.5"W x 36"W x 2.4"H, 23 lbs.
Stripes	2 per center section
Installation Holes	Center Section - 6 End Cap - 5

Premium Speed Hump

Dimensions	20"L x 35"W x 2"H, 38 lbs. connected length - 19"
End Caps	10"L x 35"D x 2"H, 14 lbs.
Stripes	6 per center section
Installation Holes	Center Section - 6 End Cap - 3

Car Stops

Dimensions	72"L x 6"W x 4.5"H, 40 lbs. 48"L x 6"W x 4.5"H, 30 lbs. 36"L x 6"W x 4.5"H, 20 lbs.
Stripes	White or Yellow 72" - 4 on each side of stop 48" & 36" - 2 on each side
Installation Holes	72" - 4 holes, 48" - 3 holes, 36" - 2 holes

PLASTICADE®

100 Howard Avenue
Des Plaines, IL 60018
phone (800) 772-0355
info@plasticade.com

Plasticade.com

MADE IN THE USA