

# Janitorial and Sanitation Collection

**Remco**  
a Vikan company

Hygienic | Sanitary | Safe



Remco provides durable, ergonomic and easy-to-clean tools for areas where hygiene and safety are critical. Designed from the bottom-up to suit the needs of the most intense sanitation standards, our shovels, scoops, and scrapers are suited for janitorial work in office buildings, schools and homes. Along with our tools, Remco features Vikan's advanced line of brushes, brooms, and squeegees. Regardless of your operation's size or complexity, Remco has the tools and expertise to solve your janitorial and sanitation needs.

# Janitorial and Sanitation Tools

Available from Remco

For over a century, Vikan® has focused on developing the most durable and effective cleaning tools in the world. With Vikan's product development emphasis on efficiency, functionality, and ergonomics, sanitation professionals have access to tools that are precisely suited to the most complex cleaning tasks.

Remco and Vikan provide total-color products to fit the most stringent sanitation standards. Our tools come in a range of 12 colors, making them ideal for integration with color-coded plans.

Our tools are also made from durable, high-quality materials, including polypropylene and stainless steel, and they are also easy to keep clean, since they don't have crevices or sharp angles. When the highest sanitation levels are required, you can trust Remco to have the products you need.



**Vikan®** Short Handle Scrubbing Brush 4192x

STIFF  
FDA  
Autoclavable  
Dishwasher Safe



Colors Available: 1 2 3 4 5 6 7 8 9 10 11 12

|                      |                            |         |
|----------------------|----------------------------|---------|
| Length:              | Width:                     | Height: |
| 9.8"                 | 2.6"                       | 2.6"    |
| Weight:              | 0.44 lbs.                  |         |
| Maximum Temperature: | 250°F                      |         |
| Material:            | Polypropylene/Polyester/SS |         |

**Vikan®** Long Handle Scrubbing Brush 4186x

STIFF  
FDA  
Autoclavable  
Dishwasher Safe



Colors Available: 1 2 3 4 5 6 7 8 9 10 11 12

|                      |                            |         |
|----------------------|----------------------------|---------|
| Length:              | Width:                     | Height: |
| 15.75"               | 2.75"                      | 2.8"    |
| Weight:              | 0.53 lbs.                  |         |
| Maximum Temperature: | 250°F                      |         |
| Material:            | Polypropylene/Polyester/SS |         |

**Vikan®** Large Hand Brush 3890x

STIFF  
FDA  
Autoclavable  
Dishwasher Safe



Colors Available: 1 2 3 4 5 6 7 8 9 10 11 12

|                      |                            |         |
|----------------------|----------------------------|---------|
| Length:              | Width:                     | Height: |
| 7.5"                 | 2.5"                       | 2.4"    |
| Weight:              | 0.48 lbs.                  |         |
| Maximum Temperature: | 250°F                      |         |
| Material:            | Polypropylene/Polyester/SS |         |

**Vikan®** 12" Angle Broom 2914x

STIFF  
FDA  
Autoclavable  
Dishwasher Safe



Colors Available: 2 3 4 5 6 7 8 9 10 11 12

|                      |                            |         |
|----------------------|----------------------------|---------|
| Length:              | Width:                     | Height: |
| 11.8"                | 1.4"                       | 10.6"   |
| Weight:              | 1.01 lbs.                  |         |
| Maximum Temperature: | 250°F                      |         |
| Material:            | Polypropylene/Polyester/SS |         |

**Vikan®** 13" Push Broom 2915x

STIFF  
FDA  
Autoclavable  
Dishwasher Safe



Colors Available: 2 3 4 5 6 7 8 9 10 11 12

|                      |                            |         |
|----------------------|----------------------------|---------|
| Length:              | Width:                     | Height: |
| 13.0"                | 2.9"                       | 6.9"    |
| Weight:              | 1.68 lbs.                  |         |
| Maximum Temperature: | 250°F                      |         |
| Material:            | Polypropylene/Polyester/SS |         |

**Vikan®** 24" Combo Push Broom 3194x

SOFT/STIFF  
FDA  
Autoclavable  
Dishwasher Safe



Colors Available: 2 3 4 5 6 7 8 9 10 11 12

|                      |                            |         |
|----------------------|----------------------------|---------|
| Length:              | Width:                     | Height: |
| 24.4"                | 2.8"                       | 4.5"    |
| Weight:              | 1.81 lbs.                  |         |
| Maximum Temperature: | 250°F                      |         |
| Material:            | Polypropylene/Polyester/SS |         |

FDA Denotes product is made of FDA-compliant materials.

Autoclavable Denotes product is autoclavable to 250°F.

Dishwasher Safe Denotes product is dishwasher safe to 176°F.

TYPE Denotes bristle type.





**Vikan®** High-Low Brush  
7047x



Colors Available: 1 2 3 4 5 6 7 8 9 10 11 12 13 14 15 16 17 18

| Length:              | Width:                     | Height: |
|----------------------|----------------------------|---------|
| 10.4"                | 5.5"                       | 3.9"    |
| Weight:              | 1.06 lbs.                  |         |
| Maximum Temperature: | 250°F                      |         |
| Material:            | Polypropylene/Polyester/SS |         |

**Vikan®** 12" Deck Scrub  
7060x



Colors Available: 1 2 3 4 5 6 7 8 9 10 11 12 13 14 15 16 17 18

| Length:              | Width:                     | Height: |
|----------------------|----------------------------|---------|
| 11.8"                | 2.8"                       | 4.5"    |
| Weight:              | 1.32 lbs.                  |         |
| Maximum Temperature: | 250°F                      |         |
| Material:            | Polypropylene/Polyester/SS |         |

**Vikan®** UST Deck Scrub  
7064x



Colors Available: 1 2 3 4 5 6 7 8 9 10 11 12 13 14 15 16 17 18

| Length:              | Width:                  | Height: |
|----------------------|-------------------------|---------|
| 15.25"               | 1.875"                  | 3.9"    |
| Weight:              | 0.90 lbs.               |         |
| Maximum Temperature: | 250°F                   |         |
| Material:            | Polypropylene/Polyester |         |

**Vikan®** 24" Single Blade Ultra  
Hygiene Squeegee  
7160x



Colors Available: 1 2 3 4 5 6 7 8 9 10 11 12 13 14 15 16 17 18

| Length:              | Width:               | Height: |
|----------------------|----------------------|---------|
| 23.3"                | 3.4"                 | 3.7"    |
| Weight:              | 0.79 lbs.            |         |
| Maximum Temperature: | 250°F                |         |
| Material:            | Polypropylene/Rubber |         |

**Vikan®** 24" Double Blade Ultra  
Hygiene Squeegee  
7714x



Colors Available: 1 2 3 4 5 6 7 8 9 10 11 12 13 14 15 16 17 18

| Length:              | Width:               | Height: |
|----------------------|----------------------|---------|
| 23.6"                | 3.7"                 | 4.3"    |
| Weight:              | 0.84 lbs.            |         |
| Maximum Temperature: | 250°F                |         |
| Material:            | Polypropylene/Rubber |         |

**Vikan®** 28" Foam Blade  
Squeegee  
7755x



Colors Available: 2 3 4 5 6

| Length:              | Width:                    | Height: |
|----------------------|---------------------------|---------|
| 27.5"                | 3.5"                      | 3.75"   |
| Weight:              | 0.85 lbs.                 |         |
| Maximum Temperature: | 199°F                     |         |
| Material:            | Polypropylene/Foam Rubber |         |

Denotes product is made of FDA-compliant materials.

Denotes product is autoclavable to 250°F.

Denotes product is dishwasher safe to 176°F.

Denotes bristle type.

**Vikan®** 51" Aluminum Handle  
2935x



Colors Available: 1 2 3 4 5 6 7 8 9 10 11 12 13 14 15 16 17 18 19 20

|                      |                        |         |
|----------------------|------------------------|---------|
| Length:              | Width:                 | Height: |
| 51.2"                | 1.25"                  | 1.25"   |
| Weight:              | 1.08 lbs.              |         |
| Maximum Temperature: | 250°F                  |         |
| Material:            | Polypropylene/Aluminum |         |

**Vikan®** 59" Ultra Hygiene Handle  
2962x



Colors Available: 1 2 3 4 5 6 7 8 9 10 11 12 13 14 15 16 17 18 19 20

|                      |               |         |
|----------------------|---------------|---------|
| Length:              | Width:        | Height: |
| 59.1"                | 1.25"         | 1.25"   |
| Weight:              | 1.05 lbs.     |         |
| Maximum Temperature: | 250°F         |         |
| Material:            | Polypropylene |         |

**Vikan®** 62" - 113" Telescopic  
Aluminum Handle  
2975x



Colors Available: 2 3 4 5 6 9

|                      |                        |         |
|----------------------|------------------------|---------|
| Length:              | Width:                 | Height: |
| 61.8" - 112.50"      | 1.25"                  | 1.25"   |
| Weight:              | 2.14 lbs.              |         |
| Maximum Temperature: | 250°F                  |         |
| Material:            | Aluminum/Polypropylene |         |


**Vikan®** Basic Wall Bracket  
0615x



Colors Available: 2 3 4 5 6 7 9

|                      |               |         |
|----------------------|---------------|---------|
| Length:              | Width:        | Height: |
| 9.4"                 | 6.5"          | 2.25"   |
| Weight:              | 0.47 lbs.     |         |
| Maximum Temperature: | 212°F         |         |
| Material:            | Polypropylene |         |

**Vikan®** Wall Bracket, Grip  
Band Module  
1013x

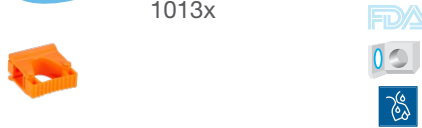

Colors Available: 1 2 3 4 5 6 7 8 9 10 11 12 13 14 15 16 17 18 19 20

|                      |                                    |         |
|----------------------|------------------------------------|---------|
| Length:              | Width:                             | Height: |
| 3.27"                | 3.43"                              | 1.89"   |
| Weight:              | 0.18 lbs.                          |         |
| Maximum Temperature: | 250°F                              |         |
| Material:            | Polypropylene/TPE Rubber/Polyamide |         |

**Vikan®** Hi-Flex Wall  
Bracket System  
1011x



Colors Available: 1 2 3 4 5 6 7 8 9 10 11 12 13 14 15 16 17 18 19 20

|                      |                                    |         |
|----------------------|------------------------------------|---------|
| Length:              | Width:                             | Height: |
| 16.54"               | 3.43"                              | 1.89"   |
| Weight:              | 0.64 lbs.                          |         |
| Maximum Temperature: | 250°F                              |         |
| Material:            | Polypropylene/TPE Rubber/Polyamide |         |

**Vikan®** Cleaning Pad Holder  
5500x



Colors Available: 2 3 4 5 6 7

|                      |                               |         |
|----------------------|-------------------------------|---------|
| Length:              | Width:                        | Height: |
| 9.0"                 | 3.6"                          | 4.7"    |
| Weight:              | 0.50 lbs.                     |         |
| Maximum Temperature: | 250°F                         |         |
| Material:            | Polypropylene/Stainless Steel |         |

**Vikan®** Handheld Cleaning  
Pad Holder  
5510x



Colors Available: 2 3 4 5 6

|                      |                               |         |
|----------------------|-------------------------------|---------|
| Length:              | Width:                        | Height: |
| 9.1"                 | 3.8"                          | 3.0"    |
| Weight:              | 0.49 lbs.                     |         |
| Maximum Temperature: | 250°F                         |         |
| Material:            | Polypropylene/Stainless Steel |         |

**Remco** Scrub Pad - Coarse  
5523



Colors Available: Brown

|           |                                     |         |
|-----------|-------------------------------------|---------|
| Length:   | Width:                              | Height: |
| 10.0"     | 4.4"                                | 0.8"    |
| Weight:   | 0.09 lbs.                           |         |
| Material: | Polyester Fibers/Abrasive Additives |         |

Denotes product is made of FDA-compliant materials.

Denotes product is autoclavable to 250°F.

Denotes product is dishwasher safe to 176°F.

Visit [GlobalIndustrial.com](http://GlobalIndustrial.com) for a full selection of products.



Web: [www.globalindustrial.com](http://www.globalindustrial.com)

Phone: 1-800-645-1232

© 2022 Remco Products 3/22 RMC-A106-GLO  
Vikan® is a registered trademark of Vikan A/S.  
Remco is Vikan's dedicated North American company.

