

Transit is a durable, anodized aluminum shelter designed to protect bikes from the elements even in extreme weather conditions. With thousands installed nationwide, the Transit style shelter has gained wide acceptance from businesses, universities, transit companies, government agencies and more.

Class 2 Bike Shelter: Canopy style

- Prefabricated in sections for quick assembly
- Hip, Gable, Barrel or Flat roof styles
- Strong, shatterproof glass wall panels
- Enclosed on 3 sides for enhanced weather protection



Transit (Hip Roof)

GENERAL INFORMATION

Frame: 6063-T52 Alloy Aluminum fabricated with Integrated Water Drainage

Finish: Anodized Dark Bronze or Clear (Silver)

Roof Styles/Materials:

HIP ROOF: 6 mm Twinwall Polycarbonate, UV Coated or Standing Seam Aluminum

GABLE ROOF: 6 mm Twinwall Polycarbonate, UV Coated or Standing Seam Aluminum

BARREL ROOF: 6 mm Twinwall Polycarbonate, UV Coated

FLAT ROOF: Omega-Ply®

Installation: Anchor securely to level, concrete pad

Wall Panels: ¼" Tempered Glass

Bike Racks: Not included


DIMENSIONS/CAPACITY*

Transit 7	Length	Width	Roof Height				Bikes (Max.)
<i>Transit 7 - Clear height 7'</i>			HIP & GABLE ROOF	BARREL ROOF	FLAT ROOF		
Transit 7-10 - Single	14' 8"	7' 5"	9' 4"	8' 10"	7' 6"	10	
Transit 7-20 - Double	29' 1"	7' 5"	9' 4"	8' 10"	7' 6"	20	
Transit 7-30 - Triple	43' 6"	7' 5"	9' 4"	8' 10"	7' 6"	30	


*Bike capacity varies with rack style

VIEWS


(Shown: Barrel Roof)

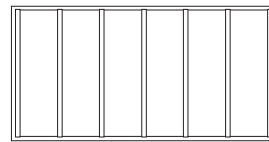


TOP

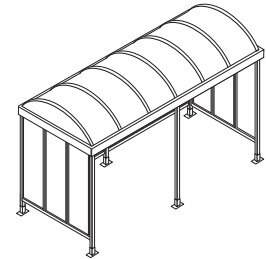

ISOMETRIC

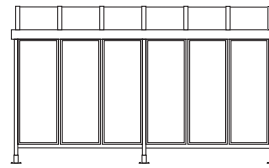

FRONT

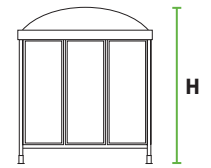

SIDE




Hip Roof



Barrel Roof



Gable Roof

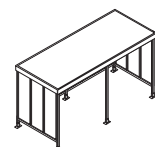

Flat Roof



velodomeselters

BIKE PARKING SOLUTIONS Bike Shelters | Bike Racks | Bike Storage Systems

888-995-8090

32 Ann Street Clifton, NJ 07013

info@velodomeselters.com

www.velodomeselters.com



Transit (Hip Roof)



Transit (Hip Roof/Standing Seam Alum.)



Transit (Barrel Roof w/ Ad Box)

OPTIONS/ACCESSORIES

- Custom Branding, Graphics and Signage
- Illuminated Ad/Graphics Box
- Solar Lighting
- Public Bike Repair Accessories
- Powder Coating in RAL or Custom Colors

FRAME FINISHES

Anodized Aluminum, 6063-T52 Alloy




Dark Bronze Clear (Silver)

Powder Coating: RAL Colors (custom colors available)

9005	9010	3001	7035	7045	5005	5003	6002	6005
Jet Black	Pure White	Signal Red	Light Grey	Telegrey 1	Signal Blue	Sapphire Blue	Leaf Green	Moss Green

WALL PANELS

¼" Tempered Glass, Clear

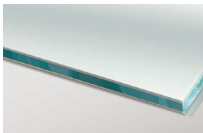


Tempered glass is stronger and safer than regular glass. It is also shatterproof.

ROOF




6mm Twinwall Polycarbonate, UV Coated / Roof: **HIP | GABLE | BARREL**

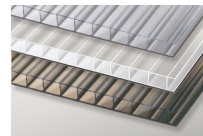

Translucent sheets with ribbed core. Impact resistant and light weight.

Clear (80% Light Transmission)
White (45% Light Transmission)
Bronze Tint (45% Light Transmission)

Standing Seam Aluminum / Roof: **HIP | GABLE**

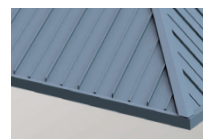

Finished aluminum panels with ribbed profile are exceptionally durable, rustproof, fade resistant and easy to maintain. Colors available.

Omega-Ply® / Roof: **FLAT**



Aluminum clad plywood panels. Strong, rigid and impact resistant, rustproof, fade resistant and easy to maintain. Colors available.

Black (standard)