

Peapod Mini is a fully enclosed and locking bike shelter that holds 10 bikes in a compact footprint. Fabricated in heavy-duty, anodized aluminum with shatterproof glass wall panels, Peapod Mini protects bikes from the elements and deters theft.

Class 1 Bike Shelter: Fully enclosed, locking, weatherproof

Also available: **Peapod Mini Bike Cage**

- Slim profile– 10 bike unit fits in 1 parking space
- Prefabricated in sections for quick assembly
- Barrel, Hip or Flat roof styles
- Glass or Bike Cage (wire mesh) versions



Peapod Mini (Hip Roof)

GENERAL INFORMATION

Frame: 6063-T52 Alloy Aluminum fabricated with Integrated Water Drainage

Finish: Anodized Dark Bronze or Clear (Silver)

Wall Panels: ¼" Tempered Glass (Standard) or ⅜" Stainless Steel Wire Mesh, Welded, 2" Sq. Grid (Bike Cage)

Door: 42" Wide, ¼" Tempered Glass, Hydraulic Closer

Roof Styles/Materials:

BARREL ROOF: 6 mm Twinwall Polycarbonate, UV Coated

HIP ROOF: 6 mm Twinwall Polycarbonate, UV Coated or Standing Seam Aluminum

FLAT ROOF: Omega Ply®


Installation: Anchor securely to level, concrete pad

Bike Racks: Not included

DIMENSIONS/CAPACITY*

Peapod Mini 8	Length	Width	Roof Height			Bikes (Max.)
Clear height 8'						
= Fits in 1 parking space			BARREL ROOF	HIP ROOF	FLAT ROOF	
Peapod Mini 8-10	14' 8"	7' 5"	9' 10"	10' 1"	8' 6"	10
Peapod Mini 8-15	21' 10"	7' 5"	9' 10"	10' 1"	8' 6"	15
Peapod Mini 8-20	29' 1"	7' 5"	9' 10"	10' 1"	8' 6"	20
Peapod Mini 8-25	36' 3"	7' 5"	9' 10"	10' 1"	8' 6"	25
Peapod Mini 8-30	43' 6"	7' 5"	9' 10"	10' 1"	8' 6"	30
Peapod Mini 8-35	50' 8"	7' 5"	9' 10"	10' 1"	8' 6"	35


*Bike capacity varies with rack style

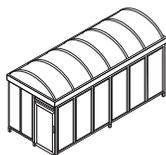

Barrel Roof




Hip Roof

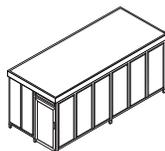


Flat Roof


VIEWS

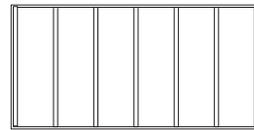

TOP

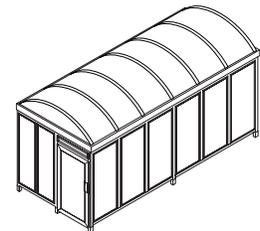

ISOMETRIC

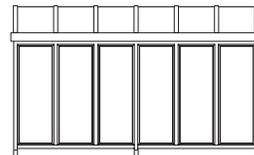

L

FRONT




W

SIDE

Peapod Mini for Parking Lots

1 Space = 10 Bikes

Peapod Mini 8-10 is designed to fit in a standard parking space.

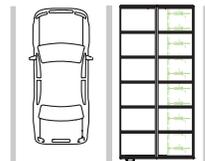

BIKE PARKING SOLUTIONS Bike Shelters | Bike Racks | Bike Storage Systems

888-995-8090

32 Ann Street Clifton, NJ 07013

info@velodomeselters.com

www.velodomeselters.com



Peapod Mini (Barrel Roof)



Peapod Mini Bike Cage (Barrel Roof)

OPTIONS/ACCESSORIES

- Bottom Panels
- Custom Branding, Graphics and Signage
- Illuminated Ad/Graphics Box
- Solar Lighting
- Public Bike Repair Accessories
- Coded Key and Keyless Access Control
- Powder Coating in RAL or Custom Colors

FRAME FINISHES

Anodized Aluminum, 6063-T52 Alloy



Dark Bronze Clear (Silver)

Powder Coating: RAL Colors (custom colors available)

9005	9010	3001	7035	7045	5005	5003	6002	6005
Jet Black	Pure White	Signal Red	Light Grey	Telegrey 1	Signal Blue	Sapphire Blue	Leaf Green	Moss Green

WALL PANELS

¼" Tempered Glass, Clear



Standard version
Tempered glass is stronger and safer than regular glass. It is also shatterproof.

¾" Stainless Steel Wire Mesh



 
Bike Cage version
Stainless steel wire mesh for indoor/outdoor use is durable and attractive. 2" square grid for a contemporary look.

BOTTOM PANELS



Aluminum panels inset at toe kick, inhibit debris, leaves and snow from entering shelter. Helps to minimize maintenance. Color may vary from frame.

ROOF




Barrel

Hip

Flat

6mm Twinwall Polycarbonate, UV Coated / Roof: **BARREL | HIP**

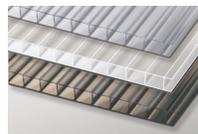

Translucent sheets with ribbed core. Impact resistant and light weight.

Clear (80% Light Transmission)

White (45% Light Transmission)

Bronze Tint (45% Light Transmission)

Standing Seam Aluminum / Roof: **HIP**



Finished aluminum panels with ribbed profile. Exceptionally durable, rustproof, fade resistant and easy to maintain. Colors available.

Omega-Ply® / Roof: **FLAT**



Aluminum clad plywood panels. Strong, rigid and impact resistant, rustproof, fade resistant and easy to maintain. Colors available.

Black (standard)