

Plastic Flip•n•Store Table

Size:
24" x 60"

Color:
Charcoal Slate
BPFT2460-20

**NEW
2018
COLOR**

Pair with the Café Time Folding Chair
600 Series MODEL #620



Table top surface smooth to write on

Grommet holes for wire management



Perforated steel modesty panel

Frame & legs made of hammer-tone powdercoated steel

Built-in cable channel to conceal wires


Tables nest for easy storage



Modesty panel with cable channel



Use lever to collapse tables

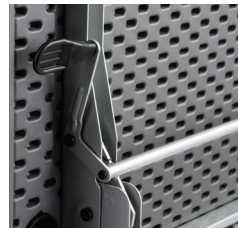

Four 2" casters (two locking)



Nesting

Tables nest together for space-saving storage.



Sleek

Perforated steel modesty panel with cable channel to conceal wires.



Sturdy

Tested to support up to 700lbs. 16 gauge steel frame. Table has 2 levers.



Mobile

Table rolls on four 2" casters (two locking), providing easy mobility.

Product Specs

Frame & Legs	Grey hammer-tone powdercoated steel
Surface	Lightweight HDPE blow molded plastic, Tabletop thickness 1 3/4"
Features	Perforated steel modesty panel, grommet holes, 4 casters with 2 locking casters, 16 gauge steel frame, 2 levers used to collapse
Weight	46lbs
Dimensions	Opened: 29 1/2"H x 60"L x 24"W Folded: 43 1/2"H x 60"L x 24 1/2"W
Shipping Dimensions	50 lbs 61" x 25" x 5" - Ready to assemble
Warranty	10 year manufacturer warranty



products meet or exceed applicable ANSI/BIFMA standards



National Public Seating



800.261.4421
www.nationalpublicseating.com