



**Encore Commercial Products, Inc.**  
 37525 Interchange Dr., Farmington Hills, MI 48335  
 Toll Free 1- 866 -737- 8900 Fax 248-354-4095  
 www.postguard.com

Title: Post Guard Bollard Cover

Drawing Number: PG1

**Recommended Use:**

Bollard, Post, or Pole  
Cover

**Specifications:**

See Below

Date: 3-15-17

Style: Round Cover

Page: 1 of 1

# POST GUARD COVER SPECIFICATION SHEET

## MATERIAL

Marlex™ HHM 5502 BN High Density Polyethylene

Microthene™ MP635662 Linear Low Density Polyethylene\*

HDPE, hexene copolymer, is tailored for blow molded products that require excellent stiffness, impact strength and UV resistance. HDPE is designed for an optimum balance of density, molecular weight distribution, demonstrating maximum property advantages for large products. Blow molded HDPE products are durable and recyclable for sustainability. Six year UV stabilizer package and antic-static package are combined with the HDPE.

\*Low Density PE, ethylene hexene copolymer. LDPE Resin is tailored for rotationally molded large hollow objects that require impact strength, warp resistance, stress crack resistance and UV stabilization.


\*\* The Yellow color 8-7/8" x 72" Post Guard bollard cover is stocked in HDPE. Other colors may be available in 8-7/8" HDPE as the market demands.

**Reflective Tape:** High quality reflective tape

**Installation Strips:** 2 foam strips

## INSTALLATION

1. Crisscross the two foam strips over the top of the bollard.
2. Slide the Post Guard cover over the foam strips and the bollard.

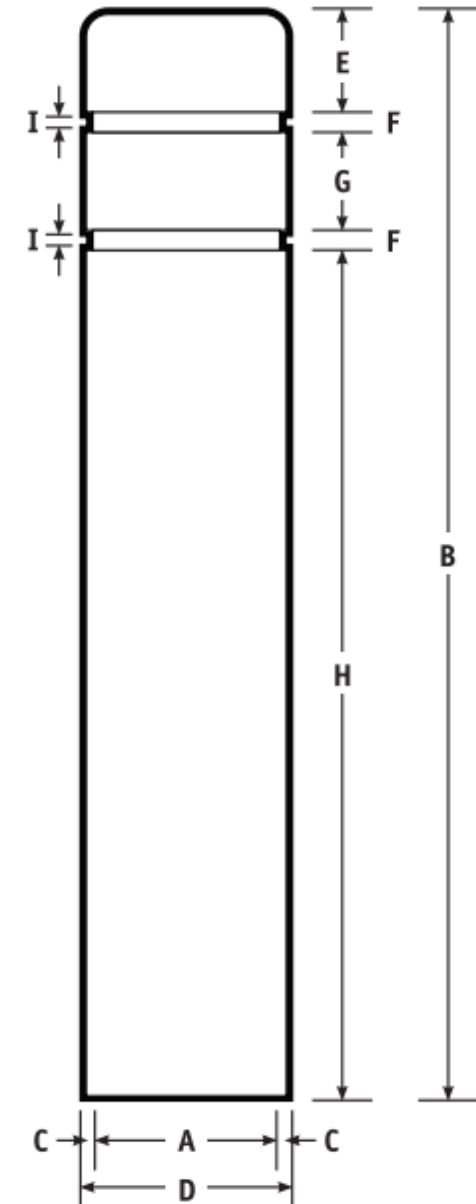

|                 | A            | B             | C         | D            | E     | F      | G     | H     | I            |
|-----------------|--------------|---------------|-----------|--------------|-------|--------|-------|-------|--------------|
|                 | ID Width/Dia | Height/Length | Thickness | OD Width/Dia |       | Recess |       |       | Reflect Tape |
| 4.5" x 52"      | 4.72         | 52            | .1406     | 5            | 2.875 | .875   | 5.875 | 41.50 | .75w         |
| 4.5" x 64"      | 4.72         | 64            | .1406     | 5            | 2.875 | .875   | 5.875 | 53.50 | .75w         |
| 7" x 52"        | 7            | 52            | .1719     | 7.34         | 2.875 | .875   | 5.875 | 41.50 | .75w         |
| 7" x 60"        | 7            | 60            | .1719     | 7.34         | 2.875 | .875   | 5.875 | 49.50 | .75w         |
| 7" x 72"        | 7            | 72            | .1719     | 7.34         | 2.875 | .875   | 5.875 | 61.50 | .75w         |
| 8 7/8" x 72"*** | 8.8125       | 72            | .19       | 9.1857       | 3.875 | .875   | 5.75  | 60.62 | .75w         |
| 10 7/8" x 60"*  | 10.875       | 60            | .22       | 11.3125      | 3.0   | .875   | 5.75  | 49.50 | 1.0w         |
| 12 7/8" x 60"*  | 13.00        | 60            | .20       | 13.4         | 3.0   | .875   | 5.75  | 49.50 | 1.0w         |