



# Flat Top Work Tables

## Stainless Steel Work Tables



Use your smart phone to scan the above QR code to visit our website:  
www.bk-resources.com

### Certifications:



### Features:

- Two (2) Sound Deadened Integrally Welded 5" "C" Channels to Reinforce and Maintain Level Working Surface
- Legs 1 5/8" Diameter
- 84" & 96" Tables Have 6 Legs

### Options:

- Single & Double Overshelves
- Drawer Assemblies
- Casters
- Upgraded Bullet Feet
- Extra Shelves
- Adjustable Table Mount Pot Rack



### Material:



#### VTT Series: S/S w/ Galvanized Legs & Undershelf

- T-430 18 ga. Stainless Steel Top
- Galvanized Legs & Adjustable Undershelf
- Adjustable High Impact Corrosion Resistant Feet



### VTT Series

#### S/S w/ Galv. Legs & Undershelf

Length	T-430 S/S 18" Width	Undershelf Dimensions	T-430 S/S 24" Width	Undershelf Dimensions	T-430 S/S 30" Width	Undershelf Dimensions
24"	VTT-1824	10" x 17 <sup>1/2</sup> "	VTT-2424	16" x 17 <sup>1/2</sup> "	-	-
30"	VTT-1830	10" x 23 <sup>1/2</sup> "	VTT-3024	16" x 23 <sup>1/2</sup> "	VTT-3030	22" x 23 <sup>1/2</sup> "
36"	VTT-1836	10" x 24 <sup>1/2</sup> "	VTT-3624	16" x 29 <sup>1/2</sup> "	VTT-3630	22" x 29 <sup>1/2</sup> "
48"	VTT-1848	10" x 41 <sup>1/2</sup> "	VTT-4824	16" x 41 <sup>1/2</sup> "	VTT-4830	22" x 41 <sup>1/2</sup> "
60"	VTT-1860	10" x 53 <sup>1/2</sup> "	VTT-6024	16" x 53 <sup>1/2</sup> "	VTT-6030	22" x 53 <sup>1/2</sup> "
72"	VTT-1872	10" x 65 <sup>1/2</sup> "	VTT-7224	16" x 65 <sup>1/2</sup> "	VTT-7230	22" x 65 <sup>1/2</sup> "
84"	VTT-1884	10" x 77 <sup>1/2</sup> "	VTT-8424	16" x 77 <sup>1/2</sup> "	VTT-8430	22" x 77 <sup>1/2</sup> "
96"	VTT-1896	10" x 89 <sup>1/2</sup> "	VTT-9624	16" x 89 <sup>1/2</sup> "	VTT-9630	22" x 89 <sup>1/2</sup> "

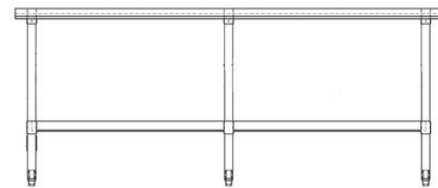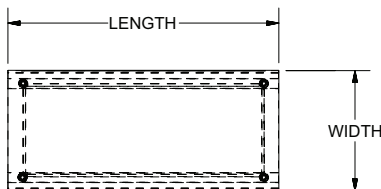

TABLES 7 FT. AND LARGER ARE FURNISHED WITH SIX (6) LEGS

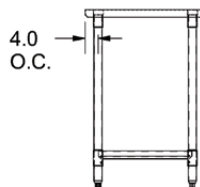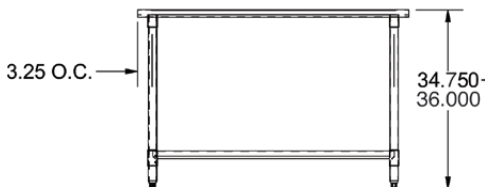

PRODUCT DATA SHEET

BK RESOURCES





# Flat Top Work Tables

## Stainless Steel Work Tables



Use your smart phone to scan the above QR code to visit our website:  
www.bk-resources.com

### Certifications:



### Features:

- Two (2) Sound Deadened Integrally Welded 5" "C" Channels to Reinforce and Maintain Level Working Surface
- Legs 1 5/8" Diameter
- 84" & 96" Tables Have 6 Legs

### Options:

- Single & Double Overshelves
- Drawer Assemblies
- Casters
- Upgraded Bullet Feet
- Extra Shelves
- Adjustable Table Mount Pot Rack



### Material:



#### SVT Series: S/S w/ Stainless Steel Legs & Undershelf

- T-430 18 ga. Stainless Steel Top
- Stainless Steel Legs & Adjustable Undershelf
- S/S Bullet Feet


### SVT Series

#### S/S w/ S/S Legs & Undershelf

Length	T-430 S/S 18" Width	Undershelf Dimensions	T-430 S/S 24" Width	Undershelf Dimensions	T-430 S/S 30" Width	Undershelf Dimensions
24"	SVT-1824	10" x 17 <sup>1/2</sup> "	SVT-2424	16" x 17 <sup>1/2</sup> "	-	-
30"	SVT-1830	10" x 23 <sup>1/2</sup> "	SVT-3024	16" x 23 <sup>1/2</sup> "	SVT-3030	22" x 23 <sup>1/2</sup> "
36"	SVT-1836	10" x 24 <sup>1/2</sup> "	SVT-3624	16" x 29 <sup>1/2</sup> "	SVT-3630	22" x 29 <sup>1/2</sup> "
48"	SVT-1848	10" x 41 <sup>1/2</sup> "	SVT-4824	16" x 41 <sup>1/2</sup> "	SVT-4830	22" x 41 <sup>1/2</sup> "
60"	SVT-1860	10" x 53 <sup>1/2</sup> "	SVT-6024	16" x 53 <sup>1/2</sup> "	SVT-6030	22" x 53 <sup>1/2</sup> "
72"	SVT-1872	10" x 65 <sup>1/2</sup> "	SVT-7224	16" x 65 <sup>1/2</sup> "	SVT-7230	22" x 65 <sup>1/2</sup> "
84"	SVT-1884	10" x 77 <sup>1/2</sup> "	SVT-8424	16" x 77 <sup>1/2</sup> "	SVT-8430	22" x 77 <sup>1/2</sup> "
96"	SVT-1896	10" x 89 <sup>1/2</sup> "	SVT-9624	16" x 89 <sup>1/2</sup> "	SVT-9630	22" x 89 <sup>1/2</sup> "

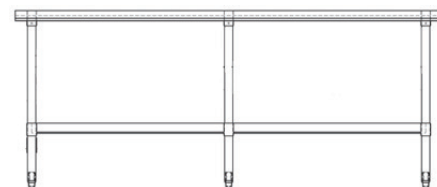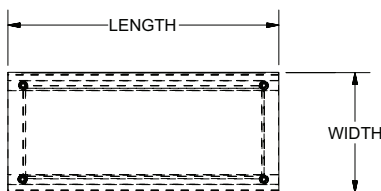

TABLES 7 FT. AND LARGER ARE FURNISHED WITH SIX (6) LEGS

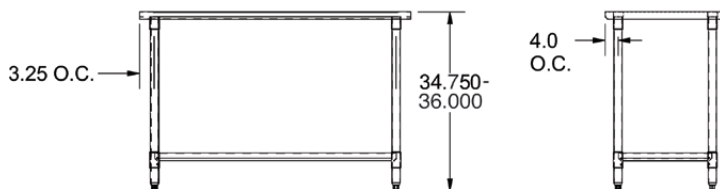

PRODUCT DATA SHEET

BK RESOURCES

