

Retractable Belt Posts

Innovation, Safety, Choice, Value – Built into every post!



Features & Benefits:

Premium Post Design

- One-piece, continuous construction.
- Belt mechanism is completely concealed within post.
- Belt mechanism is easily field replaced.
- Post can receive all major manufacturers' belts.

4-Way Dovetail Connection

- Standard 4-way connection allows post to deliver one belt while simultaneously receiving three belts or accessories (except Tempest Post).
- Belt ends fit on all major manufacturers' posts.

Slow Retracting Belt

- Unique, centrifugal belt-braking system ensures a slow and safe retraction if accidentally released.

Superior Base Design

- Weighted steel base for superior stability (except Tempest).
- Factory applied, slotted rubberized base protects flooring from damage and promotes air flow, allowing wet floors to dry quickly (except Tempest).
- Optional galvanized base for outdoor use (except Basic & Tempest Posts).

Warranty

- 5 years on post (1 year for Tempest), 3 years on mechanism (1 year for Tempest).

Retractable Belt Posts

Innovation, Safety, Choice, Value – Built into every post!



407024



5000



26-20400



40701



40701

	Exhibit Post	Tempest All-Weather	Basic Post	Contempo Designer™	Contempo Stainless™
Height	24 inches	38 ¼ inches	38 ½ inches	40 inches	40 inches
Weight	24.5 lbs.	16 lbs.	27.5 - 30 lbs.	27.5 - 30 lbs.	27.5 - 30 lbs.
Finish	Stainless, Brass or Wrinkle Black	Black, Orange or Yellow HDPE Plastic	Wrinkle Black or Chrome w/Gray Base	All Metal or Lido-Tone®	Satin or Polished Stainless Steel
Post Diameter	2 ¾ inches	3 ¼ inches	2 ¾ inches	2 ¾ inches	2 ¾ inches
Post Construction	Steel	HDPE Plastic	Steel	Steel	Stainless Steel
Base Connection	Aluminum Insert	Rubber	Set Screws	Aluminum Insert	Aluminum Insert
Base Options and Dimensions	12.5-inch domed	16-inch recycled rubber	12.5-inch domed 14-inch sloped 14.5-inch slim	12.5-inch domed 14-inch sloped 14.5-inch slim	12.5-inch domed 14-inch sloped 14.5-inch slim
Base Cover	Metal or Plastic	N/A	N/A	Metal or Plastic	Stainless Steel
Rubberized Base	Standard	N/A	Standard	Standard	Standard
Belt Color	All	All	All	All	All
Belt Length	7 feet	12 feet	7 feet	7 feet	7 feet
Slow Retracting Belt	Standard	Standard	Standard	Standard	Standard
Beltloc™	Additional	No	Additional	Additional	Standard
4-Way Connection	Standard	No	Standard	Standard	Standard
Signage Ready	Yes	No	Yes	Yes	Yes
Floor Mounting	Yes	No	No	Yes	Yes
Outdoor Usage	Add-on, Please Call	Yes	Add-on, Please Call	Add-on, Please Call	Add-on, Please Call

Related Products:



Wall Receptacle




Post-Top Signs & Graphics



Digital Belt Imprinting



Beltloc™ Locking Mechanism

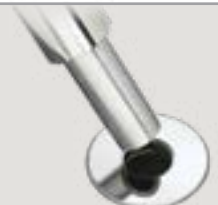

Floor Sockets