

# Beltrac® Wall Mount Units

*Instant barriers that ensure safety anywhere, anytime.*



## *Features & Benefits:*

### ***Ideal Solutions for Temporary Closures***


- Section off aisles, corridors and cash registers easily and effectively.
- Belt mechanism is completely concealed within unit.
- Belt mechanism is easily field replaced.
- Can connect to other Beltrac® posts as well as most other manufacturers' posts.

### ***Choice of Mounting Options***

- Installs in minutes!
- Magnetic mounts offer versatility.
- A variety of mounting options: Wall, Countertop, Concealed and more.

# Beltrac® Wall Mount Units

*Instant barriers that ensure safety anywhere, anytime.*

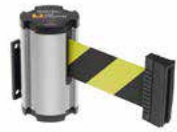


	BELTRAC® WALL MOUNT 3010	BELTRAC® MAGNETIC WALL MOUNT 3010MG	BELTRAC® WALL MOUNT 3013	BELTRAC® MAGNETIC WALL MOUNT 41300MG
Mounting Plate Dimensions	2" wide x 3" tall	2½" wide x 2½" tall	2" wide x 3" tall	2½" wide x 2½" tall
Available Finishes	Anodized: Satin, Gold, Chrome; Wrinkle Black, Wrinkle Charcoal or Lido-tone®	Anodized: Satin, Gold; Chrome; Wrinkle Black; Lido-tone®	Satin Anodized, Wrinkle Black or Lido-Tone®	Satin Anodized, Wrinkle Black or Lido-Tone®
Belt Color	All, plus standard messages	All, plus standard messages	All, plus standard messages	All, plus standard messages
Belt Length	7 feet	7 feet	13 feet	13 feet
Slow Retracting Belt	Standard	Standard	Standard	Standard
Magnetic Belt End	Available	Available	Available	Available




	BELTRAC® RECESSED WALL UNITS: 3012, 3013	BELTRAC® COUNTER MOUNT 50-41300WB/CM
Mounting Plate Dimensions	4" wide x 5" tall	4½" wide x 4½" deep
Available Finishes	Satin Aluminum	Wrinkle Black
Belt Color	All, plus standard messages	Flourescent Yellow plus standard messages
Belt Length	7 feet, 13 feet	7 feet
Slow Retracting Belt	Standard	Standard
Magnetic Belt End	Available	Not Available

## Related Products:

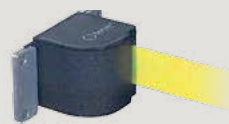

Trailer Mount (shown with Wall Mount, not included).  
40-915TM/SET

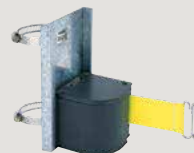

Forklift Mount (shown with Wall Mount, not included).  
20-917FM



Wall Receptacle  
50-3011