

# HyFlex®

ADVANCED MECHANICAL PROTECTION

## 11-755

Our lightest ANSI A5 / ISO Level E Cut Resistant touchscreen glove



Cut



Light Duty

## Ultralight ANSI A5/EN ISO E-level cut-resistant gloves with touchscreen compatibility

- **Heightened defenses:** Designed with INTERCEPT™ Cut Resistance Technology, and achieving ANSI A5/EN ISO E standards for cut resistance, HyFlex® 11-755 industrial gloves guard against lacerations and prevent common workplace injuries
- **Enhanced tactile sensitivity:** Palm-dipped, with nylon liner, these PU-coated gloves benefit from heightened tactile sensitivity and touchscreen compatibility
- **Elevated comfort:** Lightweight and fitted to natural hand contours, HyFlex® 11-755 PPE gloves cause minimal hand fatigue
- **Improved dexterity:** These polyurethane gloves' ultralight design also increases flexibility and ease of use
- **Certified skin-friendliness:** HyFlex® 11-755 industrial working gloves are Dermatest® - approved for skin-friendliness



### Industries

- Automotive
- Machinery and Equipment
- Metal fabrication

### Applications

- Assembly & inspection of components
- Picking, fastening components
- Final assembly
- Applying finish to materials, products

# HyFlex®

ADVANCED MECHANICAL PROTECTION

## 11-755

Our lightest ANSI A5 / ISO Level E Cut Resistant touchscreen glove

### Key Features

- **ANSI A5/EN ISO E cut protection:** 4x greater cut resistance\*
- **Ultralight formulation:** All-day comfort and dexterity ensured
- **Touchscreen-compatible design:** Improved productivity and safety  
\*versus standard ANSI A2/EN ISO B-rated gloves

### Technologies


 **INTERCEPT™**  
Cut Resistance Technology



Touchscreen Compatible

### Performance Standards & Regulatory Compliance

#### REACH Compliant

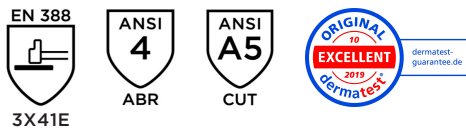

### Specifications

BRAND   STYLE	DESCRIPTION	Gauge	SIZE	LENGTH	COLOR	PACKAGE
HyFlex® 11-755	<b>Finishing:</b> Palm dipped <b>Coating Material:</b> Polyurethane <b>Liner Material:</b> HPPE, Tungsten, Spandex, Polyester <b>Cuff Style:</b> Knitwrist	18	6, 7, 8, 9, 10, 11, 12	225-285cm	Grey	• 12 pairs/bag, 12 bags/carton

### For additional information visit us at [www.ansell.com](http://www.ansell.com), or call us at

#### Europe, Middle East & Africa Region

Ansell Healthcare Europe NV  
Riverside Business Park  
Blvd International, 55  
1070 Brussels, Belgium  
T: +32 (0) 2 528 74 00  
F: +32 (0) 2 528 74 01

#### North America Region

Ansell Healthcare Products LLC  
111 Wood Avenue South,  
Suite 210  
Iselin, NJ 08830, USA  
T: +1 800 800 0444  
F: +1 800 800 0445

#### Australia

Ansell Limited  
Level 3,678 Victoria Street,  
Richmond, Vic, 3121  
Australia  
T: +61 1800 337 041  
F: +61 1800 803 578

#### Asia Pacific Region

Ansell Global Trading Center  
(Malaysia) Sdn Bhd  
Prima 6, Prima Avenue  
Block 3512, Jaijan Teknokrat 6  
T: +603 8310 6688  
F: +603 8310 6699

#### Latin America & Caribbean Region

Ansell Commercial Mexico S.A. de C.V.  
Blvd. Bernardo Quintana No. 7001-C,  
Q7001 Torre II,  
Suites 1304, 1305 y 1306,  
Col. Centro Sur, c.p. 76079  
Queretaro, Qro. Mexico  
T: +52 442 248 1544 / 248 3133

#### Canada

Ansell Canada  
105 Lauder  
Cowansville, QC J2K 2K8  
Canada  
T: +1 800 363 8340  
F: +1 800 267 3551

Ansell, ® and ™ are trademarks owned by Ansell Limited or one of its affiliates. US Patented and US and non-US Patents Pending: [www.ansell.com/patentmarking](http://www.ansell.com/patentmarking) © 2022 Ansell Limited. All Rights Reserved.

Neither this document nor any other statement made herein by or on behalf of Ansell should be construed as a warranty of merchantability or that any Ansell product is fit for a particular purpose. Ansell assumes no responsibility for the suitability or adequacy of an end user's selection of gloves for a specific application.

**Ansell**