


Jafline HD



All polyester, double-jacket
fire hose with an EPDM rubber lining

COLORS:

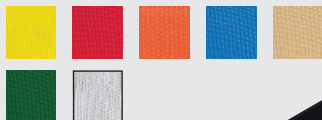

Jafline HD

- **Double-Jacket Construction:** Jafline HD is an all polyester double-jacket hose with an EPDM rubber ozone resistant lining
- **High Burst Rating:** 1200 psi up to 3" diameter.
- **Superior Performance:** Very low friction loss.
- **Maintenance Free:** Immune to mildew and rot.
- **Coated for Better Durability:** All colored hose is impregnated with our tough heat-set polymer coating for the best abrasion resistance.
- **All-Weather Performance:** Retains pliability to -40°F.
- **Lightweight:** An 1 ½" 50'+ coil weighs just 17 lbs.
- **Available in yellow, red, orange, blue, tan, green and white.**
- **Meets or exceeds NFPA Standard on Fire Hose (current edition)**
- **10 year warranty**

Applications –

- Municipal fire departments
- Industrial fire brigades
- Shipboard fire fighting

Lengths – Available in 50' and 100' lengths.

Size (in)	Bowl Size (in)	Service Test PSI	Proof Test PSI	Burst Test PSI	Weight (lbs/ft) Uncoupled
1	1 7/16	400	800	1200	0.24
1 ½	1 15/16	400	800	1200	0.32
1 ¾	2 1/8	400	800	1200	0.38
2	2 15/32	400	800	1200	0.46
2 ½	3	400	800	1200	0.56
3	3 ½	400	800	1200	0.74
4	4 17/32	300	600	900	0.82
5	5 15/32	300	600	900	0.95

† Weight includes couplings

ATIJFLHDFL0319 ATI reserves the right to modify any specification without prior notice to meet or exceed changing standards. Special diameters or construction characteristics can be produced upon special request. Contact your local dealer or ATI at: sales@atifireproducts.com



www.atifireproducts.com 888.229.9655
9 Vose Farm Road · Peterborough, NH 03458-0090

