



Boot Saver shoe covers are perfect for the color coded world of food processing by helping prevent cross-contamination.



Textured Outsole:
Provides grip on both wet and dry surfaces.

Ideal Applications: Food processing, maintenance and service technicians, home repair contractors, plant visitors, paint spray booths, and other general industry applications.

Chemical Resistance: Resistant to water-soluble compounds, low concentration acids and alkalis, alcohols, most natural fats and greases, dilute bleach, and mild to moderate strength detergents and cleaners.

Color-Coded Contamination Prevention

Boot Saver shoe covers are highly elastic and easily stretch over primary footwear to provide 100% liquid proof protection. These ambidextrous shoe covers are ideal for food processing, home repair contractors, and other environments where contamination prevention is needed.

- Four colors (Black, Red, Yellow, and Blue) to support FSMA, HACCP, GMP and other safety and contamination prevention procedures.
- 100% liquid proof protection for boots and shoes.
- High quality, natural rubber latex* stretches easily over boots while remaining resistant to snags, tears, and abrasion.
- Textured outsole provides grip on both wet and dry surfaces.
- Powder-free finish eliminates concerns about powder contamination on clothing, footwear, foods, and food-contact surfaces.
- Four sizes (Medium, Large, XL, and 2X) to fit footwear sized 7 to 15+.
- Bulk Packed, 100 pair/case.



Global #	Tingley #	Description
B2779332	6330.2X	Boot Saver® Disposable Shoe Covers, 2XL, Ankle Height, Black, 100 Pack
B2779333	6330.LG	Boot Saver® Disposable Shoe Covers, Large, Ankle Height, Black, 100 Pack
B2779334	6330.MD	Boot Saver® Disposable Shoe Covers, Medium, Ankle Height, Black, 100 Pack
B2779335	6330.XL	Boot Saver® Disposable Shoe Covers, XL, Ankle Height, Black, 100 Pack
B2779336	6332.2X	Boot Saver® Disposable Shoe Covers, 2XL, Ankle Height, Red, 100 Pack
B2779160	6332.LG	Boot Saver® Disposable Shoe Covers, Large, Ankle Height, Red, 100 Pack
B2779178	6332.MD	Boot Saver® Disposable Shoe Covers, Medium, Ankle Height, Red, 100 Pack
B2779179	6332.XL	Boot Saver® Disposable Shoe Covers, XL, Ankle Height, Red, 100 Pack
B2779180	6333.2X	Boot Saver® Disposable Shoe Covers, 2XL, Ankle Height, Yellow, 100 Pack
B2779181	6333.LG	Boot Saver® Disposable Shoe Covers, Large, Ankle Height, Yellow, 100 Pack
B2779247	6333.MD	Boot Saver® Disposable Shoe Covers, Medium, Ankle Height, Yellow, 100 Pack
B2779248	6333.XL	Boot Saver® Disposable Shoe Covers, XL, Ankle Height, Yellow, 100 Pack
B2779249	6336.2X	Boot Saver® Disposable Shoe Covers, 2XL, Ankle Height, Blue, 100 Pack
B2779250	6336.LG	Boot Saver® Disposable Shoe Covers, Large, Ankle Height, Blue, 100 Pack
B2779251	6336.MD	Boot Saver® Disposable Shoe Covers, Medium, Ankle Height, Blue, 100 Pack
B2778951	6336.XL	Boot Saver® Disposable Shoe Covers, XL, Ankle Height, Blue, 100 Pack

*Product contains natural rubber latex and may cause allergic reactions.

Product Appearance: Color density is uniform and consistent within and between lots. Upper portion is smooth and visually consistent in texture without bubbles or distortions. Lower portion is textured to provide enhanced slip-resistance. Each shoe cover is embossed with Tingley brand name and size on one side.

Labeling: Carton labels are color-coded to match product color (NOTE: Style 6330, Black Shoe Covers will be a white label). Labels indicate the Tingley and Boot Saver[®] brand names, product description, men's size, color, quantity, lot number, and country of origin.

Packaging & Case Weights: Boot Savers are bulk-packed in a clear polyethylene bag with 100 pair/case.

	MD	LG	XL	2X
Case Weight	15 lbs.	17 lbs.	20 lbs.	21 lbs.
Case Dimensions	13L x 13W x 6H in.		13L x 13W x 8H in.	

Physical Properties:


Tensile Strength - Initial (PSI)	3000 Min
Tensile Strength – After Heat Aging 72 hours @ 70°C (PSI)	2700 Min
Tensile Strength – After Water Immersion 72 hours @ 70°C (PSI)	1950 Min
Elongation – Initial (%)	700 Min
Elongation – After Heat Aging 72 hours @ 70°C (%)	630 Min
Elongation – After Water Immersion 72 hours @ 70°C (%)	595 Min
Specific Gravity (g/ml)	1.18 +/- 0.02
Volume Swell – After Water Immersion 72 hours @ 70°C (%)	15 Max
Slip Resistance – Dry (Coefficient of Friction)	0.45 Min
Slip Resistance – Wet (Coefficient of Friction)	0.40 Min

Boot Saver[®] Disposable Shoe Covers

Available Sizes:

MD
LG
XL
2X

*All dimensions are approximate

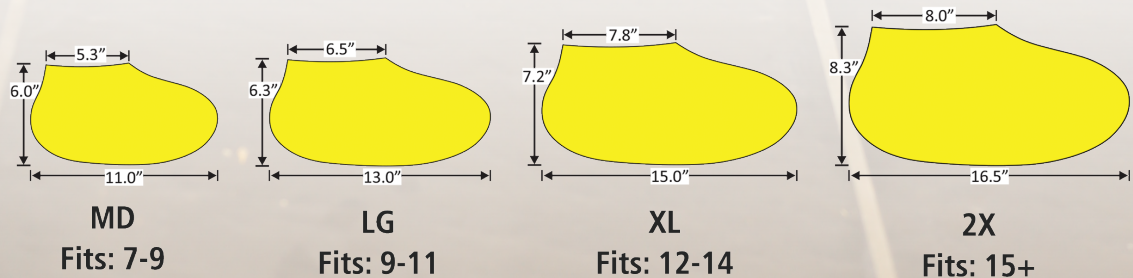

Country of Origin:
Made in Thailand

US Pat. Pending 2021/0337930A1

The information contained in this document is to the best of our knowledge and belief, accurate and reliable as of the date compiled. However, no representation, warranty, or guarantee is made as to its accuracy, reliability or completeness.

No warranty of merchantability, fitness for any particular purpose, or any other warranty expressed or implied, is made concerning the information herein provided. It is the user's responsibility to satisfy him/herself as to the suitability and completeness of such information for his/her own particular use. Neither The Tingley Rubber Corporation nor its representatives accept liability for any loss or damage that may occur from the use of this information.