



CRIBBING SUPPORT BLOCKING SERVICE TRUCK APPLICATION GUIDE

YouTube
Scan to watch



See below for the recommended crib blocking kits and components:

COMMERCIAL FLEET (COMMERCIAL TIRE / SMALL AG/OTR)

FOR SERVICE APPLICATION ON TIRES UP TO 295/25



Kit No.	15230 Original Super Stacker Block 6in x 7in x 24in	14468LT Locking Jack Plate 24in x 24in x 2in	14503 Bottom Locking Jack Plate 27in x 24in x 2in
#15266	12	1	
RECOMMENDED	#15252PLB	12	1



MEDIUM AG / OTR

FOR SERVICE APPLICATION ON TIRES UP TO 45"



Kit No.	15230 Original Super Stacker Block 6in x 7in x 24in	15239 Primo—Solid Crib Block 6in x 7in x 24in	14468LT Locking Jack Plate 24in x 24in x 2in	14503 Bottom Locking Jack Plate 27in x 24in x 2in
#15266	12		1	
#15252PLB	12		1	1
#15269		12	2	
RECOMMENDED	#15266PLB	12	1	1



LARGE OTR

FOR SERVICE APPLICATION ON TIRES 45" AND UP



For large OTR tire service application, AME recommends fleet service trucks to carry a variety of Jack Plates for various field applications. See back for the AME Jack Plate product range.

Kit No.	15239 Primo—Solid Crib Block 6in x 7in x 24in	14468LT Locking Jack Plate 24in x 24in x 2in	14503 Bottom Locking Jack Plate 27in x 24in x 2in	14466 Jack Plate 18in x 12in x 3in
RECOMMENDED	#15258PLB	18	1	1



SEE BACK PAGE FOR OPTIONAL SPACER JACK PLATES





CRIBBING SUPPORT BLOCKING SERVICE TRUCK APPLICATION GUIDE

YouTube
Scan to watch



CRIBBING BLOCKS

- Certified and tested
- Multiple sizes, shapes fit most applications
- Interlocking or aggressive non-slip surface
- Non-conducting plastic resists oil and most chemicals
- Does not splinter, like wood
- MADE IN THE USA




COLOR-CODED WORKING LOAD LIMIT LANYARDS

Blue
Blue = Medium
Total Block Working Load Limit Range 21,000 kg – 50,000 kg (46,297 lbs – 110,231 lbs)
High Vis Orange
Orange = Heavy
Total Block Working Load Limit Range 50,000 kg – 100,000 kg (110,231 lbs – 220,462 lbs)

Part No.	#15230 Original Super Stacker Block 6in x 7in x 24in	#15239 Primo—Solid Block 6in x 7in x 24in
Dimensions	6" x 7" x 24"	6" x 7" x 24"
Lanyard Color	BLUE	ORANGE
Working Load Limit	110,010 lbs (49,900 kg)	129,631 lbs (58,800 kg)
Weight	24.4 lbs (11 kg)	27 lbs (12.2 kg)

CRIB BLOCK STACKING CONFIGURATION

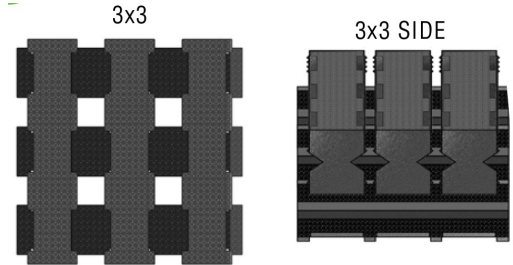

Note: Mechanically lock load and prevent damage to crib blocks caused by point-loading with AME Jack Plates

JACK PLATES

- Jack plates provide greater stability to bottle jacks, hydraulic rams, jack stands and cribbing
- Durable high density polymer resists the elements and stresses of point loading
- Light-weight and easy to handle with weight-rated colored carrying lanyard
- New Grip-It Jack Plates provide a better grip on uneven terrain in the field
- MADE IN THE USA



Model No.	Length	Width	Thickness	Capacity (Tons)	Surface Side 1	Surface Side 2	Lanyard Color
#14464	12"	12"	1"	50	Smooth	Smooth	BLUE
#14465	12"	12"	1.5"	100	Smooth	Smooth	ORANGE
#14468LT	24"	24"	2"	100	Smooth	Locking	ORANGE
#14466	18"	12"	3"	200	Smooth	Smooth	ORANGE
#14468B	24"	24"	2"	100	Smooth	Pyramid	ORANGE
#14497	12"	12"	2"	100	Smooth	Smooth	ORANGE
#14499	12"	12"	3"	200	Smooth	Smooth	ORANGE
#14500	12"	12"	2"	100	Smooth	Pyramid	ORANGE
#14501	12"	24"	2"	100	Smooth	Pyramid	ORANGE
#14503	27"	24"	2"	100	Pyramid	Locking	ORANGE

