


# > AXR7+

- Excellent printing quality and sensitivity
- Excellent resistance to smudge and scratch
- Good resistance to high temperature
- Receptor multi-compatibility


**AXR®7+ is the standard resin ribbon of the inkanto range.** Its high versatility (it also prints on coated papers), its performances (sharpness, printing speed) and its ability to widen the usual application fields of resin ribbons have resulted in making AXR®7+ the worldwide reference on this family of products.

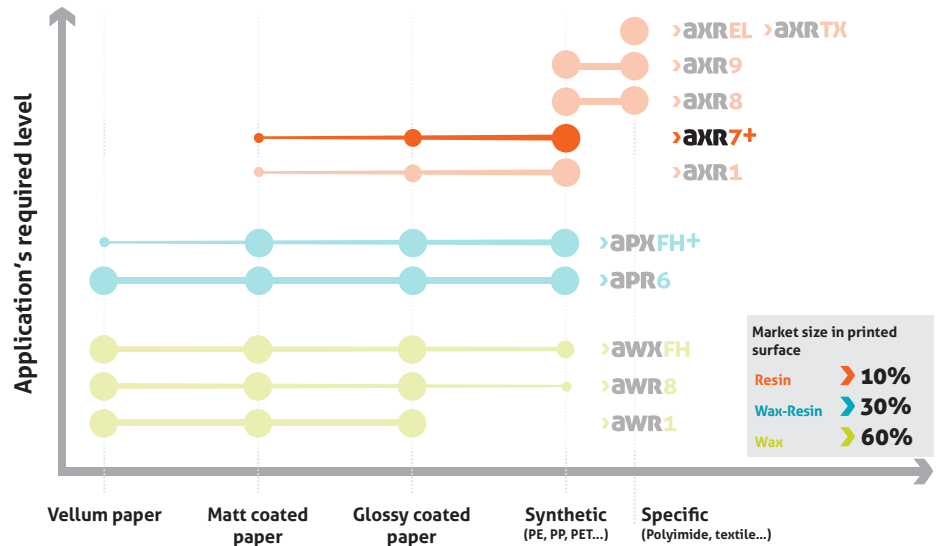


## Printing receptor

papers	synthetics
Coated ○○○	PP ●●●
Glossy coated ●●○	PE ●●●
	PET ●●●

## Printer settings

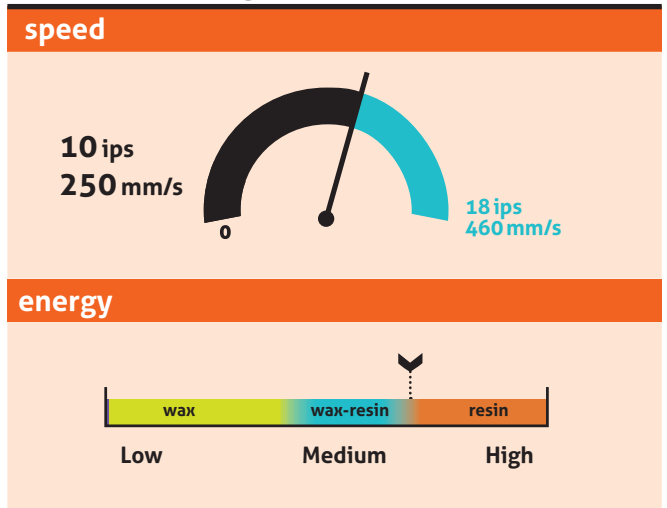

## Print resistance

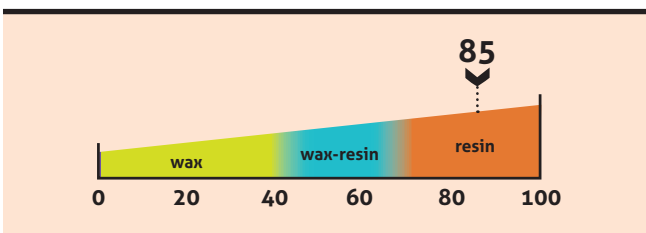

## Compliant with the following regulations

REACH / SVHC 1907/2006/EC
Food Contact 1935/2004/EC
Heavy metals 2011/65/EU
California Proposition 65
Halogen Restrictions

## Your ribbon identity

Colours: ● ○ ● ● ●

 
Length (m): .....

Width (mm): .....

Part number: .....

Your distributor: .....

Contact : .....



# > aXR7+

## Application fields




## Product performance

print quality		
90°Barcode	95	A <sub>a</sub> Small characters
0°Barcode	100	2D Barcode
		Logos
		Blackness
<small>*Optical Density by Reflection, measured using a densitometer.</small>		
technical resistances		
Heat	180°C / 356°F	Light/Blue Wool
	<small>300°C / 572°F</small>	Solvents
Water/Submerge	100	Rubbing
		Rubtester: 939g, no damage after ... cycles : IPA: 120 Ethanol: 25 Mineral Spirit: 60 Unleaded gasoline 98: nr* Motor oil: 250 Brake fluid: nr* <small>*not recommended</small>

## Product physico-chemical features

product structure	
<b>PET film</b>	Thickness: 4,5 µm
<b>Ink</b>	Resin
Melting point	80°C/176°F
<b>Backcoating</b>	Silicon based
Coefficient of Friction	Kd < 0.2
<b>Ribbon thickness</b>	< 9 µm
The ribbon is anti static build-up treated	

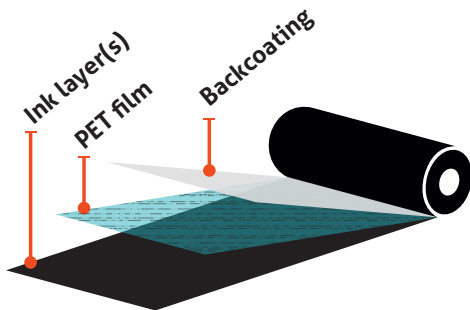

## Storage

### storage conditions

12 months recommended  
 20-80 % Humidity Rate, 5-35°C (40-95°F)

## Waste management

inkanto rolls and their packaging allow an optimised waste management. For more information please contact ARMOR.

## The inkanto benefits

---



› **Warranty**  
This product is guaranteed for life against any manufacturing defect in normal conditions of use and storage.



› **Quality commitment**  
Easy to use with guaranteed product performance: the certificate of conformity for your product can be accessed via the flashcode on the box.



› **Easy to identify products:**  
The inkanto rolls families are identified by color codes. The roll labels highlight the important information about the product.



› **Your product is delivered with a cleaning wipe**  
To clean the print head and maintain the maximum performance of your printer.



› **Packing**  
Consistent packaging units depending on the roll dimensions.

## A certified and approved production site

---



**Quality, health & safety and environmental systems:**  
ISO 9001  
OHSAS 18001  
ISO 14001  
ISO 50001 (France only)



**Responsible Care**  
The charter of the International Council of Chemical Associations for improvements in health & safety and the environment.



**Global Compact**  
UN initiative inviting companies to apply fundamental ethical and environmental values.