




# > aWR8

Receptor multi-compatibility  
Excellent blackness  
Competitiveness

**AWR®8 is the standard ribbon from the inkanto wax range.**


It doesn't make any compromise to quality and printing performance and therefore matches all criteria expected by a traditional wax application.

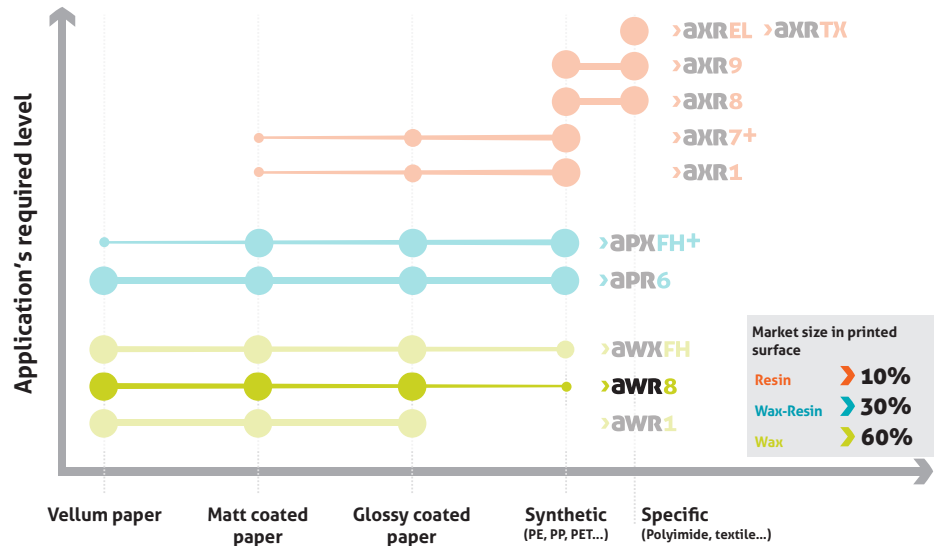


## Printing receptor

papers		synthetics	
Vellum	●●●	PP	●○○
Coated	●●●	PE	●○○
Glossy coated	●●●	PET	●○○

## Printer settings

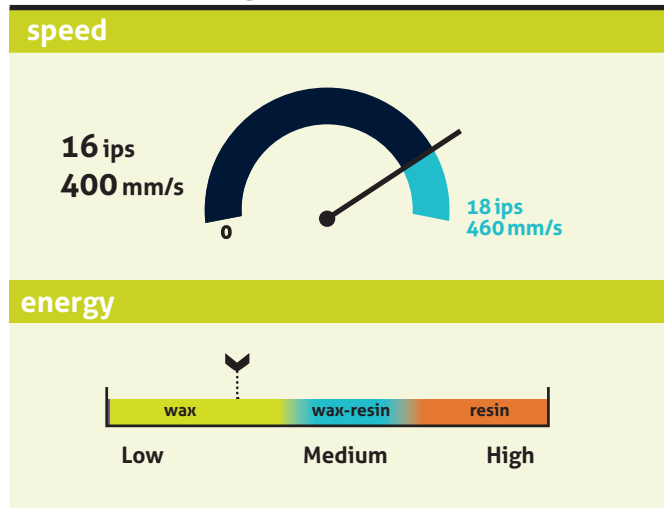

## Print resistance

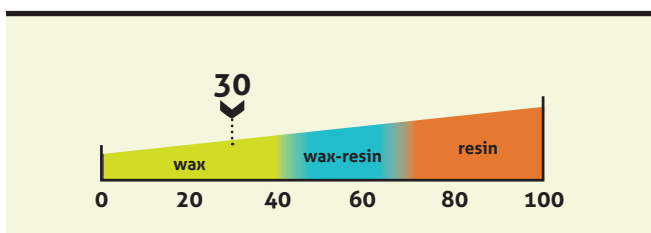

## Compliant with the following regulations

REACH / SVHC 1907/2006/EC
Food Contact 1935/2004/EC
Heavy metals 2011/65/EU
California Proposition 65
Halogen restrictions

## Your ribbon identity

Colours: ● ● ● ● ●

 
Length (m): .....

Width (mm): .....

Part number: .....

Your distributor: .....

Contact: .....





# > aWR8

## Application fields




## Product performance

print quality		
90°Barcode                      70	Small characters                      85	Logos                      95
0°Barcode                      100	2D Barcode                      100	Blackness                      2,1 ODR* <small>*Optical Density by Reflection, measured using a densitometer.</small>
technical resistances		
Heat                      60°C / 140°F	Light/Blue Wool                      >7	Solvents                      100
Water/Submerge                      100	Rubbing                      40	

## Product physico-chemical features

product structure	
<b>PET film</b>	Thickness: 4,5 µm
<b>Ink</b>	Wax
Melting point	65°C/149°F
<b>Backcoating</b>	Silicon based
Coefficient of Friction	Kd < 0.2
<b>Ribbon thickness</b>	< 9 µm
The ribbon is anti static build-up treated	

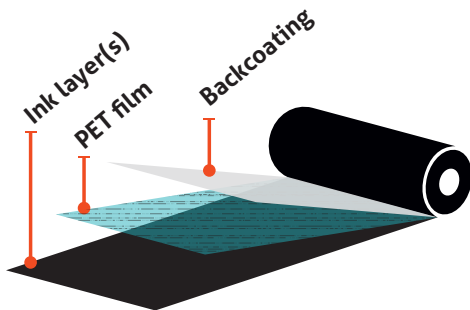

## Storage

### storage conditions

12 months recommended  
20-80 % Humidity Rate, 5-35°C (40-95°F)

## Waste management

inkanto rolls and their packaging allow an optimised waste management. For more information please contact ARMOR.

## The inkanto benefits



› **Warranty**  
This product is guaranteed for life against any manufacturing defect in normal conditions of use and storage.



› **Quality commitment**  
Easy to use with guaranteed product performance: the certificate of conformity for your product can be accessed via the flashcode on the box.



› **Easy to identify products:**  
The inkanto rolls families are identified by color codes. The roll labels highlight the important information about the product.



› **Your product is delivered with a cleaning wipe**  
To clean the print head and maintain the maximum performance of your printer.



› **Packing**  
Consistent packaging units depending on the roll dimensions.

## A certified and committed production site



**Quality, health & safety and environmental systems:**  
ISO 9001  
OHSAS 18001  
ISO 14001  
ISO 50001 (France only)



**Responsible Care**  
The charter of the International Council of Chemical Associations for improvements in health & safety and the environment.



**Global Compact**  
UN initiative inviting companies to apply fundamental ethical and environmental values.