




> APR600

Excellent sensitivity and receptor multi compatibility
 very good printing quality at high speed and sharpness of 90°
 Very high resistance to smudge


APR® 600 is the worldwide reference of premium ribbons for Corner Edge and Near Edge printers. It is the standard ribbon in inkanto's wax/resin range. Its performance (speed, sensitivity, versatility, blackness) provides a perfectly adapted answer to a large majority of applications.

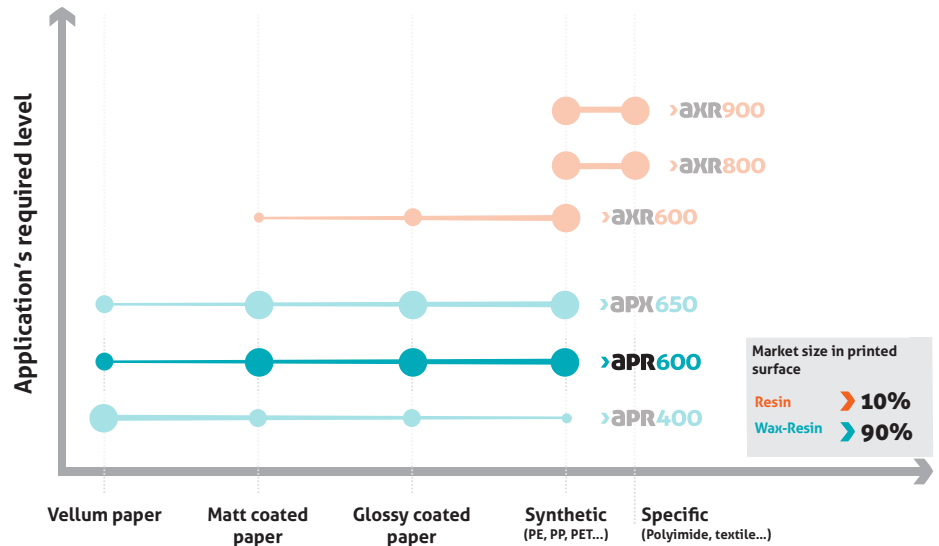


Printing receptor

papers	synthetics
Vellum ●●○	PP ●●●
Coated ●●●	PE ●●●
Glossy coated ●●●	PET ●●●

Printer settings

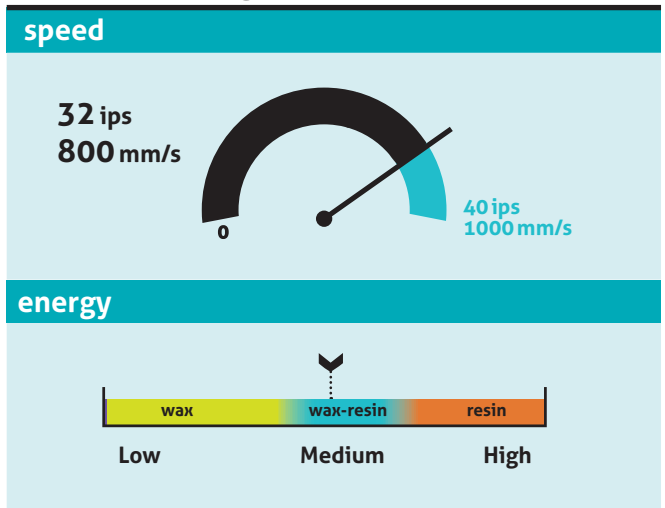

Print resistance

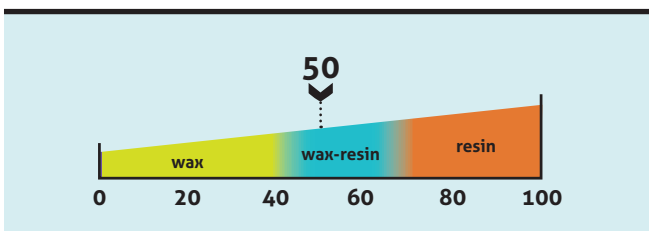

Compliant with the following regulations

REACH / SVHC 1907/2006/EC
Food Contact 1935/2004/EC
Heavy metals 2011/65/EU
California Proposition 65
Halogen restrictions

Your ribbon identity

Colours: ●●●●●●●●●●●●●●●●

 
Length (m):

Width (mm):

Part number:

Your distributor:

Contact :





APR600

Application fields




Product performance

print quality		
90°Barcode	80	A _a Small characters
0°Barcode	100	2D Barcode
		Logos
		Blackness <small>*Optical Density by Reflection, measured using a densitometer.</small>
technical resistances		
Heat	100°C / 212°F	Light/Blue Wool
	300°C / 572°F	Solvents
Water/Submerge	100	Rubbing

Product physico-chemical features

product structure	
PET film	Thickness: 4,5 µm
Ink	Wax-Resin
Melting point	80°C/176°F
Backcoating	Silicon based
Coefficient of Friction	Kd < 0.2
Ribbon thickness	< 8 µm
The ribbon is anti static build-up treated	

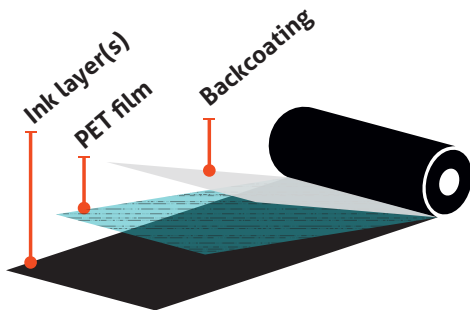

Storage

storage conditions

12 months recommended
20-80 % Humidity Rate, 5-35°C (40-95°F)

Waste management

inkanto rolls and their packaging allow an optimised waste management. For more information please contact ARMOR.

The inkanto benefits



› **Warranty**
This product is guaranteed for life against any manufacturing defect in normal conditions of use and storage.



› **Quality commitment**
Easy to use with guaranteed product performance: the certificate of conformity for your product can be accessed via the flashcode on the box.



› **Easy to identify products:**
The inkanto rolls families are identified by color codes. The roll labels highlight the important information about the product.



› **Your product is delivered with a cleaning wipe**
To clean the print head and maintain the maximum performance of your printer.



› **Packing**
Consistent packaging units depending on the roll dimensions.

A certified and approved production site



Quality, health & safety and environmental systems:
ISO 9001
OHSAS 18001
ISO 14001
ISO 50001 (France only)



Responsible Care
The charter of the International Council of Chemical Associations for improvements in health & safety and the environment.



Global Compact
UN initiative inviting companies to apply fundamental ethical and environmental values.