




> aWXFH

Very high smudge resistance
 Very good printing quality
 Excellent receptor multi-compatibility and sensitivity

AWX®FH is a resin enhanced wax ribbon.


Intrinsically, it is the highest performance wax ribbon of the inkanto range, enabling it to answer the requirements of all wax applications, including the most demanding ones, with very good resistance.

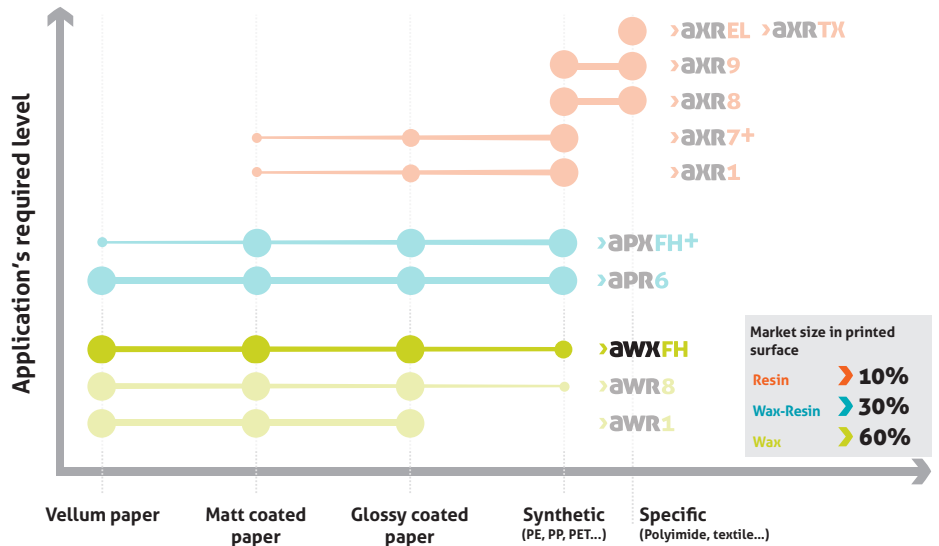


Printing receptor

papers		synthetics	
Vellum	●●●	PP	●●○
Coated	●●●	PE	●●○
Glossy coated	●●●	PET	●●○

Printer settings

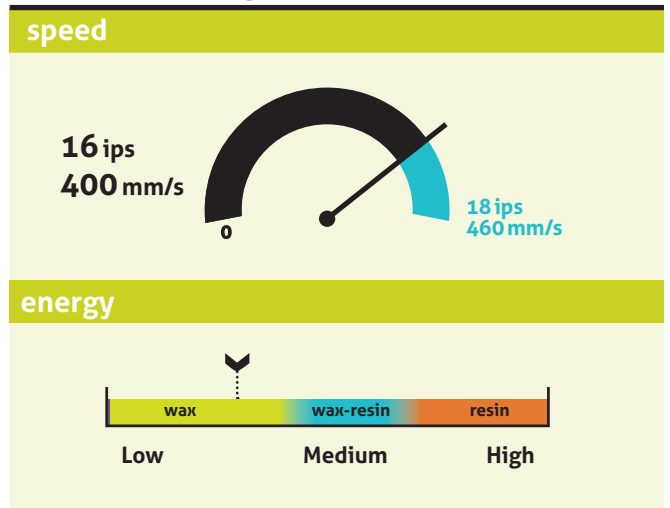

Print resistance

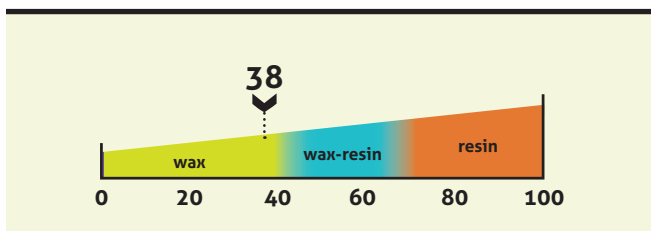

Compliant with the following regulations

REACH / SVHC 1907/2006/EC
Food Contact 1935/2004/EC
Heavy metals 2011/65/EU
California Proposition 65
Halogen restrictions

Your ribbon identity

Colours: ●

 
Length (m):

Width (mm):

Part number:

Your distributor:


Contact:





> awwx FH

Application fields

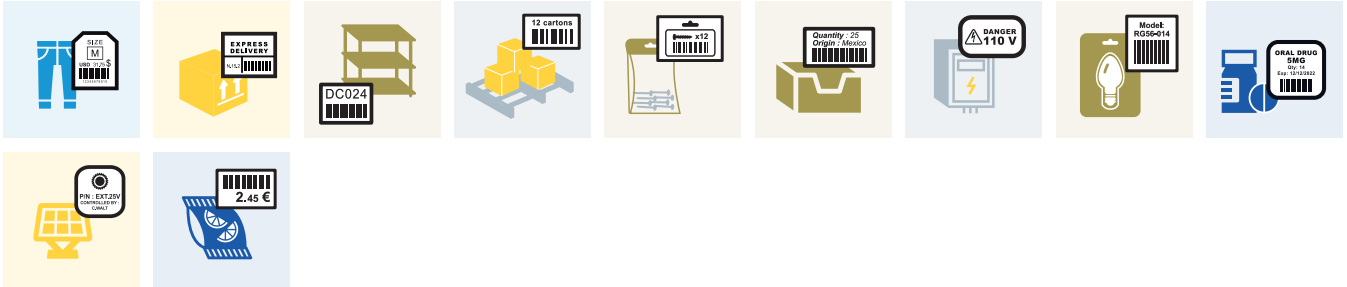


Product performance

print quality					
90°Barcode	75	A _a Small characters	85	Logos	95
0°Barcode	100	2D Barcode	100	Blackness	2,0 ODR*
technical resistances					
Heat	100°C 212°F	Light/Blue Wool	>7	Solvents	100
Water/Submerge	100	Rubbing	55		

Product physico-chemical features

product structure	
PET film	Thickness: 4,5 µm
Ink	Wax
Melting point	65°C/149°F
Backcoating	Silicon based
Coefficient of Friction	Kd < 0.2
Ribbon thickness	< 9 µm
The ribbon is anti static build-up treated	

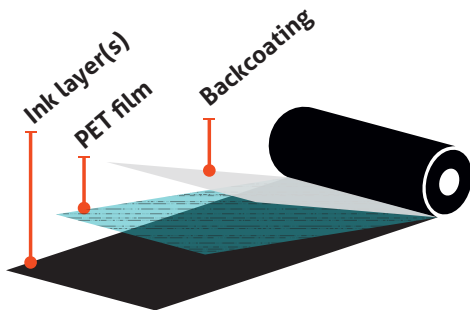

Storage

storage conditions

12 months recommended
20-80 % Humidity Rate, 5-35°C (40-95°F)

Waste management

inkanto rolls and their packaging allow an optimised waste management. For more information please contact ARMOR.

The inkanto benefits



› **Warranty**
This product is guaranteed for life against any manufacturing defect in normal conditions of use and storage.



› **Quality commitment**
Easy to use with guaranteed product performance: the certificate of conformity for your product can be accessed via the flashcode on the box.



› **Easy to identify products:**
The inkanto rolls families are identified by color codes. The roll labels highlight the important information about the product.



› **Your product is delivered with a cleaning wipe**
To clean the print head and maintain the maximum performance of your printer.



› **Packing**
Consistent packaging units depending on the roll dimensions.

A certified and committed production site



Quality, health & safety and environmental systems:
ISO 9001
OHSAS 18001
ISO 14001
ISO 50001 (France only)



Responsible Care
The charter of the International Council of Chemical Associations for improvements in health & safety and the environment.



Global Compact
UN initiative inviting companies to apply fundamental ethical and environmental values.