


Explosion Proof LED Floodlight

Brighter and more powerful than the XP970LED, this explosion proof floodlight has all the benefits of the smaller model, with more power. Standard models include a 16/3 SOOW cord and non-xp plug. The XP980LED comes with optional cords and plugs. Explosion Proof plugs available.

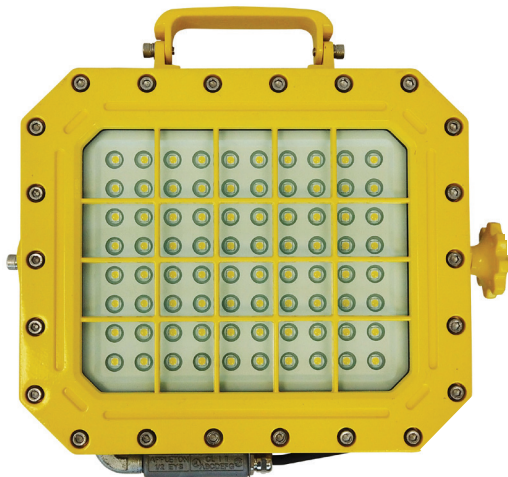

Approvals:

cULus Certified for Class I, Division 1, Groups B, C and D. Class II, Division 1, Groups E, F and G

SKUs

XP980LED-FS

24,000 lumen Explosion-Proof LED Floodlight w/50' cord and floor stand

XP980LED-TR

24,000 lumen Explosion-Proof LED Floodlight w/50' cord and 4-8' tripod

KEY FEATURES

- *Easily portable.*
- *LEDs will last over 50,000 hours.*
- *No bulb replacement required.*
- *Instant start-up, at full output, even in cold temperatures.*
- *Rugged heavy duty frame*

KEY BENEFITS

- *Safer working environment.*
- *Lower total cost of ownership.*
- *Reduced downtime on job sites.*
- *Energy saving device for a greener footprint.*

SPECIFICATIONS	
VOLTAGE	90 - 277V AC
WATTAGE	200W (1.66A @ 120V)
LIGHT TEMPERATURE	4500K (bright white light • no blue tint)
LUMENS	24,000 lumens
LIGHT EXPECTANCY	Rated for over 50,000 hours
CONSTRUCTION	Cast aluminum housing with tempered glass lens
DIMENSIONS	3.75"D x 14"H x 15.5"W
WEIGHT	35 lbs (less cable)

