

# BLUSTORM HIGH SPEED HAND DRYER



### Stainless Steel Construction

for maximum durability

### Recessed Design

to make the HD0955 ADA Compliant

### Blue Light Technology

allows users to maximize the dryers efficiency

### Wide Drying Area

for an optimal 10-15 second dry time

### MODEL NUMBER & COLOR

HD0950-09, HD0951-09	Brushed Stainless
HD0955-09	Brushed Stainless

### COLOR OPTIONS

(09) BRUSHED STAINLESS

### TECHNICAL SPECIFICATIONS

**Material:** Stainless Steel

**Motor Type:** Adjustable brush type, dual ball bearings

**Thermal Protection:**  
 Motor Shuts Off at 275°F (120V), 221°F (240V)  
 Heater Shuts Off at 185°F (85°C)

**Operating Airflow:** 32.4-58.9 CFM, Adjustable

**Air Output Temperature:**

131°F (55°C)  
 Ambient Temperature 77°F (25°C)

**Sound Level:** 68.2dB

**Isolation:** Class 1

**Drip Proof:** IP31

**Watts:** Heater Element 450-700W, Adjustable

**RPM:** 12,000-18,000, Adjustable

**Voltage & Amps:**

HD0950-09	110/120 Volts	12.5-13.4 Amps
HD0951-09	220/240 Volts	8-8.5 Amps
HD0955-09	110/120 Volts	12.5-13.4 Amps


**Mounting:** Surface or Recessed

### BluStorm Extras


Filter Assembly	SP095099-003
Filter	SP095099-004
Custom Cover	*CALL*



### HD0950 & HD0951

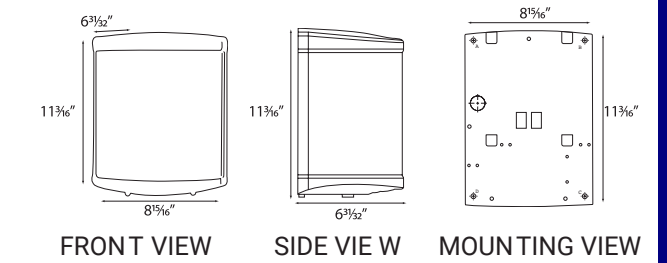

### HD0955

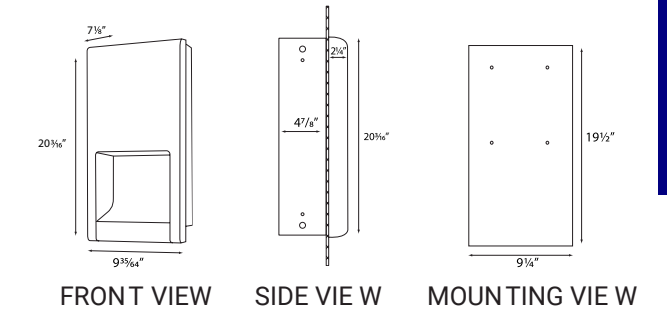

### MOUNTING HEIGHTS

from bottom of dryer to the finished floor

Men	50"
Women	47"
Children (4-7)	35"
Children (8-10)	39"
Children (11-13)	43"
Children (14-16)	47"
Disabled	40"

### DIMENSIONS & WEIGHT

#### HD0950 & HD0951

Width:	8.94"
Height:	11.125"
Depth:	6.97"
Weight:	12.1 lbs

#### HD0955

Width:	9.84"
Height:	20.20"
Depth:	7.06"
Weight:	20.7 lbs

HIGH SPEED HAND DRYERS

MODEL: HD0950 & HD0955 | ULTRA SERIES

