


# ergotron®

*moving you forward*

## **WM Low Profile Wall Mount**

- Installs in three simple steps
- Extremely slim profile, just over an inch from the wall
- Sleek silver and charcoal grey design complements home or office decor
- Includes fasteners for mounting to wood studs or concrete
- UL certified and listed to UL Standard 1678. This product has been tested to hold four times its maximum load capacity per UL standard (do NOT exceed listed weight capacity in actual use)
- Easily connects and detaches, but security fasteners deter removal
- Excellent price performance
- XL version provides the extra width to handle larger displays that use mounting-hole patterns up to 800 mm wide
- 5 year warranty

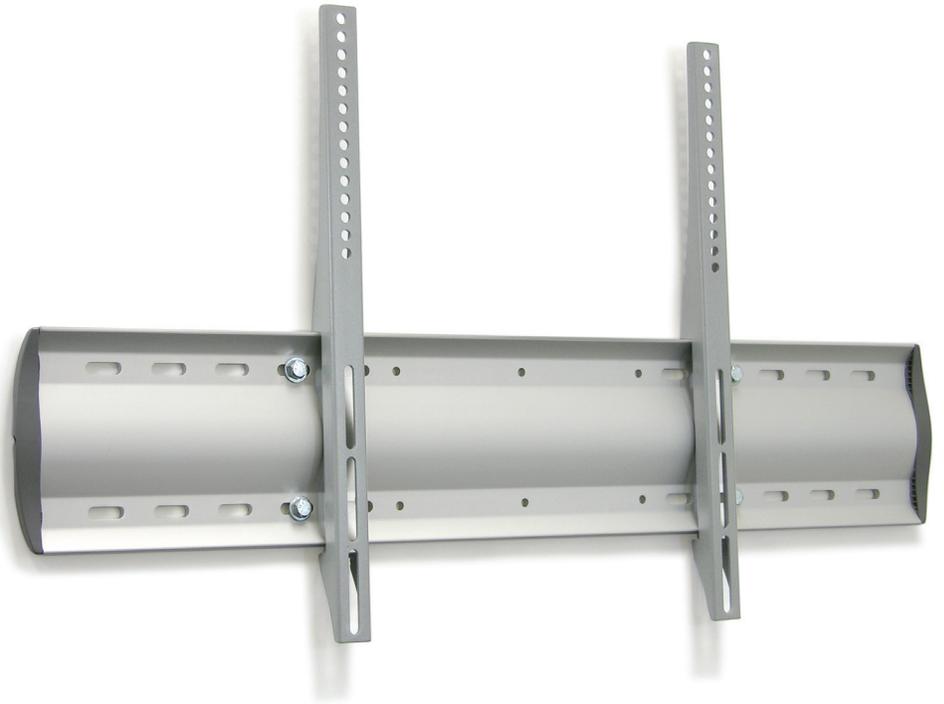

STURDY AND STABLE MOUNT WITH AN EXTREMELY SLIM PROFILE

Don't be intimidated by mounting your display or TV. This wall-hugging design hangs your flat panel TV just over an inch from the wall for an extremely slim profile.

Engineered to install in three easy steps, the Ergotron Low Profile Wall Mount is sturdy and stable. It accommodates most displays up to 175 lbs, and the security fasteners help protect your TV from theft.



# WM Low Profile Wall Mount

## SIMPLE INSTALLATION:

- 1 Attach wall plate to chosen location on wall
- 2 Attach mounting brackets to display
- 3 Hang display on wall plate

1



2



3



Security fasteners on mounting brackets prevent easy removal of the display

Mounting options: Wall plate attaches to vertical wall surfaces. Includes hardware for mounting to wood studs (16" or 24" centered studs) or concrete walls

Part # (color)	60-604-003 (silver)	XL: 60-602-003 (silver)
Includes	Wall plate, two (2) display brackets, hardware fastener kit	
Typical LCD Size	32–120"	≥ 42"
<small>LCD SIZE IS APPROXIMATION. DIMENSION IS DIAGONAL MEASUREMENT OF SCREEN. LCD SIZE MAY BE EXCEEDED AS LONG AS SCREEN WEIGHT DOES NOT EXCEED MAXIMUM WEIGHT CAPACITY OF THE MOUNT.</small>		
Weight Capacity	≤ 175 lbs (79,4 kg)	
VESA	MIS-D/E/F (see website)	
Profile	1.25" (32 mm)	
Shipping Weight	10 lbs (4,5 kg)	12 lbs (5,5 kg)
Shipping Dimensions	33.3"W x 10.4"H x 2.2"D (84,5 x 26 x 5,5 cm)	39.8"W x 10.4"H x 2.2"D (101 x 26 x 5,5 cm)
Warranty	5 years	

Download additional resources at [ergotron.com](http://ergotron.com).

For more information:

NORTH AMERICA: 800.888.8458 / +1.651.681.7600 / [sales@ergotron.com](mailto:sales@ergotron.com)

EMEA: +31.33.45.45.600 / [info.eu@ergotron.com](mailto:info.eu@ergotron.com)

APAC: [apaccustomerservice@ergotron.com](mailto:apaccustomerservice@ergotron.com)

OEM: [info@oem.ergotron.com](mailto:info@oem.ergotron.com)

© Ergotron, Inc. 02.15.2019

Literature made in the U.S.A.

Content subject to change.

Ergotron devices are not intended to cure, treat, mitigate or prevent any disease.

Patent information available at [www.ergotron.com/patents](http://www.ergotron.com/patents).

