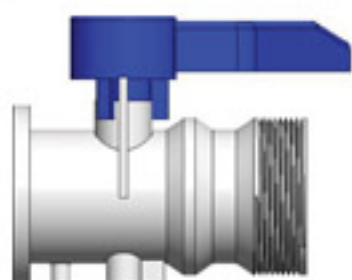
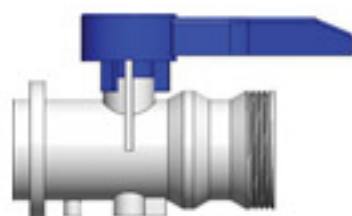
**S60 x 6 (2" Male Buttress)**

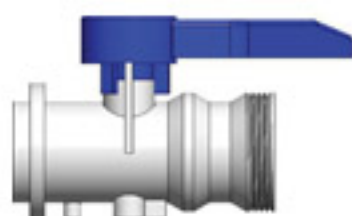
DIAMETER: 60mm (2.36")
THREAD PITCH: 6mm (0.24")
THREAD STANDARD: DIN 6131
DESCRIPTION: Common thread found on European IBC's

REFERENCE KEY: A**2" NPS Male**

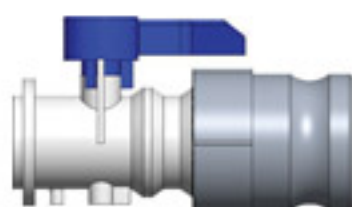
DIAMETER: 59.6mm (2.35")
THREAD PITCH: 2.21mm (0.9" / 11.5 TPI)
THREAD STANDARD: ANSI B1.20.1-1983
DESCRIPTION: American National Standard Straight Pipe Thread

REFERENCE KEY: B**2" Camlock Male with 2" BSP**

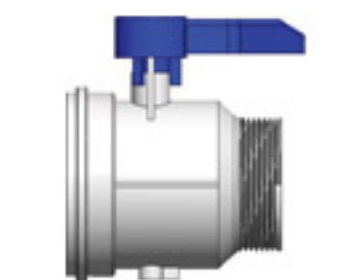
DIAMETER: 63mm (2.48") & 59.4mm (2.34") Thread
THREAD PITCH: 2.3mm (0.09" / 11 TPI)
THREAD STANDARD: Camlock-A-A-59326: 1992
Thread - BS 2779: 1986
DESCRIPTION: Camlock male adaptor with additional external BSP thread for dust cap

REFERENCE KEY: C**2" Camlock Male with 2-1/8" BSP**

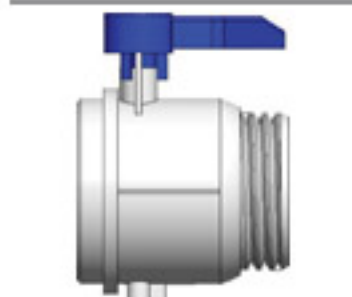
DIAMETER: 63mm (2.48") & 62.7mm (2.47") Thread
THREAD PITCH: 2.3mm (0.09" / 11 TPI)
THREAD STANDARD: Camlock-A-A-59326: 1992
Thread - N/A
DESCRIPTION: Camlock male adaptor with additional external oversized BSP thread for dust cap

REFERENCE KEY: D**2" Camlock Male Adaptor**

DIAMETER: 63mm (2.48")
THREAD PITCH: N/A
THREAD STANDARD: Camlock-A-A-59326: 1992
DESCRIPTION: Camlock male adaptor fitted to an IBC

REFERENCE KEY: E**M80 x 3 Male Thread**

DIAMETER: 80mm (3.15")
THREAD PITCH: 3mm (0.12")
THREAD STANDARD: ISO 68 (ANSI B1.13M)
DESCRIPTION: 80mm(3.15") metric thread

REFERENCE KEY: F**S100 x 8 (3" Male Buttress)**

DIAMETER: 97-100mm (3.82"-3.94")
THREAD PITCH: 8mm (0.12")
THREAD STANDARD: N/A
DESCRIPTION: Found on many 3"outlet IBC's with short length and large threading

REFERENCE KEY: G**3" Camlock with 3" BSP**

DIAMETER: 91.5mm (3.6") & 87.7mm (3.45") Thread
THREAD PITCH: 2.3mm (0.09" / 11 TPI)
THREAD STANDARD: Camlock-A-A-59326: 1992
Thread - BS 2779: 1986
DESCRIPTION: Camlock male adaptor with additional external BSP thread for dust cap

REFERENCE KEY: H