


812540 25" Light Industrial LED Task Lamps

With a total of 425 lumens and 90 lm/W efficiency, this LED lamp head brightens your workspace and ensures energy savings.

The versatile 25" flexible steel gooseneck arm provides direct light where it's needed most, while the 9-foot cable with a ground plug offers easy placement. An intuitive On/Off button and a robust 90 lb. pull magnetic base makes operation a breeze, and the lamp's sleek black aluminum alloy metal construction adds an industrial touch to your workspace.

Common Applications:

- CNC equipment
- Precision engraving machines
- Spark machines
- Laser welding machines
- Ceramic processing machines
- Small parts manufacturing
- Anywhere with a steel surface or workbench

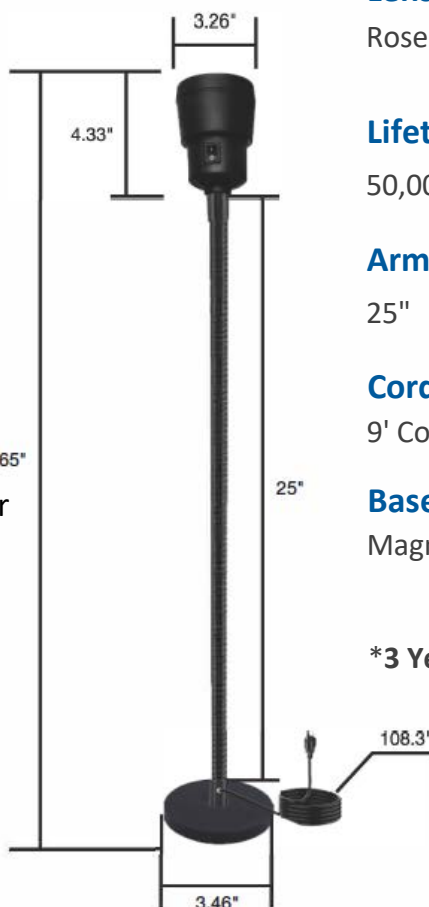

SPECIFICATIONS

Output

425 Lumens Total

Power

5 Watts

Efficiency

>= 90 lm/w when stable

Color Temp.

3000K

Surface Temp.

<50°C

Lens

Rose UV filter

CRI(Ra)

>80

IP Rate

IP50

Lifetime

50,000 Hours

Voltage

120 V

Arm

25"

Switch

On/Off button

Beam Angle

24°

Cord

9' Cord American Standard Three-Pin Plug

Base

Magnetic (90 lb. pull)

***3 Years Warranty**

