

Assembly Instructions
Instrucciones de Ensamblaje
Directives d'assemblage

 Customer Service
 US: 1-800-645-2986

 Servicio de atención al Cliente
 US: 1-800-645-2986

 Service à la clientèle
 Canada: 888-645-2986

4 in 1 Portable Workbench

Workbench | Work Platform | Creeper | Dolly

Model # 493680

① Workbench



② Work Platform



③ Creeper



④ Dolly



⚠ WARNING

- When standing on platform, keep legs in the center of platform to avoid tipping the workbench.
- Do not use excessive force when extending or retracting legs, this can damage leg supports.
- Be sure all spring loaded pins, hinges, and latches. Snap, click, and lock into place before use.
- Before use, make sure legs and latches are firmly locked.
- Do not exceed power ratings listed in the manual. Refer to Table A
- Do not exceed weight capacities per mode listed in the manual. Refer to Spec Sheet B

ATTENTION

- Ensure that operating instructions are understood by all personnel capable of using the unit.
- Avoid storing workbench outside or in humid environments.

Read this manual thoroughly prior to installation, operation or maintenance. Keep these instructions in a safe location for future reference. For questions, visit globalindustrial.com or contact Customer Service at 1-800-645-2982.

4 in 1 Multipurpose Workbench

Table A.

Modes	Weight Capacity
Workbench	500 lbs
Work Platform	500 lbs
Dolly	300 lbs
Creeper	300 lbs

Spec Sheet B.

POWER RATINGS

MAX:

125 Volts

15 Amps

1875 Watts

- 3 outlet plugs.
- 1 male plug for extension cable.



- Handle for easy portability.



Creeper Mode



Use Creeper mode when performing jobs in low profile spaces. Creeper mode is also used to efficiently and safely store the workbench.

DO NOT STEP NOR STAND ON THE PLATFORM WHILE ON CREEPER MODE.

Dolly Mode



From Creeper mode, release the four latches on the sides of the workbench to flip platform panel to the non-slip surface side.




Holes on side allow for carabiner attachment. Be sure to pair workbench with equipment that can handle weight capacity. Refer to Table A.

DO NOT STEP NOR STAND ON THE PLATFORM WHILE ON DOLLY MODE.

4 in 1 Multipurpose Workbench


Workbench Mode

①

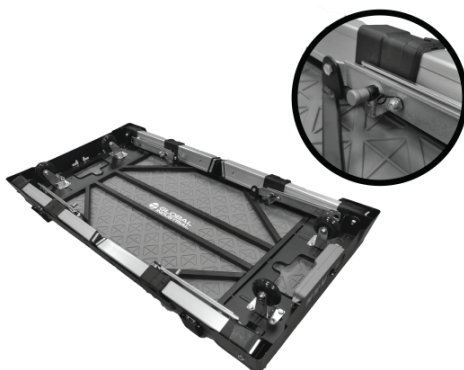

From creeper mode, flip workbench and pull out spring loaded locking pins and pull each leg up and out.

②

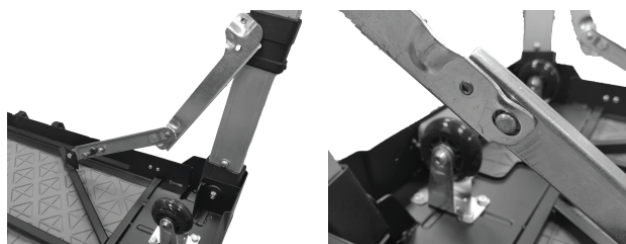

Extend leg outward until hinges lock.
HINGES MUST LOCK

③



Press on spring buttons and slide legs to adjust height. Spring button on each leg MUST CLICK before using the product.
DO NOT USE PRODUCT IF SPRING BUTTONS DO NOT CLICK AND/OR HINGES DO NOT LOCK.

Work Platform Mode

①



From Workbench mode, release the four latches on the sides of the workbench to free the platform surface panel.

②



Lift and turn over panel so that the anti-slip surface is face up. Then re-attach to workbench.